



Support Grips - Heavy Duty

- Ericson Heavy Duty Support Grips are designed to withstand greater loads and increased stress
- Stranded tinned bronze wire.

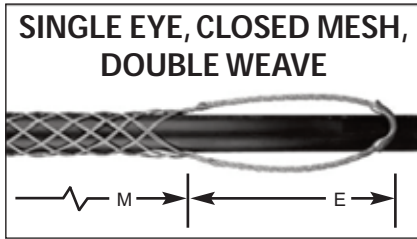

CATALOG NUMBER	DIA. RA.	APPROX. BREAKING STRENGTH	LENGTH	
			E	M
SGHD-CM-075-SE	.75-.99	2820LBS.	10	25
SGHD-CM-100-SE	1.00-1.24	4280LBS.	10	28
SGHD-CM-125-SE	1.25-1.49	4280LBS.	10	30
SGHD-CM-150-SE	1.50-1.99	4280LBS.	10	34

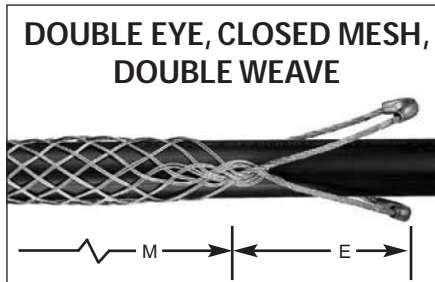

CATALOG NUMBER	DIA. RA.	APPROX. BREAKING STRENGTH	LENGTH	
			E	M
SGHD-CM-075-DE	.75-.99	2820LBS.	10	25
SGHD-CM-100-DE	1.00-1.24	4280LBS.	10	28
SGHD-CM-125-DE	1.25-1.49	4280LBS.	10	30
SGHD-CM-150-DE	1.50-1.99	4280LBS.	10	34
SGHD-CM-200-DE	2.00-2.49	8050LBS.	10	36
SGHD-CM-250-DE	2.50-2.99	8050LBS.	10	38
SGHD-CM-300-DE	3.00-3.49	10060LBS.	10	40
SGHD-CM-350-DE	3.50-3.99	12070LBS.	10	44
SGHD-CM-400-DE	4.00-4.49	12070LBS.	10	46

E = Eye Length M = Mesh Length at Nominal Diameter (Inches)

Support Grip Number Structure

Product Type	Mesh	Mesh Diameter	Eye Style
SG = Support Grips	CM = Closed Mesh	Lower Diameter	DE = Double Eye
SGHD = Support Grips Heavy Duty (Double Weave)	LC = Lace Closing	Range of Mesh	SE = Single Eye
	RC = Rod Closing		OFS = Offset Eye
			UB = Universal Bale



Caution: When selecting a grip, never use to their approximate breaking strength. Refer to Technical Reference section for safety and working load factors.