



3, 4, and 5-Wire Industrial Grade Heavy-Duty String Lights

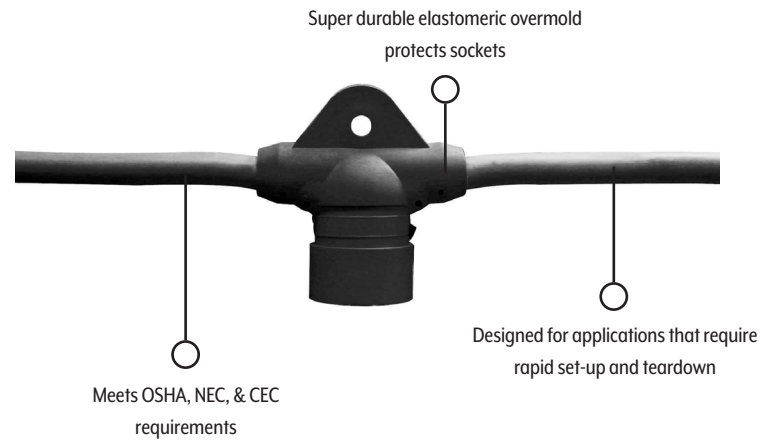

211-P vinyl dipped guard

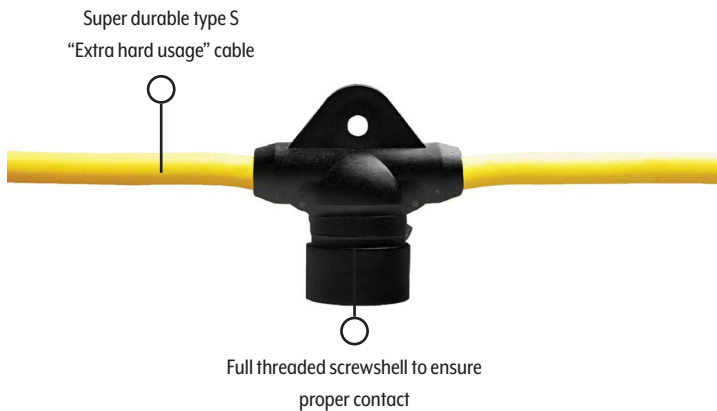


211 wire guard



215 rain guard (60W max)

String lights come standard with watertight NEMA plug and connector

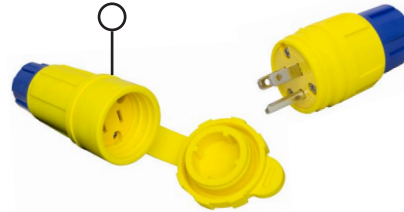

Perma-Tite® 2 watertight plug and connector



Other Standard Features:

- Select models UL listed and CSA certified
- Meets OSHA, NEC, & CEC requirements
- Full threaded screwshell to ensure proper contact
- Designed for applications that require rapid set-up and teardown
- String lights available in 50 ft. and 100 ft.
- String lights come standard with watertight NEMA plug and connector
- Power drops available
- Guards sold separately
- Product customizations are available upon request

Applications:

- Shipyard construction
- Shipboard usage
- Aircraft construction
- Mines/Tunnels
- Transit
- Steel Mills
- Military
- Dams
- Power Gen Shutdowns
- Oil/Gas Turnarounds
- Holiday/Festive Decorative displays
- Bridge Lighting
- Custom Design solutions to meet your application

Related Products:

Part Number	Description	Label
SLBLED-60	11W 1150 lumen LED damp location light bulb	A
SS-HD	Rubber socket sleeve, weathertight seal	B
RFID	RFID tagging service	C
SLHK-1	String light hang kit	D



Selection Guide:

Part Number	Listing	Length	Cable Type / Voltage	# of Sockets	Socket Spacing	Max Watts per Socket	Primary	Secondary
12350Y-1	UL / CSA	50 ft.	12/3 SEOW or SOW 600V	5	10 ft.	150 Watts ¹	NEMA 5-15	NEMA 5-15
12350Y-2	UL / CSA	50 ft.	12/3 SEOW 600V	5	10 ft.	150 Watts ¹	NEMA L5-15	NEMA L5-15
12350Y-3	UL / CSA	50 ft.	12/3 SEOW 600V	5	10 ft.	150 Watts ¹	NEMA L5-20	NEMA L5-20
123100Y-1	UL / CSA	100 ft.	12/3 SEOW 600V	10	10 ft.	150 Watts	NEMA 5-15	NEMA 5-15
123100Y-2	UL / CSA	100 ft.	12/3 SEOW 600V	10	10 ft.	150 Watts	NEMA L5-15	NEMA L5-15
123100Y-3	UL / CSA	100 ft.	12/3 SEOW 600V	10	10 ft.	150 Watts	NEMA L5-20	NEMA L5-20
12460Y-4	N/A	60 ft.	12/4 SEOW 600V	6	10 ft.	150 Watts ¹	NEMA L14-20	NEMA L14-20
124100Y-4	N/A	100 ft.	12/4 SEOW 600V	10	10 ft.	150 Watts	NEMA L14-20	NEMA L14-20
12560Y-5	N/A	60 ft.	12/5 SEOW 600V	6	10 ft.	150 Watts	L21-20C	L21-20C
12590Y-5	N/A	90 ft.	12/5 SEOW 600V	9	10 ft.	150 Watts ¹	L21-20C	L21-20C
14350Y-1	UL	50 ft.	14/3 SEOW 600V	5	10 ft.	150 Watts ¹	NEMA 5-15	NEMA 5-15
14350Y-2	UL	50 ft.	14/3 SEOW 600V	5	10 ft.	150 Watts ¹	NEMA L5-15	NEMA L5-15
143100Y-1	UL	100 ft.	14/3 SEOW 600V	10	10 ft.	150 Watts	NEMA 5-15	NEMA 5-15
143100Y-2	UL	100 ft.	14/3 SEOW 600V	10	10 ft.	150 Watts ¹	NEMA L5-15	NEMA L5-15

¹ For 10 socket strings 150W is max per socket. For less than 10 sockets up to 200W is permissible although socket may be marked 150W



Ericson Manufacturing Company
4323 Hamann Parkway
Willoughby, OH 44094, USA



1.800.374.2766
info@ericson.com
www.ericson.com
L1000839A