

CES-A-BMB (Order no. 077791)

Actuator CES-A-BMB


- ▶ Cylindrical design M12 x 0.75



Insertion tool

With the aid of the insertion tool, the actuator CES-A-BMB (cylindrical design) can be screwed into a prepared M12 x 0.75 thread in the safety door.

Dimensional drawings

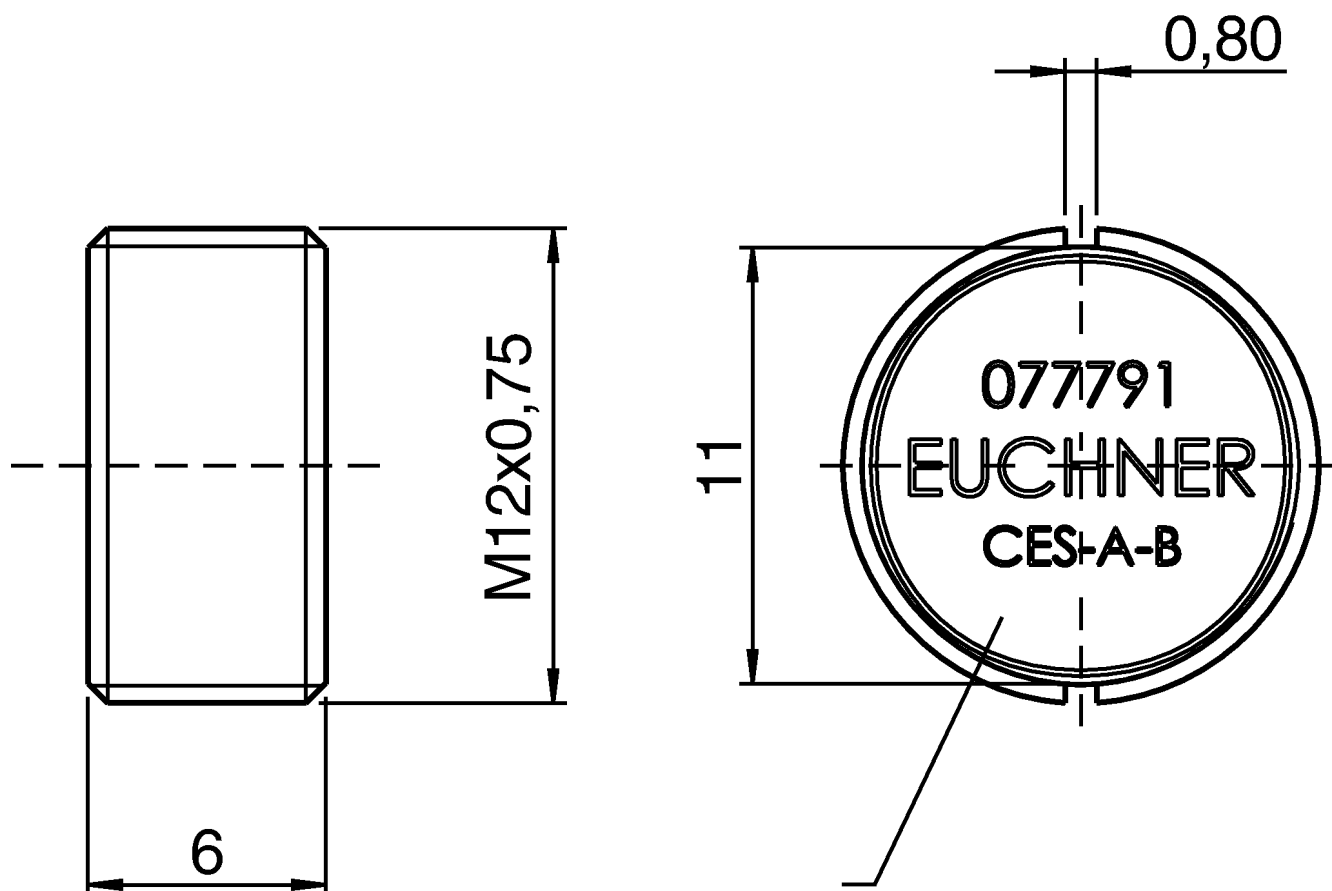

Technical data

Approvals



Electrical connection values

Power supply	Inductive via read head
--------------	-------------------------

Mechanical values and environment

Mounting type	screws, flush in steel
Degree of protection	IP67/IP69/IP69K
Ambient pressure	max. 10 bar (applies only if the pressure acts on the actuator from all sides)
Ambient temperature	-25 ... +85 °C
Material	
	Active face Ceramic (AL2 O3)
	Sleeve stainless steel

Downloads

All documentation for this material can be found on our website:

<https://www.euchner.de/en-us/a/077791/?#downloads-tab>

Ordering data

Ordernumber	077791
Item designation	CES-A-BMB
Gross weight	0,005kg
Customs tariff number	85389099990
ECLASS	27-27-24-04 Actuator for safety-related proximity switch

Accessories

Mounting accessories

Insertion tool for actuator CES-A-BMB



037662

EINDREHWERKZEUG