



## CMS-M-AC (Order no. 084592)

### Actuator CMS design A

- ▶ Cube-shaped version, 88 x 25 mm

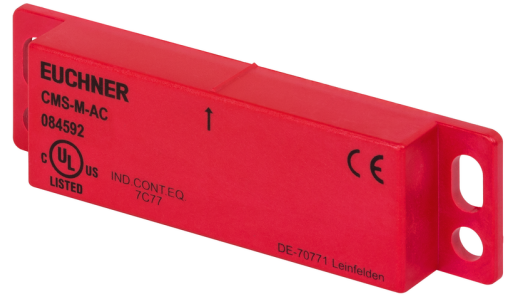


### Dimensional drawings

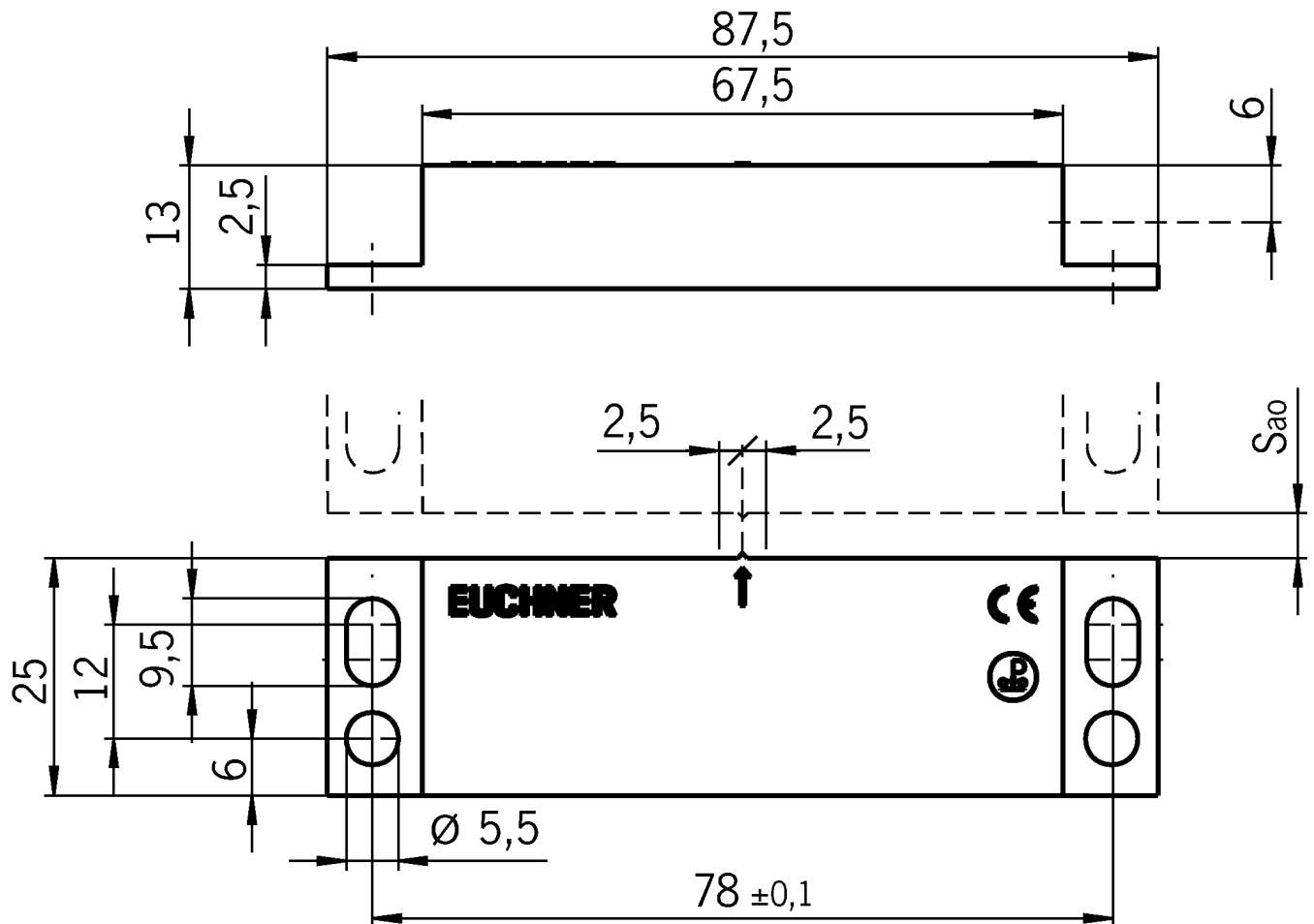

## Technical data

### Approvals

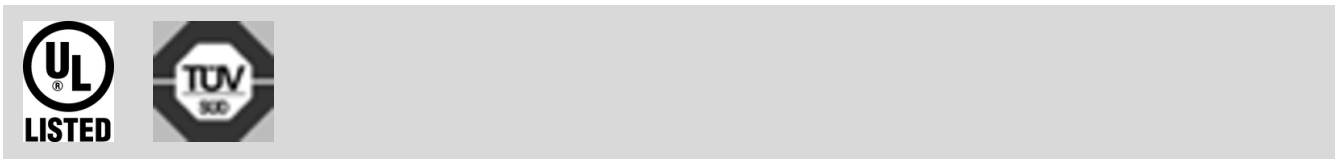

### Mechanical values and environment

|                      |                |
|----------------------|----------------|
| Tightening torque    | 0.4 ... 0.5 Nm |
| Design               | A              |
| Degree of protection | IP67           |
| Ambient temperature  | -20 ... +60 °C |
| Material             |                |
|                      | Housing PPS    |
| Method of operation  | Magnetic       |

### Miscellaneous

|                    |   |
|--------------------|---|
| in compliance with | EN ISO 13849-1:2015; EN 50178:1997; EN 60204-1:2006/A1:2009; EN ISO 14119:2013; EN 61000-6-2:2005; EN 61000-6-3:2007/A1:2011; EN 60947-5-3:2013 |
|--------------------|---|

## Downloads

All documentation for this material can be found on our website:

<https://www.euchner.de/en-us/a/084592/?#downloads-tab>

**Ordering data**

|                       |  |
|-----------------------|--|
| Ordernumber           | 084592   |
| Item designation      | CMS-M-AC   |
| Gross weight          | 0,043kg  |
| Customs tariff number | 85389099990  |
| ECLASS                | 27-27-24-04 Actuator for safety-related proximity switch |