



Model SLM500 shown with mounting base options (ordered separately)

► Model SLM500

# StreamLine® Modular Multifunctional LED Combination Audible/Visual Signal

Model SLM500 is a multifunctional LED beacon and sounder combination developed with a multiple input technology that allows three separate levels of alarm (alert, pre-alarm, alarm) controllable via independent electric contacts.

Channel 1 includes a simulated strobe (triple flash) visual signal only. Channel 2 adds an audible tone, selectable from 32 tones via dip switch, to the simulated strobe effect. Channel 3 includes a steady light and a second, unique tone selectable from 32 different tones, for a total of 64 unique tones.

The volume of a selected tone is adjustable (65-105 dBa) for the highest performing tone). Its enclosure is made from a self extinguishing polycarbonate material with high impact and UV resistance.

## FEATURES

- Compatible with 12-24VAC/DC or 120-240VAC\*
- PLC compatible with PNP or NPN connections\*
- 3 Channels included
  - 1: Simulated strobe
  - 2: Simulated strobe + tone 1
  - 3: Steady light + tone 2
- 50,000 hour LED
- Five lamp/lens colors: Amber, Blue, Clear, Green and Red
- Five mounting base options
- Type 3R, IP65 enclosure
- CE Certified and RoHS Compliant
- UL and cUL listed

\*Voltage and PLC connections are dependent on selected base.

MODEL	VOLTAGE	FLASH RATE/MINUTE (FLASH MODE)	DECIBELS @ 1M	
			MIN.	MAX.
<b>SLM500 *</b>	12-24VAC/DC or 120-240VAC	85 (+/-10)	65	105

\* Indicates color: (A) Amber, (B) Blue, (C) Clear, (G) Green or (R) Red

MAXIMUM OPERATING CURRENT (mA)			
12 VAC/DC	24 VAC/DC	120 VAC	240 VAC
380	460	100	60


# StreamLine® Modular Multifunctional LED Combination Audible/Visual Signal (SLM500)

## SPECIFICATIONS


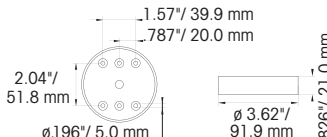

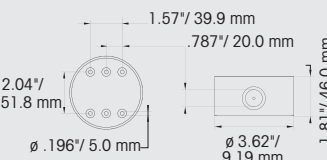

 

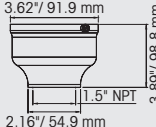

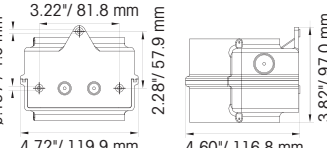
Lamp Life:	50,000 Hours	
Light Source:	LED	
Operating Temperature:	-22°F to 122°F	-30°C to 50°C
Weight (unit(s) + base = total weight)		
SLM500	7.76 oz	0.22 kg
Shallow Base	2.12 oz	0.06 kg
Deep Base		
12-24 VAC/DC	4.23 oz	0.12 kg
120-240 VAC	6.0 oz	0.17 kg
Wall Mount		
12-24 VAC/DC	6.70 oz	0.19 kg
120-240 VAC	8.47 oz	0.24 kg
Pipe Mount		
12-24 VAC/DC	5.29 oz	0.15 kg
120-240 VAC	6.70 oz	0.19 kg
Twin Wall Mount		
12-24 VAC/DC	9.17 oz	0.26 kg
120-240 VAC	12.35 oz	0.35 kg

## HOW TO ORDER

- Specify model number SLM500 and color
- Specify required mounting base (see chart)
- Optional dome guard  
For shallow mounting base (SLMDG1)  
For deep mounting base (SLMDG2)
- Accessories for Twin and Wall Mount Bases  
Cable Gland, M20, Gray, 2 Pack (K77700416)  
Cable Gland, M20, Red, 2 Pack (K77700416-01)
- Accessories for Pipe Mount Base  
1" NPT Adapter (SLMNPT1)  
1/2" NPT Adapter (SLMNPT2)

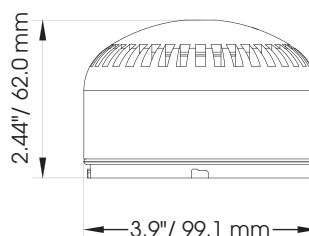

## MOUNTING BASE OPTIONS

	Model Number	Base Color	Voltage	
 Shallow Base	SLMBS-012-024GY	Gray	12-24VAC/DC	
 Deep Base	SLMBD-012-024GY	Gray	12-24VAC/DC	
	SLMBD-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBD-012-024R	Red	12-24VAC/DC	
	SLMBD-120-240GY	Gray	120-240VAC	
 Wall Mount	SLMBW-012-024GY	Gray	12-24VAC/DC	
	SLMBW-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBW-120-240GY	Gray	120-240VAC	
 Pipe Mount	SLMBP-012-024GY	Gray	12-24VAC/DC	Pipe Mount comes standard with 1/2" NPT Adapter 
	SLMBP-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBP-120-240GY	Gray	120-240VAC	
 Twin Wall Mount	SLMBT-012-024GY	Gray	12-24VAC/DC	
	SLMBT-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBT-120-240GY	Gray	120-240VAC	