



► Model PM22C

# Panel Mount 22mm Multifunctional LED Audible/Visual Combination Signal

Model PM22C is a multifunctional panel mount LED and piezoelectric sounder combination that offers 7 different sound/flash pattern combinations, controllable via independent electric contacts. Combinations include 1) steady light only, 2) continuous sound only, 3) steady light + continuous sound, 4) strobe (300FPM) + intermittent tone SYNC, 5) 2x flash (60FPM) + 2x intermittent tone SYNC, 6) 3x flash (40FPM) + 3x intermittent tone SYNC and 7) random light + random tone.

Model PM22C available in 12-24VAC/DC and two electrical connection options: M12 Cable Gland with 12" (300 mm) leads or M12 4-Pin Quick Connect (-Q). It is panel mounted through a 22 mm/0.87" hole and secured with the provided locking ring.

The PM22 Series offers a self-extinguishing polycarbonate body that protects against vibrations, dust and other atmospheric elements.

## FEATURES


- Available in 12-24VAC/DC
- 7 flash/tone combinations:
  - 1) steady light
  - 2) continuous tone
  - 3) steady light + tone
  - 4) strobe + intermittent tone SYNC
  - 5) 2x flash + 2x intermittent tone SYNC
  - 6) 3x flash + 3x intermittent tone SYNC
  - 7) random light + random tone
- Choice of M12 cable gland or M12 4-pin quick connect (-Q models) electrical connections
- 50,000 hour LED
- Opaque polycarbonate lens
- 360 degrees light-diffusing design
- Type 3R, IP65 enclosure
- CE Certified
- UL and cUL listed

| MODEL                 | VOLTAGE     | FLASH RATE/MINUTE (FLASH MODE) |          |          |        |        | DECIBELS MAXIMUM |    |
|-----------------------|-------------|--------------------------------|----------|----------|--------|--------|------------------|----|
|                       |             | STROBE                         | 2X FLASH | 3X FLASH | RANDOM | STEADY | 10'              | 1M |
| <b>PM22C-012-024*</b> | 12-24VAC/DC | 300                            | 60       | 40       | N/A    | N/A    | 82               | 92 |

\* Indicates color: (A) Amber, (B) Blue, (C) Clear, (G) Green, (R) Red and/or electrical connection: (-Q) Quick Connect (leave blank for M12 cable gland)

| MAXIMUM OPERATING CURRENT (mA) |       |       |       |
|--------------------------------|-------|-------|-------|
| 12VDC                          | 24VDC | 12VAC | 24VAC |
| 45                             | 45    | 90    | 110   |

# Panel Mount 22mm Multifunctional LED Audible/Visual Combination Signal (PM22C)

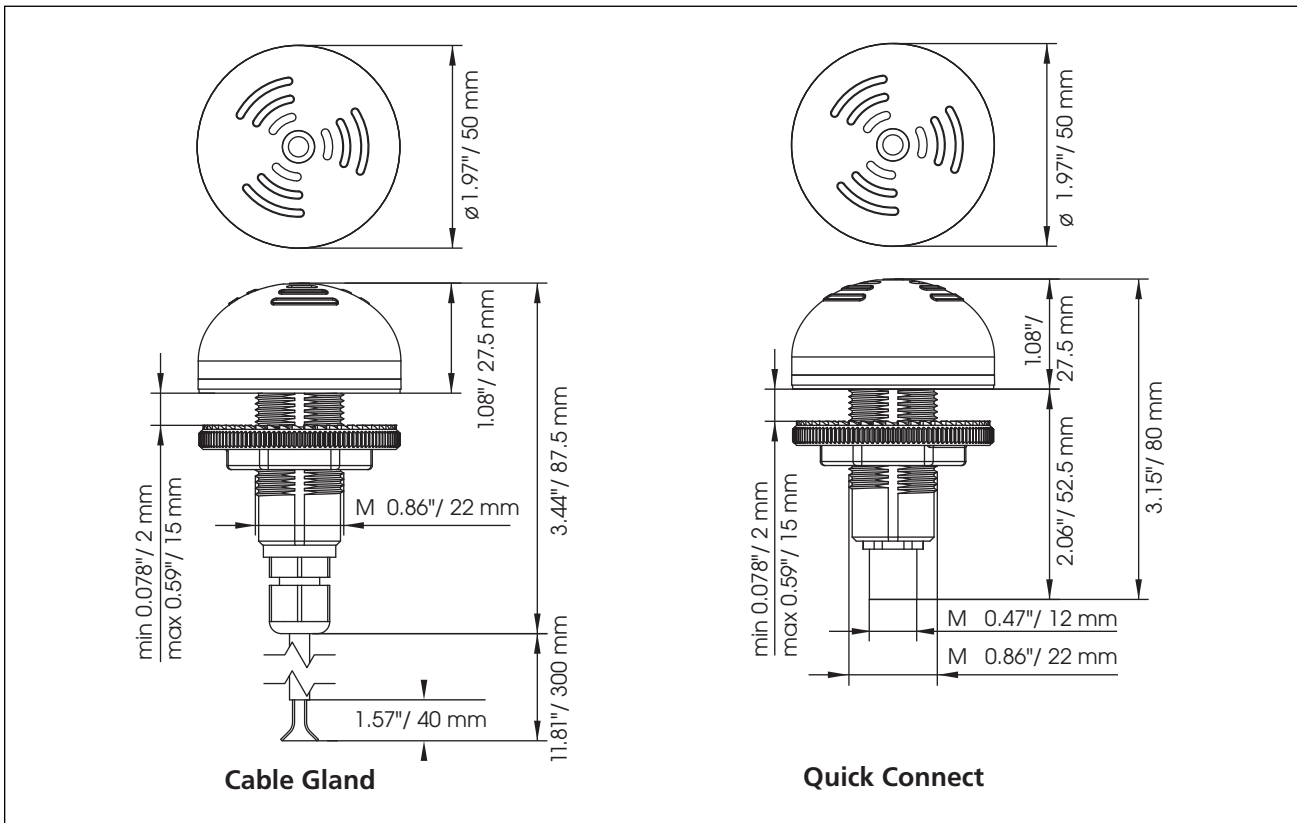

## SPECIFICATIONS

|                        |                |               |
|------------------------|----------------|---------------|
| Lamp Life:             | 50,000 Hours   |               |
| Light Source:          | LED            |               |
| Operating Temperature: | -22°F to 122°F | -30°C to 50°C |
| Net Weight:            | 1.44 oz        | 0.04 kg       |
| Shipping Weight:       | 15.44 oz       | 0.15kg        |

### M12 Cable Gland      M12 Quick Connect

|                       |                  |                  |
|-----------------------|------------------|------------------|
| Diameter              | 1.97"    50.0 mm | 1.97"    50.0 mm |
| Height:               | 3.44"    87.5 mm | 3.15"    80.0 mm |
| Height above surface: | 1.08"    27.5 mm | 1.08"    27.5 mm |

## HOW TO ORDER

