

► Model LP22LED

StreamLine® Low Profile LED Light



Model LP22LED is a unique, multi-pattern LED light ideal for a variety of industrial applications requiring low profile signaling. The unit can be flush mounted or mounted on a 1/2" NPT pipe with the integrated pipe mount. The enclosure consists of a polycarbonate dome in five colors (Amber, Blue, Clear, Green and Red) and is rated Type 4X.

The LP22LED has four flash patterns (steady light, single flash, double flash and triple flash) selectable via dip-switch.

FEATURES


- Available in 12-24V AC/DC and 90-240VAC
- 1/2" NPT or flush mount
- Four flash patterns
- Five lamp/lens colors: Amber, Blue, Clear, Green and Red
- IP65, NEMA Type 4X enclosure
- Low profile — only 2.71" tall x 2.99" diameter (69mm x 76mm)
- UL and cUL Listed and CE Compliant

MODEL	VOLTAGE	FLASH RATE/MINUTE			
		STEADY	SINGLE FLASH	DOUBLE FLASH	TRIPLE FLASH
LP22LED-012-024*	12-24VAC/DC	N/A	120 (+/-10)	90 (+/-10)	140 (+/-10)
LP22LED-090-240*	90-240VAC	N/A	120 (+/-10)	90 (+/-10)	140 (+/-10)

* Indicates color: (A) Amber, (B) Blue, (C) Clear, (G) Green or (R) Red

MODEL	MAXIMUM OPERATING CURRENT (mA)			
	12VAC/DC	24VAC/DC	90VAC	240VAC
LP22LED-012-024*	180	180	N/A	N/A
LP22LED-090-240*	N/A	N/A	40	40

StreamLine® Low Profile LED Light (LP22LED)

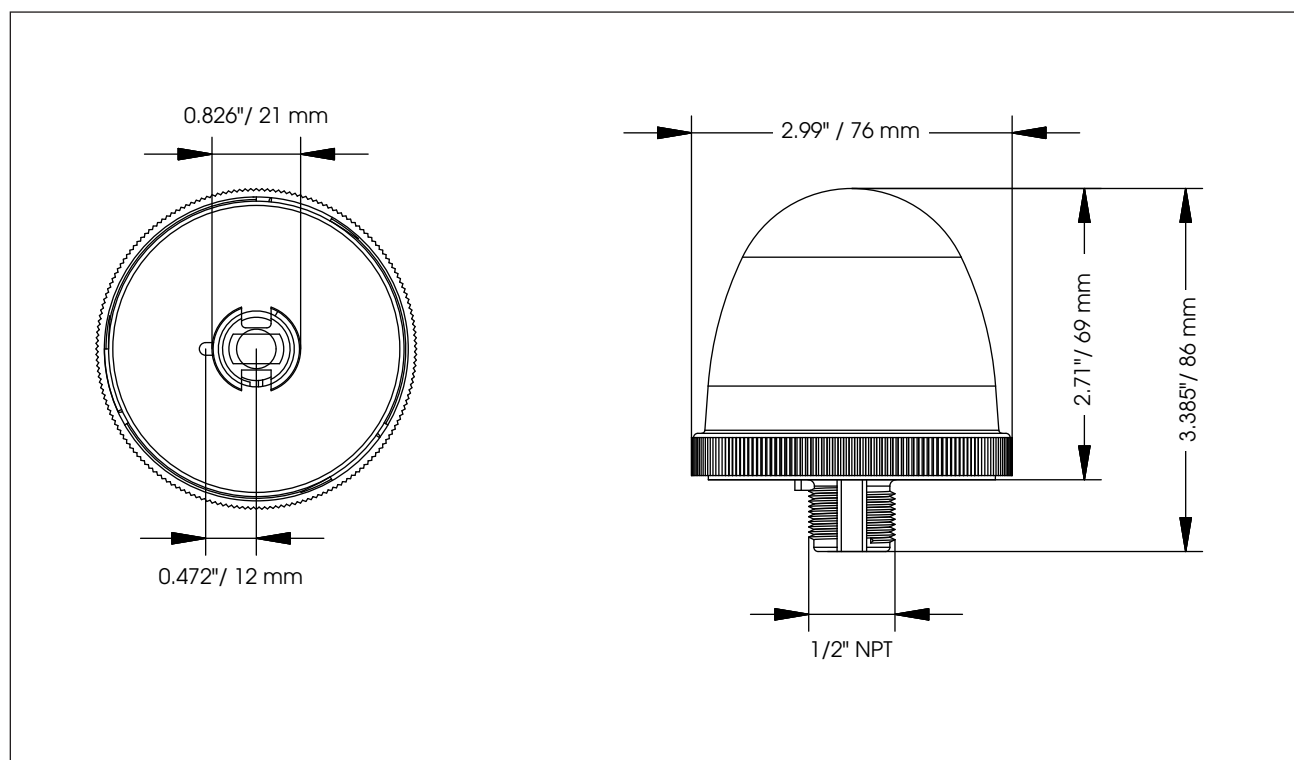

SPECIFICATIONS

Lamp Life:	50,000 Hours	
Light Source:	LED Array	
Operating Temperature Range:	-22°F to 122°F	-30°C to 50°C
Net Weight:	5.29 oz	0.15 kg
Height — above surface:	2.71"	69 mm
Diameter:	2.99"	76 mm

HOW TO ORDER

LP22LED

- 012-024

A

TYPE
 LP22LED

VOLTAGE
012-024 (12-24VAC/DC)
090-240 (90-240VAC)

COLOR
A Amber
B Blue
C Clear
G Green
R Red