



- Models MSLBRCKT, MSLED, MSP, MSS, MSTB

MicroStat® and UniStat® Status Indicator Optional Accessories

A variety of optional equipment is available for the MicroStat® and UniStat® Status Indicators.

MSLBRCKT

Wall mounting the MicroStat or UniStat is simple with this basic bracket.

MSLED

Five plug-in LED's are available for the MicroStat; Amber, Blue, Clear, Green, or Red. The MSLED replaces the lamp in any MSL light module. MSLED modules are UL Listed.

MSP

Some applications require that the status indicators be raised above the machine surface. Using powder coated steel helps improve the visibility of the MicroStat or UniStat. Three different lengths are available; they measure 4-inches (MSP-4), 16-inches (MSP-16) and 32-inches (MSP-32).

MSS

Adding sound to the MicroStat is simple with the plug-in Sound Module. The Sound Module produces 83-85 dBa @ 10 feet. This compact piezo device replaces the lamp in the top position of any MicroStat. A slotted opaque lens protects the sound module circuit and permits the sound to be heard at maximum levels. Adding the sound module to the MicroStat changes the Type rating from 4X to Type 1. Sound modules are available in 24VDC and 120VAC operating voltages.


MSTB

The MicroStat or UniStat base can be pipe-mounted or surface-mounted. When using the pipe extensions, the tulip base is required for a true surface mount.

FLASHERS

Flashers for the MicroStat are available in 24VDC and 120VAC. Each flash at 75 FPM.

MicroStat® and UniStat® Status Indicator Optional Accessories

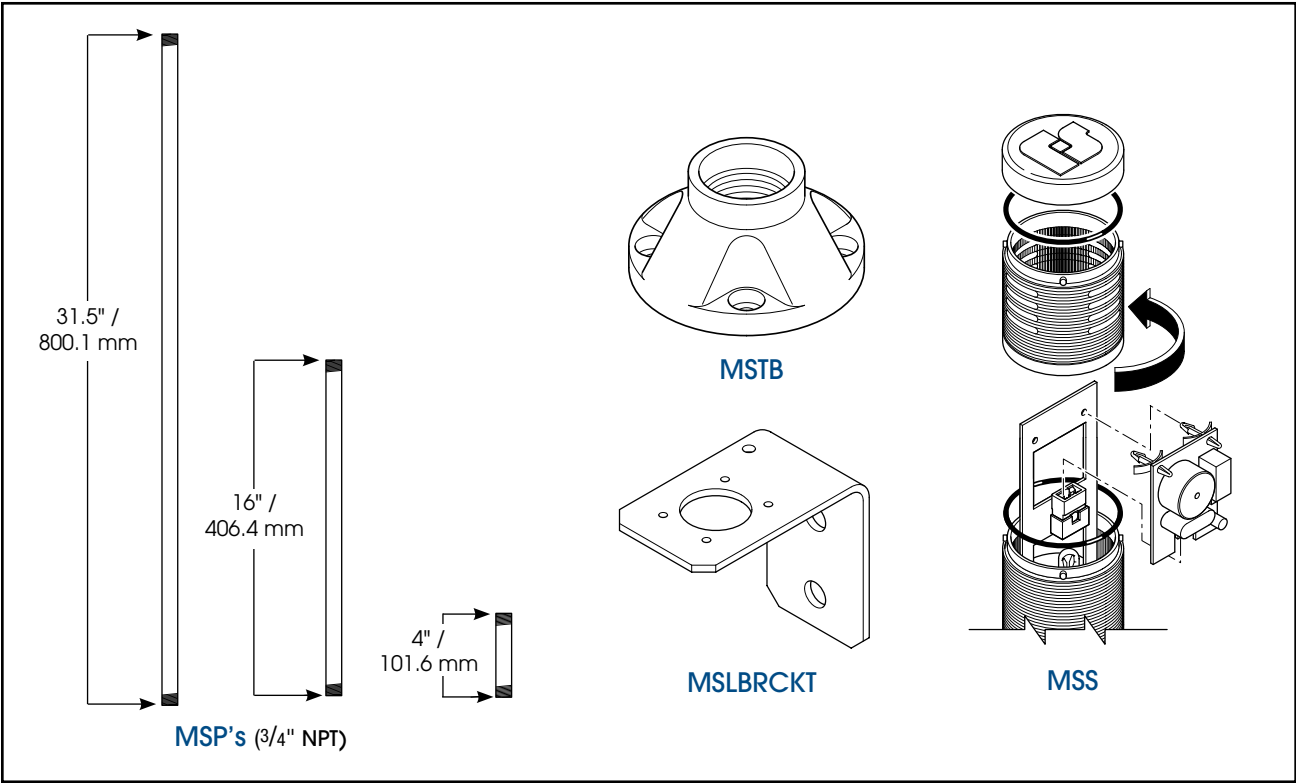

SPECIFICATIONS

MSS

Operating Current:	24VDC	0.03 amps
	120VAC	0.04 amps
dBa Output:	83-85 @ 10'	93-95 @ 1m
Net Weight:	0.25 lbs	0.11 kg
Shipping Weight:	0.75 lbs	0.34 kg
Height:	2.0"	50.8 mm
Diameter:	2.2"	55.9 mm

MSLED

Operating Current:	24VDC	0.095 amps
	120VAC	0.095 amps
Net Weight:	0.05 lbs	0.02 kg
Shipping Weight:	0.55 lbs	0.25 kg
Height:	1.75"	44.45 mm
Width:	1.5"	38.1 mm

MSLBRCKT

Net Weight:	0.4 lbs	0.18 kg
Shipping Weight:	0.9 lbs	0.41 kg
Height:	3.45"	87.63 mm
Width:	2.0"	50.8 mm

MSTB

Net Weight:	0.3 lbs	0.14 kg
Shipping Weight:	0.8 lbs	0.36 kg
Height:	1.5"	38.1 mm
Diameter:	2.75"	68.6 mm

HOW TO ORDER

Description

Part Number

Wall mounting	MSLBRCKT
LED Lamp, Amber	MSLED-A
LED Lamp, Blue	MSLED-B
LED Lamp, Clear	MSLED-C
LED Lamp, Green	MSLED-G
LED Lamp, Red	MSLED-R
3/4" NPT Pipe Extension	
4"	MSP-4
16"	MSP-16
32"	MSP-32
Sound Module	
24VDC	MSS-024
120VAC	MSS-120
Pipe/Surface Mount Base	MSTB

REPLACEMENT PARTS

Description

Part Number

Flasher, 24VDC	K8285237A
Flasher, 120VAC	K8285239A