



► Model PM22C RGB

# Panel Mount 22mm Multifunctional Audible/Visual Multicolor LED Combination

Model PM22C RGB is a steady, multicolor panel mount LED and piezoelectric sounder combination. The model offers seven color options combined with a continuous tone, within the same unit.

Model PM22C RGB is available in 24VDC and two electrical connection options: M12 Cable Gland with 12" (300 mm) leads or M12 4-Pin Quick Connect (-Q). It is panel mounted through a 22 mm/0.87" hole and secured with the provided locking ring.

The PM22 Series offers a self-extinguishing polycarbonate body that protects against vibrations, dust and other atmospheric elements.


## FEATURES

- Available in 24VDC
- Multicolor LED produces Blue, Clear, Cyan, Green, Magenta, Red and Yellow
- Steady light effect and continuous tone combination
- Choice of M12 cable gland or M12 4-pin quick connect (-Q models) electrical connections
- 50,000 hour LED
- Opaque polycarbonate lens
- Type 3R, IP65 enclosure
- CE and UKCA compliant
- UL and cUL listed

MODEL	VOLTAGE	FLASH RATE/MINUTE (FLASH MODE)	DECIBELS MAXIMUM		MAXIMUM OPERATING CURRENT (mA)
			10'	1 M	
<b>PM22C-024RGB*</b>	24VDC	Steady	75	85	80

\* Indicates electrical connection: (-Q) Quick Connect (leave blank for M12 cable gland)

# Panel Mount 22mm Multifunctional Audible/Visual Multicolor LED Combination (PM22C RGB)

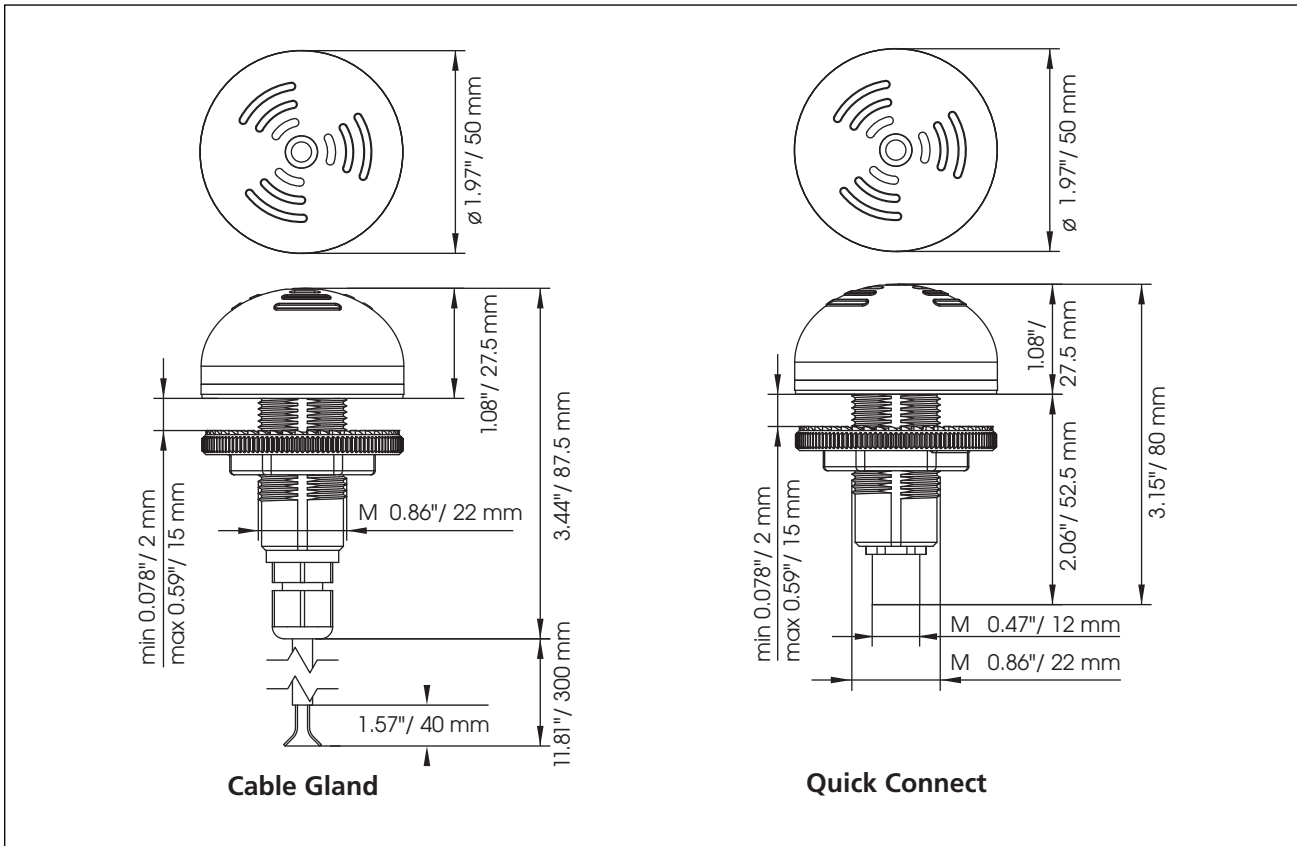

## SPECIFICATIONS

Lamp Life:	50,000 Hours	
Light Source:	LED	
Operating Temperature:	-22°F to 122°F	-30°C to 50°C
Net Weight:	1.44 oz	0.04 kg
Shipping Weight:	15.44 oz	0.15kg
	<b>M12 Cable Gland</b>	<b>M12 Quick Connect</b>
Diameter	1.97" 50.0 mm	1.97" 50.0 mm
Height:	3.44" 87.5 mm	3.15" 80.0 mm
Height above surface:	1.08" 27.5 mm	1.08" 27.5 mm

## HOW TO ORDER

### Specify Model:

**PM22C-024RGB** - Panel Mount 22 mm, Audible/Visual Multicolor LED, M12 Cable Gland

**PM22C-024RGB-Q** - Panel Mount 22 mm, Audible/Visual Multicolor LED, M12 Quick Connect