

TECHNICAL DATA

VPS220-R – Voltage Probe Set, 100:1, one red



Product overview: VPS220-R – Voltage Probe Set, 100:1, one red

Double insulated voltage probe for ScopeMeter 190 series.

Each probe set includes:

- 600 V CAT III / 1000 V CAT II rated 100:1 Voltage Probe
- Hook Clip for Probe Tip
- Ground Lead with Mini Alligator
- Insulation Sleeve
- 30 V CAT II rated Ground Spring for Probe Tip


Specification:

- Attenuation: 100:1
- Bandwidth: 200 MHz
- Max. Input Voltage 1000 V CAT II or 600 V CAT III
- Max. Voltage to ground: 1000 V CAT II or 600 V CAT III per IEC / EN61010-031
- Input Resistance: 100 M Ω
- Input Capacitance: 4.6 pF
- Compensation range: 10 to 25 pF
- Cable Length: 1.2 m

Specifications: VPS220-R – Voltage Probe Set, 100:1, one red

Specification	
Attenuation	100:1
Bandwidth	200 MHz
Max. input voltage	1000 V CAT II or 600 V CAT III
Max. voltage to ground	1000 V CAT II or 600 V CAT III per IEC / EN61010-031
Input resistance	100 MΩ
Input capacitance	4.6 pF
Compensation range	10 to 25 pF
Cable length	1.2 m

Ordering information

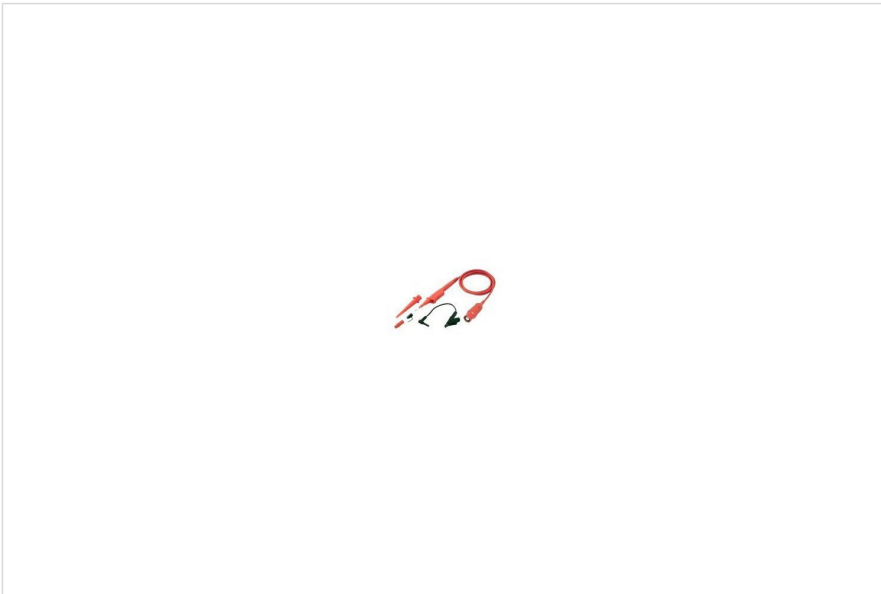

Fluke VPS220-R

Voltage Probe Set, 100:1, One Red

Each probe set includes:

- 600 V CAT III / 1000 V CAT II rated 100:1 voltage probe
 - Hook clip for probe tip
 - Ground lead with mini alligator
 - Insulation sleeve
 - 30 V CAT II rated ground spring for probe tip
-

Fluke. *Keeping your world up and running.®*

Fluke Corporation
PO Box 9090, Everett, WA 98206 U.S.A.

For more information call:
In the U.S.A. (800) 443-5853
In Canada (800) 36-FLUKE
From other countries +1 (425) 446-5500
www.fluke.com

©2022 Fluke Corporation.
Specifications subject to change without notice.
09/2022

**Modification of this document is not permitted
without written permission from Fluke Corporation.**