


Molded Case Circuit Breakers

Spectra™ RMS

Section 6

SK 1200 Frame
 300-1200A Circuit Breakers
 Electronic Trip, Digital, Solid-State
 Suitable for Reverse Feed
 UL File E-11592, CSA LR 40350

Product Number Structure

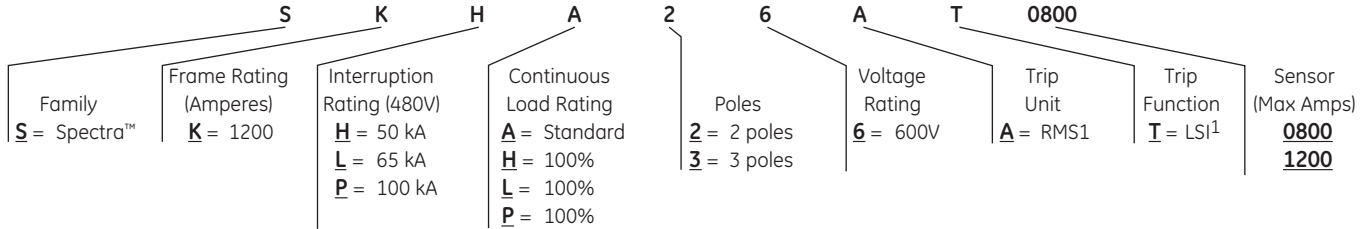

¹Adjustable Instantaneous with Tracking Short Time (Long Time established via Interchangeable Rating Plugs).
 Note: This information is provided for interpreting product numbers (it should not be used to build product numbers).

SKH, SKL, SKP; 800A, 600 Vac Max., (IEC 947-2:800A 690 Vac Max.)

Rating Plug				Frame					Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	Current Sensor	Poles	UL 489 IC @ 480 Vac			Product Number	Wire Range
	Low	High				50kA Product Number	65kA Product Number	100kA Product Number		
300	940	3015	SRPK800A300	800	2	SKHA26AT0800	SKLA26AT0800	SKPA26AT0800	TCAL81	(3) 3/0-500 Cu
400	1255	4015	SRPK800A400							
500	1570	5020	SRPK800A500							
600	1875	6195	SRPK800A600							
700	2155	7420	SRPK800A700							
800	2440	8705	SRPK800A800		3	SKHA36AT0800	SKLA36AT0800	SKPA36AT0800		

SKH, SKL, SKP; 1200A, 600 Vac Max., (IEC 947-2: 1250A, 690 Vac Max.)

Rating Plug				Frame					Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	Current Sensor	Poles	UL 489 IC @ 480 Vac			Product Number	Wire Range
	Low	High				50kA Product Number	65kA Product Number	100kA Product Number		
600	1825	6110	SRPK1200A600	1200	2	SKHA26AT1200	SKLA26AT1200	SKPA26AT1200	TCAL125	(4) 250-500 Cu
700	2125	7125	SRPK1200A700							
800	2430	8145	SRPK1200A800							
900	2735	9160	SRPK1200A900							
1000	3040	10180	SRPK1200A1000							
1175	3574	11961	SRPK1200A1175		3	SKHA36AT1200	SKLA36AT1200	SKPA36AT1200		
1200	3650	12215	SRPK1200A1200							

Note: All Spectra™ breakers UL listed as HACR type.
 All Spectra™ breakers marked CE.

