


# Reduced Voltage Starters

## Solid State

### ASTAT XT Soft Starter

## Section 2

### Product Number Configuration

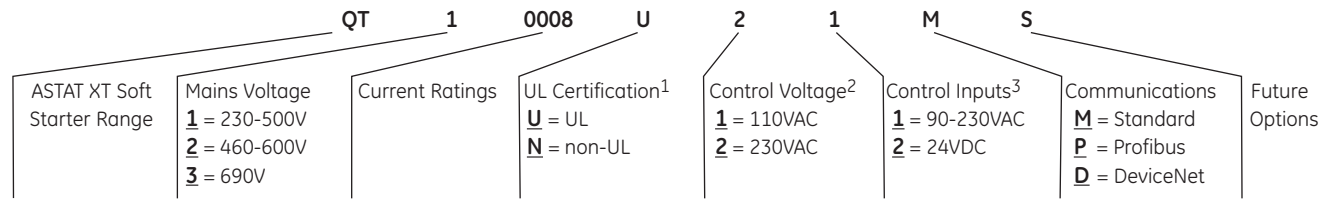

#### Notes:

cUL Certification

<sup>1</sup>ASTAT XT Soft Starter up to 600V, and up to 170A (Product Numbers up to QT10170\_ or QT2) are always cUL certified. Option "N" not available.  
 Units QT2, from QT20008\_ up to QT20820\_ are always cUL certified. Option "N" not available.  
 Units QT1, or QT2 from QTx0950\_ up to QTx1400 are not UL certified. Option "U" not available.  
 Units QT3\_, rated to 690V, are not UL certified. Option "U" not available

Control and Inputs Voltage

<sup>2</sup>ASTAT XT Soft Starter standard Control Voltage is option 2, Voltage 230VAC, +10%, -15%

<sup>3</sup>ASTAT XT Soft Starter standard configuration for Inputs is option 1, Voltage 90-230VAC, +10%, -15%

All ASTAT XT Soft Starter models rated 950A and up **must** be operated with a bypass contactor.

