




## Heavy-Duty Cable Ties

Heavy-duty design offers 120 and 175 lbs of tensile strength.

- Patented DoubleLock® design (on 120 lb) ensures 50% greater tensile strength.
- Ultraviolet black (UVB) ties resist harmful light rays – primarily for outdoor use.

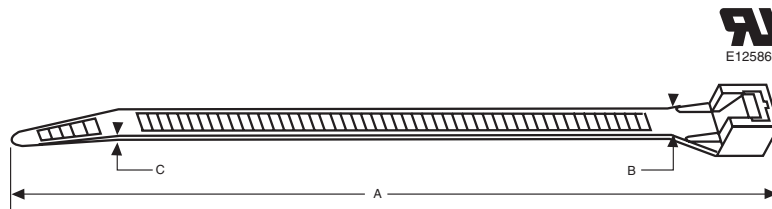

Length	Color	Part #	Pkg Qty	DoubleLock®	Tensile Strength	Length A	Width B	Thickness C	Bundle Dia. Max.	UL
8"	Natural	46-408	100/bag	DLOCK	120 lb	8.00"	0.25"	.072"	2"	UR
	UVB	46-408UVB	100/bag	DLOCK	120 lb	8.00"	0.25"	.072"	2"	UR
12"	Natural	46-412	100/bag	DLOCK	120 lb	12.00"	0.25"	.072"	3"	UR
	UVB	46-412UVB	100/bag	DLOCK	120 lb	12.00"	0.25"	.072"	3"	UR
15"	Natural	45-515	10/bag	DLOCK	120 lb	15.00"	0.25"	.072"	4"	UR
	Natural	46-415	50/bag	DLOCK	120 lb	15.00"	0.25"	.072"	4"	UR
	UVB	45-515UVB	10/bag	DLOCK	120 lb	15.00"	0.25"	.072"	4"	UR
	UVB	46-415UVB	50/bag	DLOCK	120 lb	15.00"	0.25"	.072"	4"	UR
17"	Natural	45-518N	10/bag	—	175 lb	17.00"	0.35"	.07"	4.90"	UR
	Natural	46-418	50/bag	—	175 lb	16.93"	0.35"	.07"	4.90"	UR
	UVB	45-518UVBN	10/bag	—	175 lb	16.93"	0.35"	.07"	4.90"	UR
	UVB	46-418UVB	50/bag	—	175 lb	17.00"	0.35"	.07"	4.90"	UR
21"	Natural	45-521	10/bag	—	175 lb	20.70"	0.35"	.07"	5.5"	UR
	Natural	46-421	50/bag	—	175 lb	20.78"	0.35"	.07"	5.51"	UR
	UVB	45-521UVB	10/bag	—	175 lb	20.78"	0.35"	.07"	5.51"	UR
	UVB	46-421UVB	50/bag	—	175 lb	20.70"	0.35"	.07"	5.5"	UR
24"	Natural	45-524	10/bag	—	175 lb	23.97"	0.35"	.07"	7"	UR
	Natural	46-424	50/bag	—	175 lb	23.97"	0.35"	.07"	7"	UR
	UVB	45-524UVB	10/bag	—	175 lb	23.97"	0.35"	.07"	7"	UR
	UVB	46-424UVB	50/bag	—	175 lb	23.97"	0.35"	.07"	7"	UR
30"	Natural	46-330	25/bag	—	175 lb	30.50"	0.35"	.07"	9"	UR
	UVB	46-330UVB	25/bag	—	175 lb	30.50"	0.35"	.07"	9"	UR
36"	Natural	45-536	10/bag	—	175 lb	35.91"	0.35"	.07"	10.30"	UR
	Natural	46-436	50/bag	—	175 lb	35.91"	0.35"	.07"	10.30"	UR
	UVB	45-536UVB	10/bag	—	175 lb	35.91"	0.35"	.07"	10.30"	UR
	UVB	46-436UVB	50/bag	—	175 lb	35.91"	0.35"	.07"	10.30"	UR
48"	Natural	45-548	10/bag	—	175 lb	48.00"	0.35"	.07"	14.30"	UR
	Natural	46-448	50/bag	—	175 lb	48.00"	0.35"	.07"	14.30"	UR
	UVB	45-548UVB	10/bag	—	175 lb	48.00"	0.35"	.07"	14.30"	UR
	UVB	46-448UVB	50/bag	—	175 lb	48.00"	0.35"	.07"	14.30"	UR