


IMPROVED Ultra Eegor™ Hydraulic Bender

Bends 2½" to 4" conduit:

- Rigid
- Rigid aluminum (schedule 40 max)
- EMT
- IMC

No additional attachment sets required to change per pipe or conduit type.

- 30 ton, 28" stroke cylinder can make a 90° bend with one pass.
- Double-acting cylinder for rapid retraction, regardless of hose lengths and system losses.
- Improved shoes and follow bars to reduce conduit kinking during bending.
- Hydraulic power ensures the smoothest bends without deformations to the conduit.
- Constant radii follow bars eliminate the need for special calculations.
- Conduit is automatically stripped free from the shoe during the return cycle-which ensures no extra labor or damaged conduit.
- Angle markings on frame ensure easy and accurate bending.

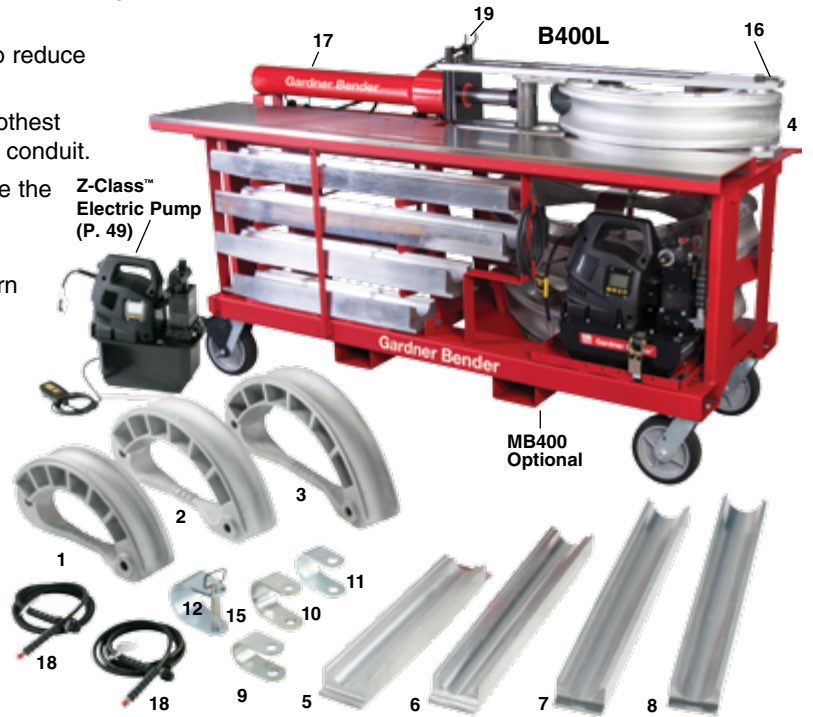

Centerline Radius Chart:

Nominal Size	IMC	EMT	Rigid
2½"	13½"	13½"	13½"
3"	15⅞"	15⅞"	15⅞"
3½"	18½"	18½"	18½"
4"	21"	21"	21"

B400L with BE400 Table, CS400Cylinder Support & Z-Class™ Pump

SEE PG
49



FOR MORE INFO ON
Electric Pumps

tip:

*To convert older B400 or B400D to Long-stroke Cylinder, use CD3028KT Kit, which includes Long-stroke Cylinder, CS400 Cylinder Support and DC404 Decal.

Part #	Description	Pump	Weight
B400L	Long-stroke Ultra Eegor™	—	770 lbs
B400LP408S	Long-stroke Ultra Eegor™	P408S Electric	870 lbs
B400DL	Long-stroke Ultra Eegor™ w/o 3½" shoe group	—	770 lbs
B400DLP408S	Long-stroke Ultra Eegor™ w/o 3½" shoe group	P408S Electric	795 lbs
CD3028KT*	Eegor® Conversion Kit, 28" Stroke Cylinder		105 lbs
ZDC404	Bend Angle Decal		1 lb

Components Included with the Long-stroke Ultra Eegor™ Bender

Part #	Conduit	Description	Weight	I.D. #	Part #	Conduit	Description	Weight	I.D. #
BS2500	2½"	Bending Shoe	44 lbs	1	BZ34	3"	U-strap	5 lbs	10
BS3000	3"	Bending Shoe	50 lbs	2	BZ39*	3½"	U-strap	8 lbs	11
BS3500	3½"	Bending Shoe	75 lbs	3	BZ44	4"	U-strap	10 lbs	12
BS4000	4"	Bending Shoe	90 lbs	4	BZ76	-	U-strap Pin	4 lbs	15
BFB2500	2½"	Follow Bar	34 lbs	5	BZ78	-	Bend Shoe Pin	4 lbs	16
BFB3000	3"	Follow Bar	35 lbs	6	ZCD3028	-	30-Ton, Double-Acting Hyd. Cyl.	95 lbs	17
BFB3500	3½"	Follow Bar	42 lbs	7	HC927	-	(2) 10' Hose w/High-Flow Coupler	4 lbs	18
BFB4000	4"	Follow Bar	40 lbs	8	BZ74	-	Double Anchor Frame Pin	66 lbs	19
BZ28	2½"	U-strap	5 lbs	9	CM20	-	Metal Case for Ultra Eegor™	182 lbs	-

*These parts are not included with B400DL and B400DLP408S.