

# Crimp Connectors


Use GB® crimp connectors for strong, vibration-resistant permanent connections in branch circuit and fixture wiring.

- Two styles and sizes available.
- Copper or zinc-plated steel.



## Copper

| Part #  | Model | Pkg Qty  | Wire Range    | Min   | Max           |
|---------|-------|----------|---------------|-------|---------------|
| 10-310C | 310   | 100/clam | #18 - #10 AWG | 2 #16 | 2 #10 w/1 #12 |
| 10-311C | 311   | 50/clam  | #14 - #8 AWG  | 3 #12 | 4 #10         |

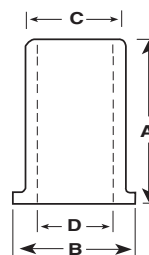

Dimensions

| Model   | A    | B      | C      | D      |
|---------|------|--------|--------|--------|
| 310/410 | 3/8" | 19/64" | 1/4"   | 13/64" |
| 311/411 | 5/8" | 23/64" | 21/64" | 17/64" |


## Zinc-plated Steel

| Part #  | Model | Pkg Qty  | Wire Range    | Min   | Max           |
|---------|-------|----------|---------------|-------|---------------|
| 10-410  | 410   | 100/box  | #18 - #10 AWG | 2 #16 | 2 #10 w/1 #12 |
| 10-410C | 410   | 100/clam |               |       |               |
| 13-410  | 410   | 500/bag  |               |       |               |
| 20-410  | 410   | 12/clam  |               |       |               |
| 10-411  | 411   | 50/box   | #14 - #8 AWG  | 3 #12 | 4 #10         |
| 10-411C | 411   | 50/clam  |               |       |               |
| 20-411  | 411   | 8/clam   |               |       |               |

# Copper Split Bolt Connectors

All-copper alloy construction for high mechanical strength, maximum conductivity and low resistance.

- Accept a wide range of solid and stranded conductors from 16 AWG – 3/0 AWG.
- Can be torqued with standard wrenches.

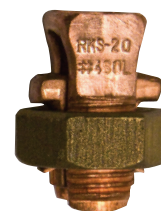


| Part # | Pkg Qty | Wire Gauge                                 |
|--------|---------|--------------------------------------------|
| GSBC-8 | 2/clam  | #16 - #10 AWG Stranded, #16 - #8 AWG Solid |
| GSBC-6 | 2/clam  | #10 AWG Stranded, #10 - #8 AWG Solid       |
| GSBC-4 | 2/clam  | #8 - #4 AWG Solid                          |
| GSBC-2 | 2/clam  | #6 - #2 AWG Solid                          |

| Part #   | Pkg Qty | Wire Gauge          |
|----------|---------|---------------------|
| GSBC-1/0 | 1/clam  | #4 - #0 AWG Solid   |
| GSBC-2/0 | 1/clam  | #2 - #00 AWG Solid  |
| GSBC-3/0 | 1/clam  | #2 - #000 AWG Solid |

# Aluminum Split Bolt Connectors

Constructed of high-strength aluminum with oxide-displacing jaws to prevent galvanic corrosion.

- Accept conductors from 10 AWG – 4/0 AWG.
- Use GB® OX-GARD™ anti-oxidant treatment on Al-Al and Al-Cu to prevent corrosion and permit cooler connections.

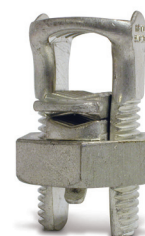

| Part #  | Pkg Qty | Wire Gauge                            |
|---------|---------|---------------------------------------|
| GAK-2   | 1/clam  | #8 - #2 AWG Solid                     |
| GAK-1/0 | 1/clam  | #8 - #0 AWG Solid                     |
| GAK-2/0 | 1/clam  | #10 AWG Stranded, #10 - #00 AWG Solid |
| GAK-4/0 | 1/clam  | #6 - #0000 AWG Solid                  |