

48x48x99 faceplate version

Universal Versions

40A 48




AC CURRENT/VOLTAGE INDICATOR - ALARM UNIT

AC current and voltage indicator and alarm unit, 4-digit display, microprocessor-based, configurable from faceplate keys and from PC.

- **Inputs: VAC, AAC**
- **Faceplate protection: IP65**
- **Alarms: 2 (configurable)**



CE UL

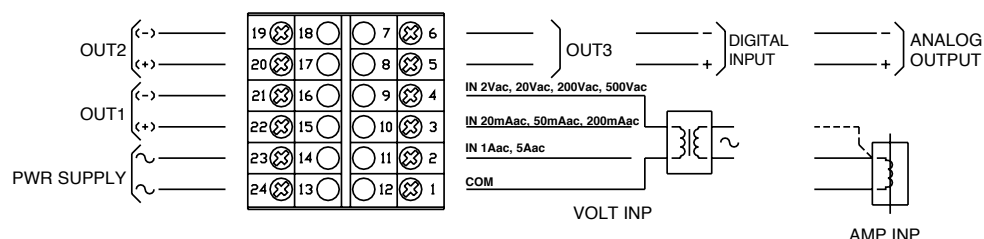

Power supply	Order code	SAP/METEL code
11..27Vac/Vdc	40A-48-4-00-RR-0-0-0	F000213
100..240Vac/Vdc	40A-48-4-00-RR-0-0-1	F000213

48x48x99 faceplate version

Universal Versions

40B 48




POSITION, FORCE AND PRESSURE INDICATOR - ALARM UNIT WITH INPUT FOR STRAIN-GAUGE AND POTENTIOMETER

Indicator - alarm unit for load cells, strain-gauge pressure transducers and potentiometers, microprocessor-based, configurable from faceplate keys and from PC.

- **Inputs: Strain Gauge and potentiometer**
- **Retransmitted output**
- **Faceplate protection: IP65**
- **Alarms: 2 (configurable)**
- **Power supply for external sensor**



CE UL

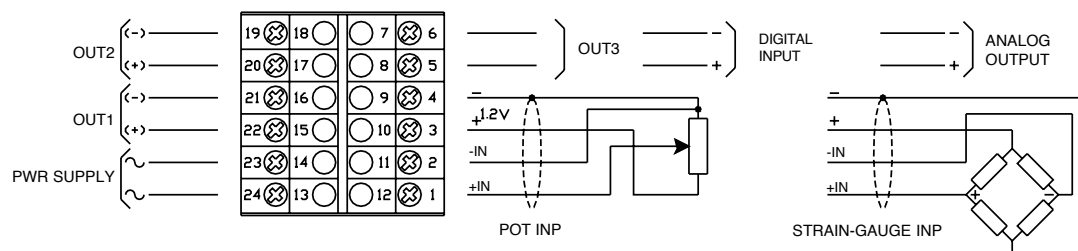

Outputs	Special functions	Power supply	Order code	SAP/METEL code
2 relays	Transm. power supply 10 Vdc	11..27Vac/Vdc	40B-48-4-10-RR-0-0-0	F000996
2 relays	Transm. power supply 10 Vdc	100..240Vac/Vdc	40B-48-4-10-RR-0-0-1	F000206
2 relays+ Analog	Transm. power supply 10 Vdc	11..27Vac/Vdc	40B-48-4-10-RR-0-2-0	F001000
2 relays+ Analog	Transm. power supply 10 Vdc	100..240Vac/Vdc	40B-48-4-10-RR-0-2-1	F001001