


GQ



MONOPHASE SOLID STATE RELAY WITH SCR

Monophase solid state relay for resistive and inductive loads. Zero crossing. Double SCR output in antiparallel. Logic controller in VAC/VDC (20...260 VAC/DC). Signal LEDs. Integrated IP20 cover.

- Control logic input 20-260VAC/DC
- Faceplate protection: IP20
- Nominal working temperature 40°C
- Internal MOV overvoltage protection

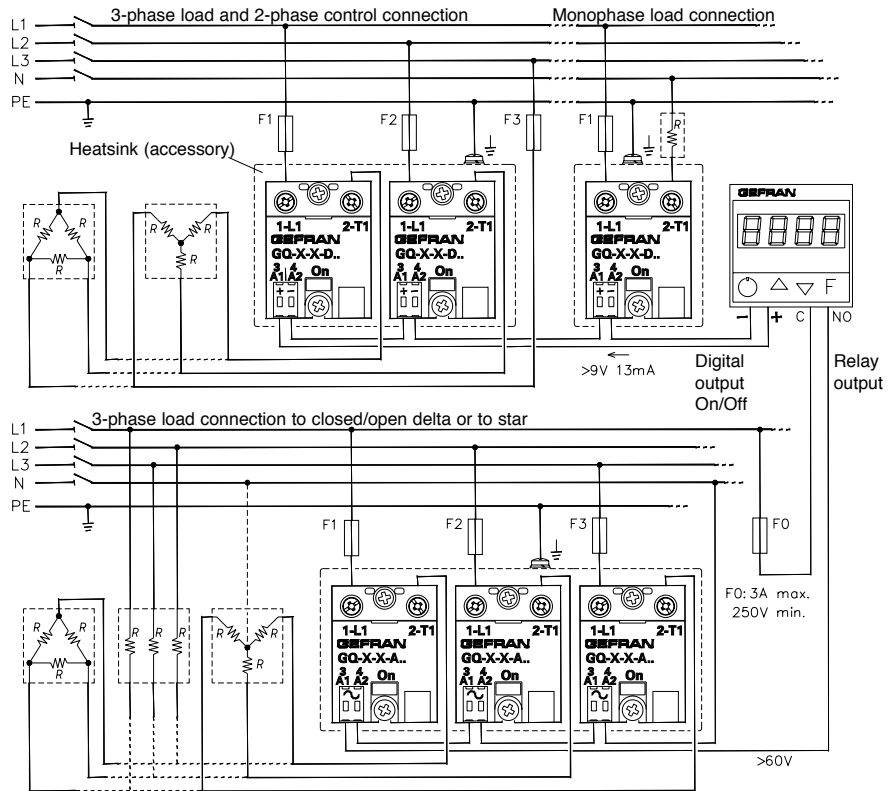

CE UL

Current	Working voltage	Control type	Control	Order code	SAP/METEL code
15 A	Up to 230 Vac	Logic	20...260Vac/Vdc	GQ-15-24-A-1-1 (230V/15A)	F045251
25 A	Up to 230 Vac	Logic	20...260Vac/Vdc	GQ-25-24-A-1-1 (230V/25A)	F040885
25 A	Up to 480 Vac	Logic	20...260Vac/Vdc	GQ-25-48-A-1-1 (480V/25A)	F042271
50 A	Up to 230 Vac	Logic	20...260Vac/Vdc	GQ-50-24-A-1-1 (230/50A)	F040886
50 A	Up to 480 Vac	Logic	20...260Vac/Vdc	GQ-50-48-A-1-1 (480V/50A)	F041187
90 A	Up to 230 Vac	Logic	20...260Vac/Vdc	GQ-90-24-A-1-1 (230V/90A)	F046827
90 A	Up to 480 Vac	Logic	20...260Vac/Vdc	GQ-90-48-A-1-1 (480V/90A)	F041046