




### Main characteristics


- Max. temperature limit: - 40 ... + 400° C
- Reference tolerances: Standards IEC 584.2 class 2:  
for type J, K:  $\pm 2,5^{\circ} C$  (- 40 ... + 333° C)  
 $\pm 0.0075 [t]$  ( $t > + 333^{\circ} C$ )
- Thermoelement with compact isolation and continuous metal sheathing (MgO isolation)
- Cable to DIN standard

### MODELS


#### TCMCP

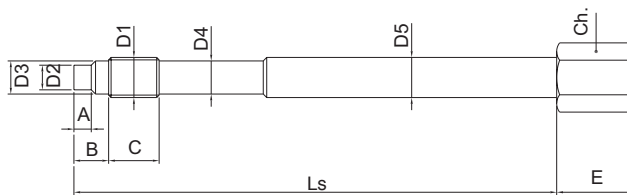


#### TCMCC

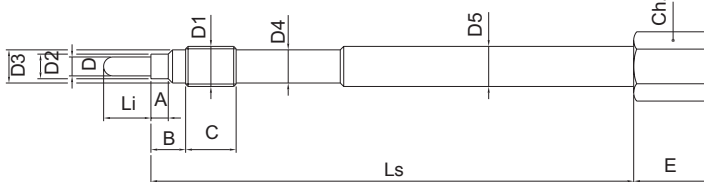

#### TCMCE

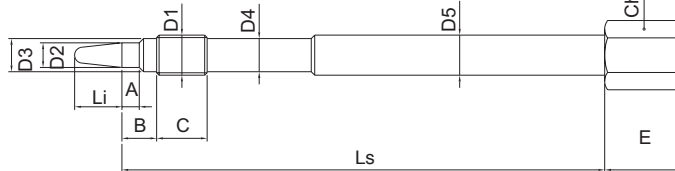

#### TCMGF

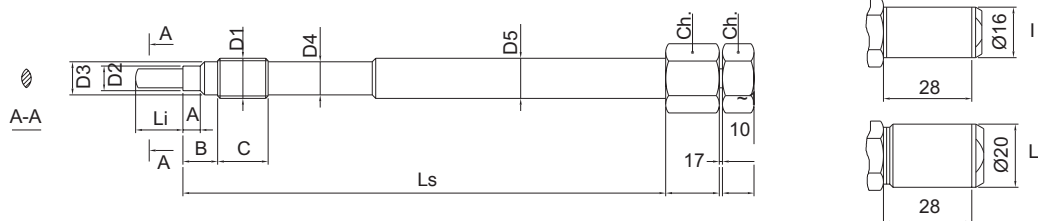

D1	D2	D3	D	D4	D5	A	B	C	Ls	Ch	E	Li
1/2-20UNF	ø 7,8	ø 10,5	ø 6	ø 10,5	ø 12,7	5,5	11	16	90-153	17-19	17-25	Immersion length Immersion length
M18x1,5	ø 10	ø 16	ø 7	ø 16	ø 17,8	6	14	20	90-153	19	17-25	

