





Main features

- Temperature limits: - 40 ... + 250° C
- Tolerance: Norme UNI 7938 standards, IEC 584.2 : class 2: for types J, K: $\pm 2.5^{\circ}$ C
- Extension cable insulation: fibreglass, screened TEFLON®
- Eyelet thermocouple with low thermal profile and quick response time, suitable for measures on flat surfaces
- Cable to DIN standard

MODELS

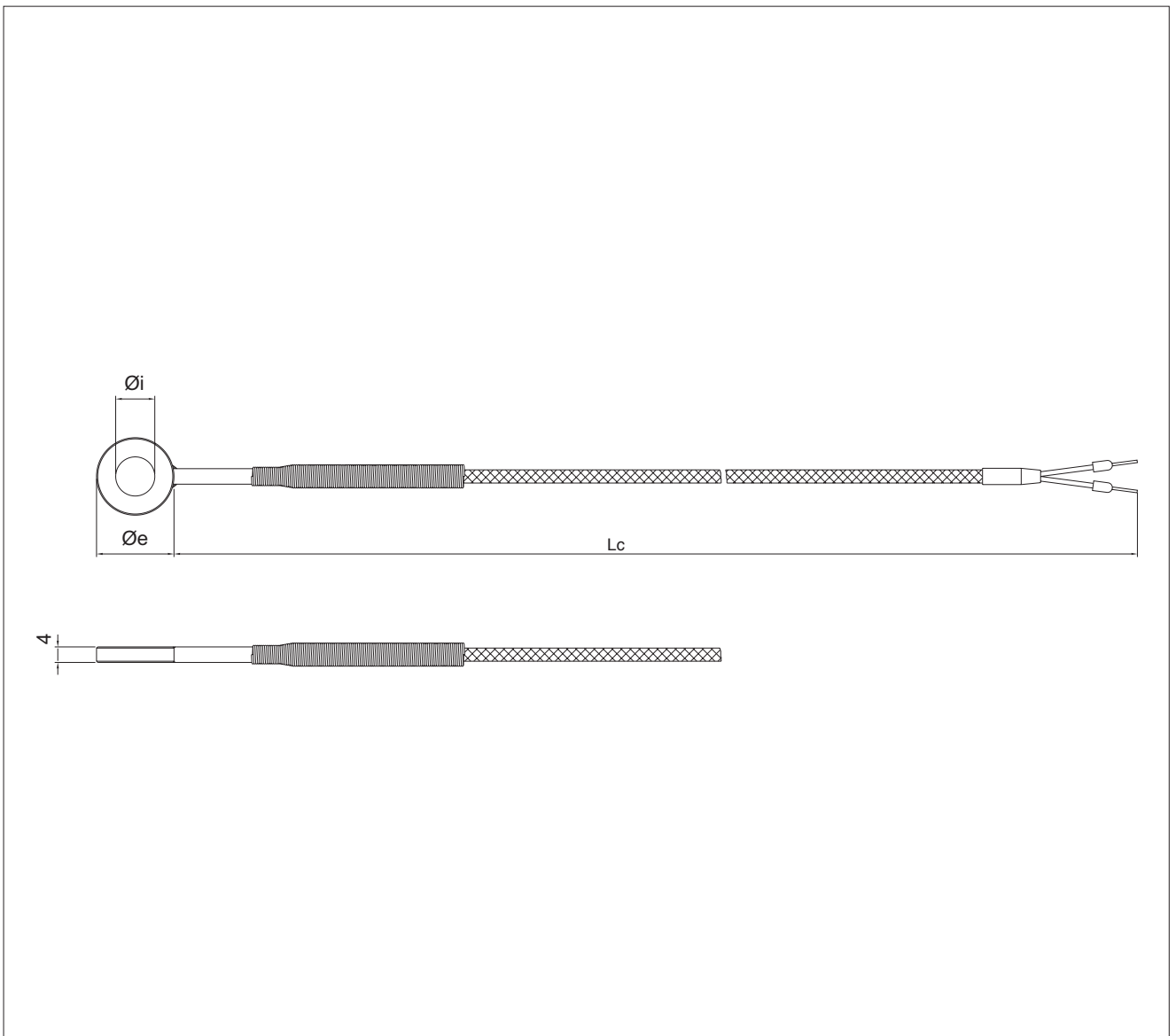

ORDER CODE

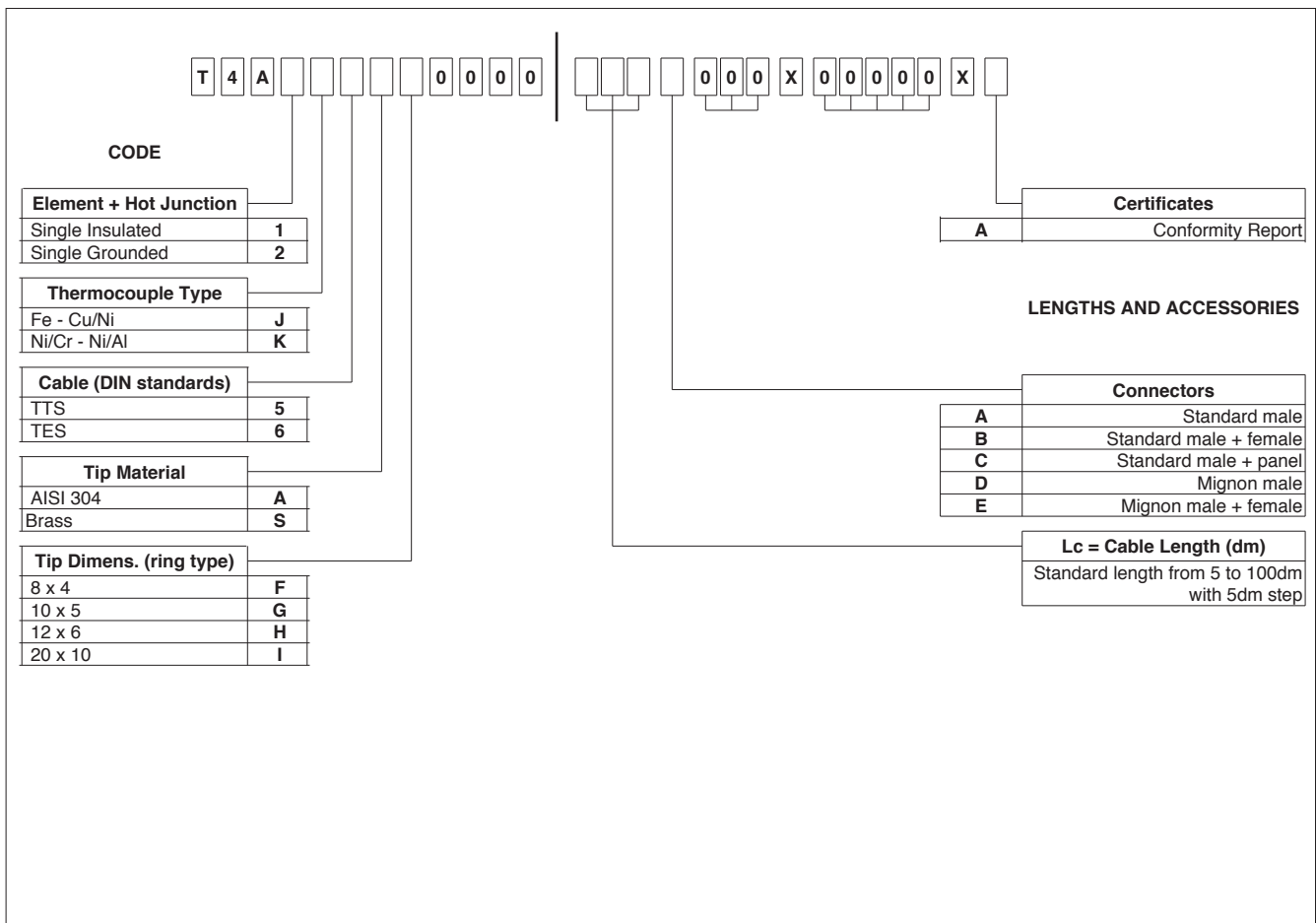

GEFRAN spa reserves the right to make any kind of design or functional modification at any moment without prior notice