


# Part Number: R-3MT-KIT-H

Absence of Voltage Safe-Test Point with Label and Dust Cap, Horizontal Mount



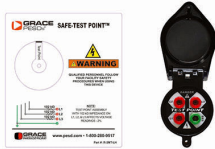

<https://shop.graceport.com/products/r-3mt-kit-h>




## Product Specifications

Component Details	
Part Number	R-3MT-KIT-H
Electrical Specifications	
Operational Voltage Range AC Single or 3-Phase	0-600VAC phase to phase or phase to ground 0-400Hz
Operational Voltage Range DC or Stored Energy	0-1000VDC, any (2) wires line-to-line or line-to-ground (UL Listed to 600VDC)
Storage Temperature Range	-45°C to + 85°C
Operational Temperature Range	-20°C to +55°C
Mechanical Specifications	
Installation	30mm Pushbutton Hole
UL Type	12 &13
Orientation	Horizontal
Geometric Data	
Label Dimensions	4.323"W x 4.60"H
Commercial Data	
Country of Origin	Taiwan
Schedule B Code	8538.90.8160





### Approval Certifications

Logo	Approval	Additional Text	Certificate Name	
	UL Underwriters Laboratories Inc.		E311256	
	CE European Conformity	INGR0516-A-00	SS001-0616-A-CE	

### CAD Files

File Format	
2D PDF File	

### Datasheets

Name	
Safe-Test Point Datasheet	
Safe-Test Point Datasheet Spanish	
Safe-Test Point High Impedance Technical Note	
Safe-Test Point Installation Guide	

### Don't see what you're looking for?

Contact us at [sales@gracetechnologies.com](mailto:sales@gracetechnologies.com), call 1-800-280-9517 or visit [www.graceport.com](http://www.graceport.com) to chat with our customer service.