

WIRE STRIPPING TOOLS



1950-SS



1955-SS



1956-SS



1916-SS



1917-SS

Wire Strippers

- Cutlery grade stainless steel prevents wear and corrosion to provide 5x longer life
- Pliers grab, form and bend wires
- Precision-ground strippers engineered for clean, easy insulation removal
- Double-layered vinyl handles for comfort and slip resistance

Stainless Steel Wire Stripper/Cutter/Crimper

- Bolt threaders clean threads after shearing
- Professional, multi-function tool includes a crimper, looper, non-obstructive lock mechanism, spring return, and high grade shears

CAT. NO.	UPC NO.	DESCRIPTION	SOLID STRIP	STRANDED STRIP	BOLT SHEAR	CRIMP
1950-SS	783310022411	Pro Stainless Wire Stripper / Cutter / Crimper	10-18	12-20	6-32, 8-32	16-10
1955-SS	783310013617	Pro Stainless Wire Stripper / Cutter / Crimper (Curve)	10-18	12-20	6-32, 8-33	16-10
1956-SS	783310022428	Pro Stainless Wire Stripper / Cutter / Crimper (Curve)	6-14	8-16	6-32, 8-34	16-10

Stainless Steel Wire Stripper/Cutter

- Multi-function tool includes a looper, non-obstructive lock mechanism, spring return, and high grade shears

CAT. NO.	UPC NO.	DESCRIPTION	SOLID STRIP	STRANDED STRIP
1916-SS	783310013594	Stainless Wire Stripper / Cutter	10-20	12-22
1917-SS	783310013600	Stainless Wire Stripper / Cutter	16-26	18-28



1927-SS

Stainless Steel Stripper/Crimper

- Multi-functional, professional grade
- Cutlery grade stainless steel prevents wear and corrosion to provide 5x longer life
- Multiple bolt shears and crimpers for a wide range of tests
- Bolt threaders clean threads after shearing
- Precision-ground strippers engineered for clean, easy insulation removal
- Comfort grips are double molded, lightweight and easy to grab
- Includes a looper, non-obstructive lock mechanism, spring return, and high grade knives

CAT. NO.	UPC NO.	DESCRIPTION	SOLID STRIP	STRANDED STRIP	BOLT SHEAR	CRIMP
1927-SS	783310022435	Pro Stainless Combination Tool w/Spring	8-18	10-20	4-40 to 10-24	Multiple



1923A

Crimping/Stripping Combination Tool

- Easily strip both solid and stranded wires, crimp terminals, cut screws and wire
- Precision-ground blades ensure consistent stripping and cutting
- Double-dipped grips for superior comfort and assured grip
- Heat-treated for strength with black oxide finish for rust resistance
- Cleanly cuts and strips 10-22 AWG wire
- 2 wire cutters: middle cuts copper, tip cuts hardened wire
- Cleanly cuts #4-40, #6-32 and #8-32, #10-24, #10-32 screws
- Crimps 10-22 AWG insulated and non-insulated terminals, splices and lugs
- Splices and terminates 7 mm and 8 mm ignition terminals

CAT. NO.	UPC NO.	DESCRIPTION	CAP. AWG	
			SOLID	STRANDED
1923A	783310000846	Crimping/Stripping Combination Tool	8-18	10-22



1935

Automatic Wire Stripper

- Production grade wire stripper strips insulation from most smaller gauge wires
- Strips up to 7/8" (22.2 mm) length
- Strips PVC and THHN insulation
- For use with solid and stranded wire

CAT. NO.	UPC NO.	DESCRIPTION	CAP. AWG
1935	783310376002	Automatic Wire Stripper	10-22 solid and stranded

HAND TOOLS



45000

Kwik Stripper® Wire Stripper

- Strips and cuts flat and round cable
- Self-adjusts to most wire gauges
- Laminated steel blades helps minimize the risk of nicking conductors
- Front entry jaws have an adjustable strip length guide
- Lightweight reinforced nylon is chemical and corrosion resistant

CAT. NO.	UPC NO.	DESCRIPTION	CAP. AWG
45000	783310450009	Kwik Stripper Wire Stripper	10-34 solid and stranded
R 20243	783310202431	Blade Cassette	



0252-11



NM Cable Ripper

- Slits outer jacket of Romex® 10/2, 12/2, 14/2 and other non-metallic (NM) sheathed cable
- Wire gauge on handle for identifying #6 to #14 AWG
- Corrosion-resistant zinc plating
- Side-entry design for end or mid-run slitting of jacket

CAT. NO.	UPC NO.	DESCRIPTION	OVERALL LENGTH
0252-11	783310563006	NM Cable Ripper	3-5/8" (9.2 cm)

MC 1" Flexible Cable/Conduit Cutter

- Use with AC and MC Cable up to 1" outside diameter
- Thumb screw allows for easy adjustment for cable sizes up to 1"
- Cuts in seconds with a few quick turns of the crank and an easy twist of the armor
- Will not nick inner conductors
- Convenient under-handle blade storage holds spare blades
- Quick load clamp system makes repeat cuts fast and easy



0952-01

CAT. NO.	UPC NO.	DESCRIPTION
0952-01	783310020721	Cutter, Cable MC
R 1941-1	783310002888	Single Replacement Blade
R 1941-5	783310337355	5 Pack Replacement Blades

NOTES: See pages 319 – 321 for additional wire and cable stripping tools. See pages 299 – 317 for additional crimping tools.

SCREWDRIVERS



0153-02C

Screwdriver Sets

- Heavy-duty construction for longer life
- Handle marked for easy identification of screwdriver size, type and length
- Precision-machined tips for accurate fastener contact
- Strong, durable black phosphate tips prevent chipping of plating
- High-grade, rust resistant, chrome-plated finish
- Cushion grip handle for extra comfort and torque

7-Piece Screwdriver Set

- Set includes:
 - 3/16" x 4" Cabinet
 - 3/16" x 6" Cabinet
 - 1/4" x 4" Keystone
 - 1/4" x 4" Cabinet
 - 5/16" x 6" Keystone
 - #1 x 3" Phillips
 - #2 x 4" Phillips

CAT. NO.	UPC NO.	DESCRIPTION
0153-02C	783310546610	7-Piece Screwdriver Set



0153-01C

5-Piece Screwdriver Set

- Set includes:
 - 3/16" x 6" Cabinet
 - 1/4" x 4" Keystone
 - 1/4" x 6" Cabinet
 - 5/16" x 6" Keystone
 - #2 x 4" Phillips

CAT. NO.	UPC NO.	DESCRIPTION
0153-01C	783310563037	5-Piece Screwdriver Set



0153-03C

Mini Screwdriver Set

- Set includes:
 - #0 Phillips
 - 1/16" Keystone
 - 3/32" Cabinet
 - 1/8" Cabinet

CAT. NO.	UPC NO.	DESCRIPTION
0153-03C	783310134381	4-Piece Mini Screwdriver Set (Round Shank)



0153-14C

Heavy-Duty Keystone Tip Screwdrivers

- Square shank allows use of wrench or pliers for added torque
- Handle marked for easy identification of screwdriver size, type and length
- Rugged keystone tip for additional strength
- Precision-machined tips for accurate fastener contact
- Strong, durable black-phosphate tips prevent chipping of plating
- Cushion grip handle for extra comfort and torque
- Meets ASME/ANSI specifications

CAT. NO.	UPC NO.	DESCRIPTION
0153-11C	783310546443	Square Shank 1/4" x 4" Flat Blade Screwdriver
0153-12C	783310546450	Square Shank 1/4" x 6" Flat Blade Screwdriver
0153-13C	783310546467	Square Shank 1/4" x 8" Flat Blade Screwdriver
0153-14C	783310546474	Square Shank 1/4" x 10" Flat Blade Screwdriver
0153-15C	783310563044	Square Shank 5/16" x 6" Flat Blade Screwdriver
0153-16C	783310563051	Square Shank 3/8" x 8" Flat Blade Screwdriver



0153-21C

Cabinet Tip Screwdrivers

- Narrow cabinet tip for limited access applications
- Handle marked for easy identification of screwdriver size, type and length
- Precision-machined tips for accurate fastener contact
- Strong, durable black-phosphate tips prevent chipping of plating
- Cushion grip handle for extra comfort and torque
- Meets ASME/ANSI specifications

CAT. NO.	UPC NO.	DESCRIPTION
0153-21C	783310546528	Round Shank 3/16" x 4" Flat Blade Screwdriver
0153-22C	783310546535	Round Shank 3/16" x 6" Flat Blade Screwdriver
0153-23C	783310546542	Round Shank 3/16" x 8" Flat Blade Screwdriver
0153-24C	783310546559	Round Shank 3/16" x 10" Flat Blade Screwdriver
0153-25C	783310546498	Round Shank 1/4" x 4" Flat Blade Screwdriver
0153-26C	783310546504	Round Shank 1/4" x 6" Flat Blade Screwdriver
0153-27C	783310546511	Round Shank 1/4" x 8" Flat Blade Screwdriver



0153-33C

Heavy-Duty Phillips Tip Screwdriver

- Precision-machined tips for exact fit
- Handle marked for easy identification of screwdriver size, type and length
- Strong, durable black-phosphate tips prevent chipping of plating
- Cushion grip handle for extra comfort and torque
- Meets ASME/ANSI specifications

CAT. NO.	UPC NO.	DESCRIPTION
0153-31C	783310546566	Heavy-Duty Phillips Tip #1 x 3" Screwdriver
0153-33C	783310546580	Heavy-Duty Phillips Tip #2 x 4" Screwdriver
0153-34C	783310546597	Heavy-Duty Phillips Tip #2 x 6" Screwdriver
0153-35C	783310546603	Heavy-Duty Phillips Tip #3 x 6" Screwdriver
0153-36C	783310892137	Heavy-Duty Phillips Tip #2 x 10" Screwdriver



0453-15C

Screw-Holding Screwdrivers

- Fine screw-holding device, available for either slotted or Phillips screws
- Easily holds screw in place when installing in hard-to-reach locations
- Precision tip for accurate fastener fit
- Heavy-duty construction for longer life
- Cushion grip handle for extra comfort and torque
- Handle marked for easy identification of screwdriver size and type
- Meets ASME/ANSI specification

CAT. NO.	UPC NO.	DESCRIPTION
0453-12C	783310563129	Screw-holding Screwdriver 1/8" x 5"
0453-14C	783310563143	Screw-holding Screwdriver 3/16" x 6"
0453-15C	783310563150	Screw-holding Screwdriver 1/4" x 7"
0453-16C	783310563167	Screw-holding Screwdriver Phillips Tip #0 x 5"
0453-17C	783310563174	Screw-holding Screwdriver Phillips Tip #1 x 5"
0453-18C	783310563181	Screw-holding Screwdriver Phillips Tip #2 x 7"



0353-01C

Square-Recess Tip Drivers

- Precision tip for accurate fastener fit
- Handle marked and color coded for easy identification of screwdriver size and type
- Heavy-duty construction for longer life
- High-grade, rust-resistant, chrome-plated finish
- Cushion grip handle for extra comfort and torque
- Meets ASME/ANSI specifications

CAT. NO.	UPC NO.	DESCRIPTION
0353-01C	783310546955	4-Piece Square-Recess Tip Driver Set, Contains - #0 x 4", #1 x 4", #2 x 4", & #3 x 4"
0353-11C	783310546887	Square-Recess Tip Driver - #0 x 4"
0353-12C	783310546894	Square-Recess Tip Driver - #1 x 4"
0353-13C	783310546917	Square-Recess Tip Driver - #2 x 4"
0353-14C	783310546931	Square-Recess Tip Driver - #3 x 4"
0353-21C	783310546528	Square-Recess Tip Driver - #0 x 8"
0353-22C	783310892151	Square-Recess Tip Driver - #1 x 8"
0353-23C	783310892168	Square-Recess Tip Driver - #2 x 8"
0353-24C	783310892175	Square-Recess Tip Driver - #3 x 8"



0153-32C

0153-28C

Stubby Screwdriver

- Precision-machined tips for exact fit
- Handle marked for easy identification of screwdriver size, type and length
- Strong, durable black-phosphate tips prevent chipping of plating
- Cushion grip handle for extra comfort and torque
- Meets ASME/ANSI specifications

CAT. NO.	UPC NO.	DESCRIPTION
0153-04C	783310134916	Stubby 2-Piece Screwdriver Set
0153-28C	783310546481	Round Shank 1/4" x 1-1/2" Flat Blade Screwdriver
0153-32C	783310546573	Heavy-Duty Phillips Tip #2 x 1-1/2" Screwdriver

SPECIALTY DRIVERS



9753-11C

Conduit Reaming Screwdriver

- Deburs ID and OD of 1/2", 3/4" and 1" thin wall conduit
- Handle marked for easy identification
- Hardened blade for longer life
- Hooded, flat tip driver used to fasten EMT fittings
- Cushion grip handle for extra comfort and torque
- Replaceable blade

CAT. NO.	UPC NO.	DESCRIPTION
9753-11C	783310546962	Conduit Reaming Screwdriver



9753-12C

Scratch Awl

- Integrated steel endcap for durability and long life
- Heavy-duty construction for piercing and scribing
- High-grade, rust-resistant, chrome-plated finish
- Cushion grip handle for extra comfort and torque

CAT. NO.	UPC NO.	DESCRIPTION
9753-12C	783310546979	Scratch Awl 3"



9753-13C

Bottle Opener

- Heavy-duty construction to handle any size job
- High-grade, stainless steel for repeated use
- Cushion grip handle for extra comfort and torque
- Handle marked for easy identification

CAT. NO.	UPC NO.	DESCRIPTION
9753-13C	783310892496	Bottle Opener

ADJUSTABLE TORQUE DRIVER

MAXIMIZED ACCURACY. INCREASED PROTECTION.

NEW



Major Graduation Display


Torque range: 5-40 in lb

Adjustable Knob

Easily set torque value

Calibrated

Within tolerance according to:
ASME B107.300-2010
(certificate included)

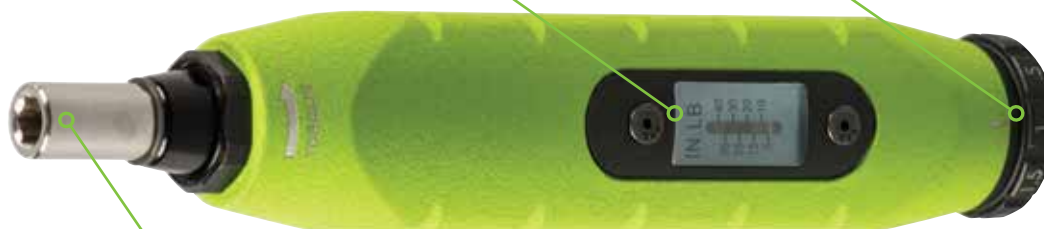

0153-46T

1/4" female hex drive magnetically holds bits and sockets

Accuracy

- Ensures connections are tightened to the correct torque rating, eliminating the need for guesswork

Compliance

- Sufficiently tightens connections to comply with new 2017 National Electric Code (110.14D)
- Helps prevent fires and other hazards caused by improperly torqued connections

Protection

- Durable, compact case provides optimal tool protection

Case

- EVA foam-molded case provides increased cushioning, resilience, and durability while keeping contents inside secure
- Bit sizes are printed inside the case for easy identification and selection



SPECIFICATIONS

Torque Range	5-40 in lb	
Overall Length	6 3/4"	
Shank Length	11/16"	
Handle Length	6"	
Bits	Phillips #1 x 6" Phillips #2 x 6" Flat 3/16" x 6" Flat 1/4" x 6" Square #1 x 6" Square #2 x 6"	Phillips #1 x 3 1/2" Phillips #2 x 3 1/2" Flat 3/16" x 3 1/2" Flat 1/4" x 3 1/2" Square #1 x 3 1/2" Square #2 x 3 1/2"
Sockets:	Nut Driver 3/16"-6" Nut Driver 1/4"-6" Nut Driver 5/16"-6" Nut Driver 11/32"-6"	Nut Driver 3/8"-6" Nut Driver 7/16"-6" Nut Driver 1/2"-6"

CAT. NO.	UPC NO.	DESCRIPTION
N 0153-46T	783310083603	Torque Screwdriver & Bit Set
N R 9953-46T	783310083597	Replacement Bit Kit
N R 0153-46CASE	783310090694	Case, Replacement Torque Screwdriver




11-IN-1 MULTI-DRIVER

MULTI-FUNCTIONAL SCREWDRIVER & NUTDRIVER

NEW



Bits are quickly and easily swapped out

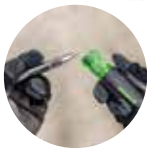

Bits are stored inside the shank



0153-47C



Square Recess #1 & #2



Phillips #2 & Slotted 1/4"



Torx® #10 & #15



Phillips #1 & Slotted 3/16"



1/4" Nutdrivers

SPECIFICATIONS

Overall Length	7.94"	
Shank Length	1.97"	
Handle Length	4.92"	
Bits	Phillips #1 Flat 3/16" Square #1 Phillips #1 Torx #10	Phillips #2 Flat 1/4" Square #2 Phillips #2 Torx #15
Sockets	Nut Driver 1/4" Nut Driver 5/16" Nut Driver 3/8"	

CAT. NO.	UPC NO.	DESCRIPTION
0153-47C	783310083634	Multi-Tool, 11-in-1
9953-20	783310083641	Bit Set, Replacement

HAND TOOLS



0153-42C

6-In-1 Multi-Tool

- Versatile multi-bit screwdriver with six tools in one
- Precision-machined, hardened steel bits
- High-grade, rust-resistant, chrome-plated finish
- Cushion grip handle for extra comfort and torque
- Contains:
 - 3/16" & 1/4" Flat-Tip
 - #1 & #2 Phillips and 5/16 & 1/4" Hex
 - #1 & #2 Phillips

CAT. NO.	UPC NO.	DESCRIPTION
0153-42C	783310563082	6-In-1 Multi-tool
R 9953-13	783310563105	Replacement Bits