



***ULTRA TUGGER® 10***  
***and Mobile VersiBoom II***

Professional. Nothing Less.™



## Mobile VersiBoom™ II and Ultra Tugger®

The Ultra Tugger and Mobile VersiBoom offer a flexible solution that can match almost any pull or job site situation and help get the job done quickly and easily.

The Ultra Tugger 10 (UT10-2S) has multiple mounting options; aside from using the Mobile VersiBoom™ II, you also have the option to use it with a floor mount or chain mount.

---

### Two-Speed Ultra Tugger (UT10-2S)

The Ultra Tugger 10,000-pound puller has two speeds and can shift from high speed to low speed with a double-tap motion on the foot pedal. High speed can pull up to 16 feet per minute up to 4,000 pounds, while low speed can pull 8,000 pounds at 9 feet per minute. The capacity peaks at 10,000 pounds at a rate of 6 feet per minute.

### Mobile VersiBoom II


The Mobile VersiBoom sets up in less than two minutes and can be used in almost every pulling situation. This combination of speed and versatility can increase the number pulls per day and help deliver greater benefit to your bottom line!

# ULTRA TUGGER® 10

## PRODUCT FEATURES

The UT10-2S motor is designed specifically for heavy-duty cable pulling applications. Greenlee's two-speed motor provides consistently stronger pulling power at less amperage than the competition. This increases durability and provides a steady pull speed.

- Two-speed motor allows for fast pulls up to 10,000 pounds
- The strong, rugged motor is designed to handle both large and small cable pulling applications up to 10,000 pounds
- On-board force gauge uses LED lights to display pulling force and speed
- Quickly change from high-speed to low-speed by double-tapping the foot pedal
- Removable foot pedal for storage

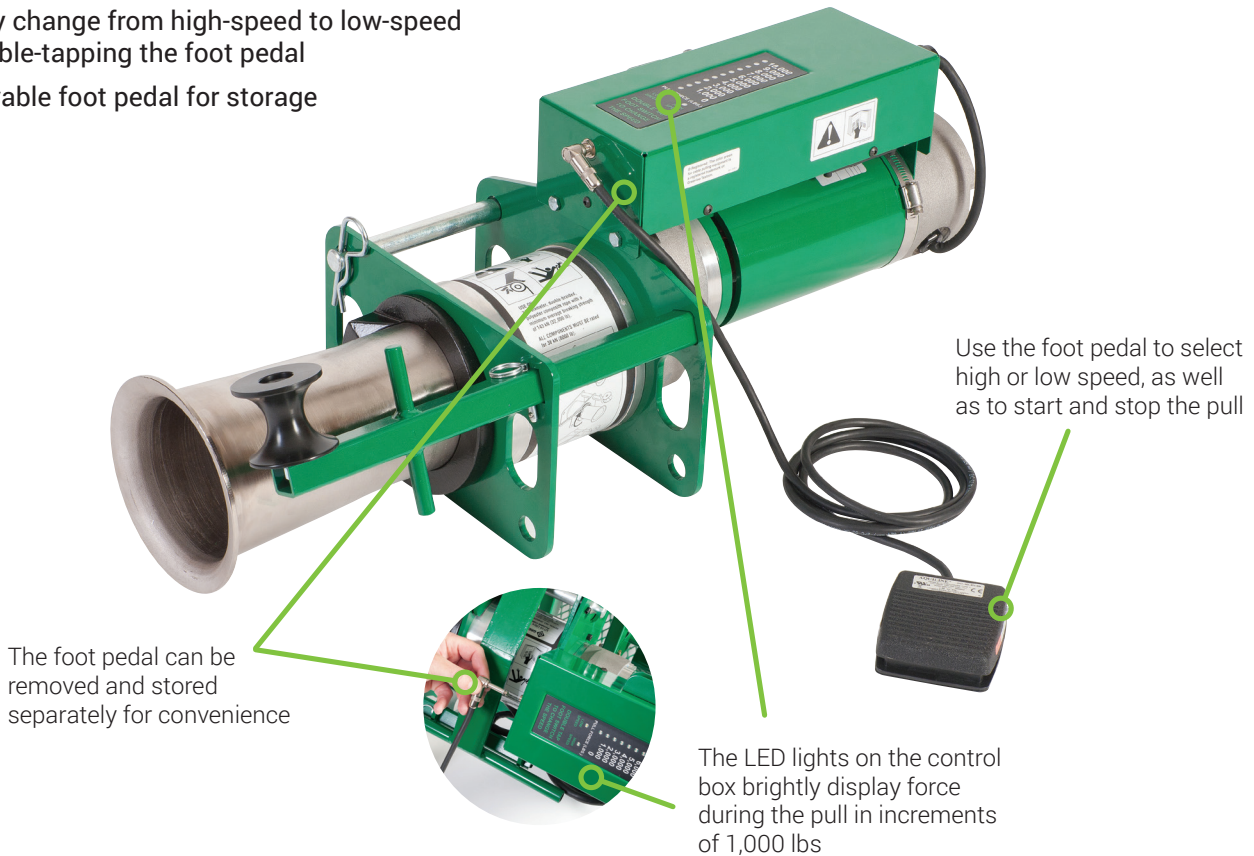

## PULLING FORCE

0 lbs. to 6,500 lbs. (0 kN to 28.9 kN):

**CONTINUOUS OPERATION**

6,500 lbs. to 8,000 lbs. (28.9 kN to 35.6 kN):

**15 MINUTES ON / 15 MINUTES OFF**

8,000 lbs. to 10,000 lbs. (35.6 kN to 44.5 kN):

**MOMENTARY**

|                       | HIGH SPEED             | LOW SPEED             |
|-----------------------|------------------------|-----------------------|
| No Load:              | 16 FT/MIN (4.88 M/MIN) | —                     |
| 2,000 lbs. (8,900 N): | 14 ft/min (4.27 m/min) | —                     |
| 4,000 lbs. (17.8 kN): | 12 ft/min (3.66 m/min) | —                     |
| 6,000 lbs. (26.7 kN): | —                      | 7 ft/min (2.13 m/min) |
| 8,000 lbs. (35.6 kN): | —                      | 6 ft/min (1.83 m/min) |

# MOBILE VersiBoom® II

SIMPLE ONE PERSON SET-UP IN LESS THAN TWO MINUTES



**1** Lift the boom to desired angle using crank



**2** Position the elbow to desired angle



**3** Position the nose just over conduit and lower adapter into conduit by cranking the boom lower


**Interchangeable Nose and Elbow**



**Built-in Storage**  
Store adapters for 2" - 5" conduit



**Quick Clean Up**  
Folds down in under 2 minutes to be small enough to fit in a pickup truck

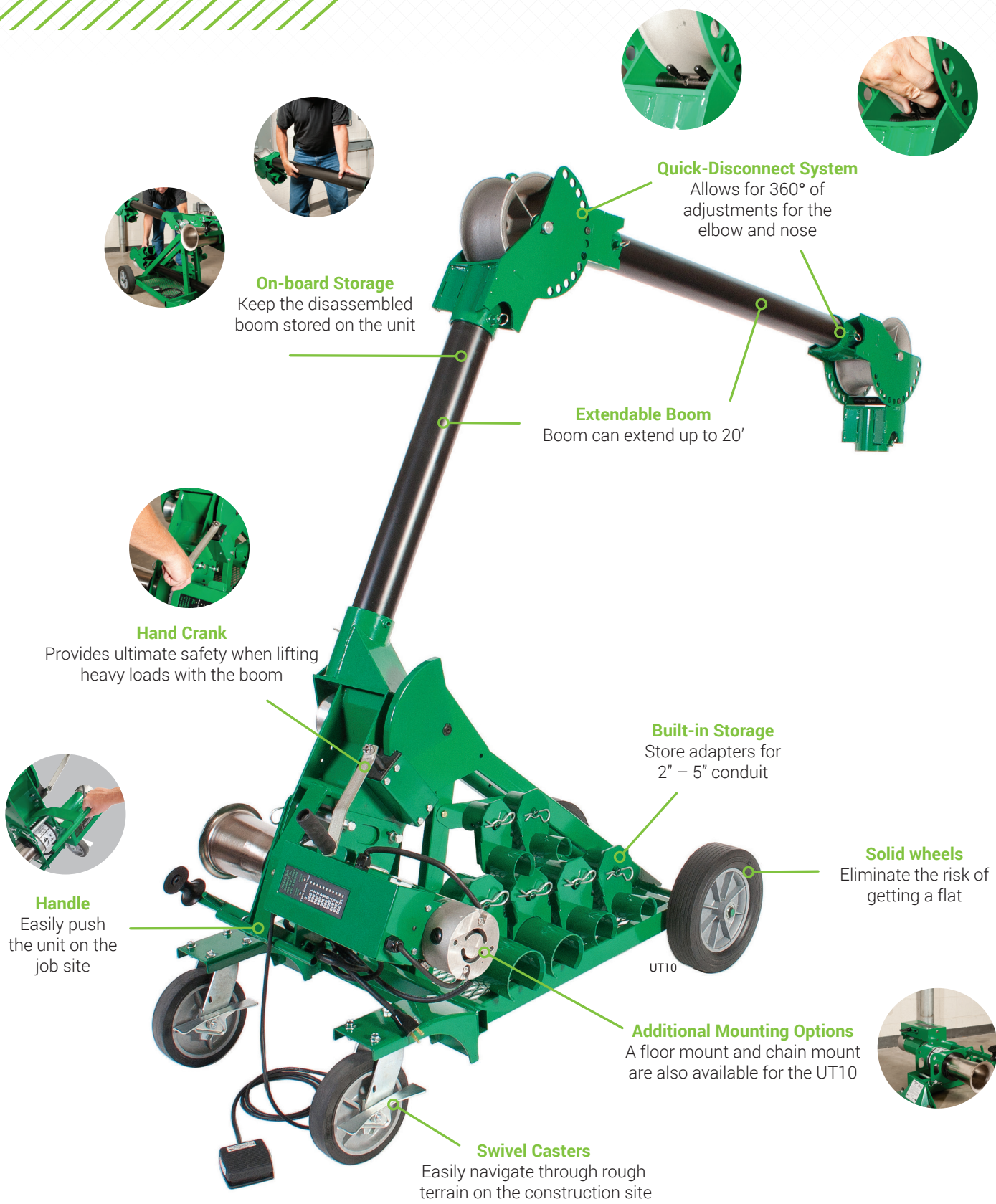

**On-board Storage**  
Keep the disassembled boom stored on the unit



**Quick-Disconnect System**  
Allows for 360° of adjustments for the elbow and nose



**Extendable Boom**  
Boom can extend up to 20'



**Hand Crank**  
Provides ultimate safety when lifting heavy loads with the boom



**Handle**  
Easily push the unit on the job site

**Built-in Storage**  
Store adapters for 2" – 5" conduit

**Solid wheels**  
Eliminate the risk of getting a flat

**Additional Mounting Options**  
A floor mount and chain mount are also available for the UT10



**Swivel Casters**  
Easily navigate through rough terrain on the construction site

UT10

# UT10 PRODUCTS



## 6906A

UT10-2S Package with Mobile VersiBoom II and 6 Adapters



## 6900

UT10-2S Package with Floor mount



## 6901

UT10-2S Package with Chain mount



## Cable Feeder

Increase efficiency and productivity by using a cable feeding system to make cable setup and payout a one-person job.



## G-Series Smart Pull

Monitor real time force, speed and distance during a cable pull avoiding rework and liability.



## Rope

Use up to 7/8" rope with a maximum rated capacity that meets or exceeds the cable pullers maximum pulling force.



## Cable Handling

A comprehensive line of jack stands, reel rollers, caddies and dispensers to efficiently handle cable payout.



## Grips & Crimpers

Save time by using Gator Grips. Select the size for an indent crimper, and be set up for the pull in less than two minutes.

## KIT SELECTION GUIDE

### PRODUCTS INCLUDED

| CAT. NO. | UPC NO. | DESCRIPTION                        | UT10 Kits |      |      |       | Mobile VersiBoom II Kits: |       |
|----------|---------|------------------------------------|-----------|------|------|-------|---------------------------|-------|
|          |         |                                    | 6900      | 6901 | 6906 | 6906A | MVB                       | MVB-A |
| UT10-2S  | 05528   | Puller Assembly (UT10)             | X         | X    | X    | X     |                           |       |
| 02846    | 02846   | Chain Mount Ass'y-Pkgd             | X         |      |      |       |                           |       |
| 00865    | 00865   | Mount Assy-Floor                   |           | X    |      |       |                           |       |
| MVB      | 00553   | Mobile VersiBoom II                |           |      | X    |       | X                         |       |
| MVB-A    | 00610   | Mobile VersiBoom II and 6 Adapters |           |      |      | X     |                           | X     |
| 00561    | 00561   | 3' Boom                            |           |      | X    | X     | X                         | X     |
| 00560    | 00560   | 4' boom                            |           |      | X    | X     | X                         | X     |
| 00563    | 00563   | Adapter Weldment, 2"               |           |      |      | X     |                           | X     |
| 00564    | 00564   | 2-1/2" Adapter                     |           |      | X    | X     | X                         | X     |
| 00565    | 00565   | Adapter Weldment, 3"               |           |      | X    | X     | X                         | X     |
| 00566    | 00566   | Adapter Weldment, 3-1/2"           |           |      |      | X     |                           | X     |
| 00567    | 00567   | 4" Adapter                         |           |      | X    | X     | X                         | X     |
| 00610    | 00610   | Adapter Weldment, 5"               |           |      |      | X     |                           | X     |
| 00583    | 00583   | Adapter Assembly, 2" Screw-On      |           |      |      |       |                           |       |
| 00584    | 00584   | Adapter Assembly, 2-1/2" Screw-On  |           |      |      |       |                           |       |
| 00585    | 00585   | Adapter Assembly, 3" Screw-On      |           |      |      |       |                           |       |
| 00586    | 00586   | Adapter Assembly, 3-1/2" Screw-On  |           |      |      |       |                           |       |
| 00587    | 00587   | Adapter Assembly, 4" Screw-On      |           |      |      |       |                           |       |

### KIT OPTIONS

# ORDERING INFORMATION



|            | CAT NO. | UPC NO. | DESCRIPTION   |
|------------|---------|---------|---|
| <b>NEW</b> | 6906A   | 00567   | UT10-2S Package with Mobile VersiBoom II and 6 Adapters |
|            | 6906    | 00359   | UT10-2S Package with Mobile VersiBoom II                |
|            | 6906-22 | 00812   | UT10-22 (220 V) Package with Mobile VersiBoom II        |
|            | 6900    | 00357   | UT10-2S Package with Floor mount                        |
|            | 6900-22 | 00814   | UT10-22 (220 V) Package with Floor mount                |
|            | 6901    | 00358   | UT10-2S Package with Chain mount                        |
|            | 6901-22 | 00813   | UT10-22 (220 V) Package with Chain mount                |
|            | UT10-2S | 05528   | Puller Assembly   |
|            | UT10-22 | 00829   | (220 V) Puller Assembly                                 |
| <b>NEW</b> | MVB-A   | 00610   | Mobile VersiBoom II and 6 Adapters                      |
|            | MVB     | 00553   | Mobile VersiBoom II                                     |
|            | 00471   | 00471   | Coupling Hanger Kit                                     |
|            | 00563   | 00563   | Adapter Weldment, 2"                                    |
|            | 00564   | 00564   | Adapter Weldment, 2-1/2"                                |
|            | 00565   | 00565   | Adapter Weldment, 3"                                    |
|            | 00566   | 00566   | Adapter Weldment, 3-1/2"                                |
|            | 00567   | 00567   | Adapter Weldment, 4"                                    |
|            | 00610   | 00610   | Adapter Weldment, 5"                                    |
|            | 00583   | 00583   | Adapter Assembly, 2" Screw-On                           |
|            | 00584   | 00584   | Adapter Assembly, 2-1/2" Screw-On                       |
|            | 00585   | 00585   | Adapter Assembly, 3" Screw-On                           |
|            | 00586   | 00586   | Adapter Assembly, 3-1/2" Screw-On                       |
|            | 00587   | 00587   | Adapter Assembly, 4" Screw-On                           |
|            | 00588   | 00588   | Hanger Weldment, Short                                  |
|            | 00589   | 00589   | Hanger Weldment, Long                                   |
|            | 00590   | 00590   | Screw On Coupling Kit                                   |



Professional. Nothing Less.™

