



# MC & AC CABLE & FLEXIBLE METALLIC CONDUIT FITTINGS

FLEX




| TRADE SIZE                                     | HALEX PART # | CTN/CASE QTY   | CTN/CASE WT (LBS) | DIMENSIONS (IN INCHES) |       |
|--|--------------|----------------|-------------------|------------------------|-------|
|  |              |                |                   | A                      | B     |
| <b>Anti-Short Bushings</b>                     |              |                |                   |                        |       |
| <b>Polyethylene</b>                            |              |                |                   |                        |       |
| <i>FITS CABLE RANGE: 14/2, 14/3, 12/2</i>      |              |                |                   |                        |       |
| 0 (5/16")                                      | 75400        | 10 BAGS/35 PCS | 0.6               | 0.394                  | 0.350 |
| 0 (5/16")                                      | 75400BP      | 1000           | 1.7               | 0.394                  | 0.350 |
| <i>FITS CABLE RANGE: 14/4, 12/3, 6/1, 4/1</i>  |              |                |                   |                        |       |
| 1 (3/8")                                       | 75401        | 10 BAGS/35 PCS | 0.45              | 0.450                  | 0.410 |
| 1 (3/8")                                       | 75401BP      | 1000           | 2.0               | 0.450                  | 0.410 |
| <i>FITS CABLE RANGE: 12/4, 10/2, 10/3, 2/1</i> |              |                |                   |                        |       |
| 2 (7/16")                                      | 75402        | 5 BAGS/35 PCS  | 0.4               | 0.588                  | 0.540 |
| 2 (7/16")                                      | 75402BP      | 500            | 1.2               | 0.588                  | 0.540 |
| 3 (1/2")                                       | 75403        | 5 BAGS/20 PCS  | 0.3               | 0.780                  | 0.730 |
| 3 (1/2")                                       | 75403BP      | 250            | 1.0               | 0.780                  | 0.730 |
| 4 (3/4")                                       | 75404        | 4 BAGS/16 PCS  | 0.2               | 0.990                  | 0.940 |
| 4 (3/4")                                       | 75404BP      | 250            | 1.0               | 0.990                  | 0.940 |



**APPLICATION:** INDOORS ONLY - Use to protect wire within flexible metallic conduit MC and AC cable. Insert one bushing at each end of conduit or cable. **MATERIAL:** Polyethylene.  
**CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.



| TRADE SIZE                   | HALEX PART # | CTN/CASE QTY | CTN/CASE WT (LBS) | DIMENSIONS (IN INCHES) |         |      |
|------------------------------|--------------|--------------|-------------------|------------------------|---------|------|
|                              |              |              |                   | A (MIN)                | A (MAX) | B    |
| <b>Squeeze Connectors</b>    |              |              |                   |                        |         |      |
| <b>Zinc Die Cast</b>         |              |              |                   |                        |         |      |
| 3/8" (1/2" ko)               | 04203B       | 50/500       | 3.5/35            | 0.58                   | 0.61    | 1.00 |
| 1/2"                         | 04205B       | 25/250       | 2.5/25            | 0.74                   | 0.95    | 1.47 |
| 3/4"                         | 04207B       | 25/250       | 3.3/32.5          | 0.88                   | 1.11    | 1.58 |
| 1"                           | 04210B       | 10/100       | 2/20              | 1.14                   | 1.38    | 1.75 |
| 1 1/4"                       | 04212B       | 10/100       | 2.9/29            | 1.42                   | 1.65    | 1.91 |
| 1 1/2"                       | 04215B       | 5/50         | 2/19.5            | 1.68                   | 1.94    | 2.09 |
| 2"                           | 04220B       | 10/40        | 4.6/18.4          | 2.08                   | 2.56    | 2.34 |
| 2 1/2"                       | 04225B       | 10           | 9                 | 2.88                   | 3.25    | 2.75 |
| 3"                           | 04230B       | 5            | 6.5               | 3.34                   | 3.63    | 3.19 |
| 3 1/2"                       | 04235B       | 2            | 3                 | 3.75                   | 4.13    | 3.56 |
| 4"                           | 04240B       | 1            | 2                 | 4.19                   | 4.56    | 3.94 |
| <b>WITH INSULATED THROAT</b> |              |              |                   |                        |         |      |
| 1/2"                         | 84205B       | 25/250       | 2.5/25            | 0.74                   | 0.95    | 1.52 |
| 3/4"                         | 84207B       | 25/250       | 3.3/32.5          | 0.88                   | 1.11    | 1.63 |
| 1"                           | 84210B       | 10/100       | 2/20              | 1.14                   | 1.38    | 1.80 |
| 1 1/4"                       | 84212B       | 10/100       | 2.9/29            | 1.42                   | 1.65    | 1.96 |
| 1 1/2"                       | 84215B       | 5/50         | 2/19.5            | 1.68                   | 1.94    | 2.14 |
| 2"                           | 84220B       | 10/40        | 4.6/18.4          | 2.08                   | 2.56    | 2.39 |

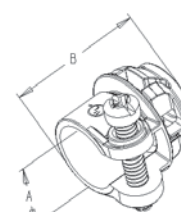

**APPLICATION:** INDOORS ONLY - In a dry location, use to connect flexible metallic conduit and steel AC cable to a steel outlet box, load center or other metal enclosure. The 3/8" can also be used with steel and aluminum MC cable. **MATERIAL:** Zinc Die Cast. **MISC:** 3/8" size fits 1/2" knockout.  
**SUITABLE FOR:** 3/8" steel flexible conduit, #14/2 wire steel armored cable, .561 steel and .538-599 aluminum interlocked metal clad cable. 1/2" steel flexible metal conduit and #4-2 wire steel armored cable. 3/4" steel flexible metal conduit and #6-3 wire steel armored cable. 1" steel and reduced wall steel flexible metal conduit and #2-2 wire steel armored cable. 1 1/4" - 4" steel flexible metal conduit.  
**CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.