




ELECTRICAL METALLIC TUBING FITTINGS

EMT




TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
EMT-To-EMT Pull Elbows					
Zinc Die Cast					
<i>WITHOUT GASKET</i>					
1/2"	14405	15	2.8	1.31	0.97
3/4"	14407	10	3.7	1.50	1.20
<i>WITH NEOPRENE GASKET</i>					
1/2"	94405	10	2.4	1.31	0.97
3/4"	94407	5	1.9	1.50	1.20
1"	94410	5	3.4	1.85	1.52

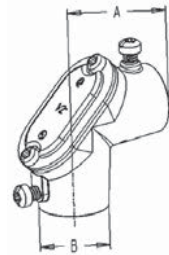

APPLICATION: DRY LOCATIONS – Use to connect EMT conduit together at a 90° bend.
MATERIAL: Zinc Die Cast. **TYPE:** Set-Screw. **FEATURES:** Removable aluminum cover facilitates wire pulling. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.



TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
EMT-To-Box Pull Elbows					
Zinc Die Cast					
<i>WITHOUT GASKET</i>					
1/2"	14305	10	2.2	1.31	0.97
3/4"	14307	5	1.8	1.50	1.20

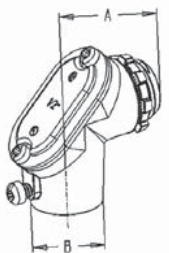

APPLICATION: DRY LOCATIONS – Use to connect EMT conduit to a metal box or enclosure to form a 90° bend. **MATERIAL:** Zinc Die Cast. **TYPE:** Set-Screw. **FEATURES:** Removable aluminum cover facilitates wire pulling. Die cast locknut provided. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.




TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
EMT/Rigid-To-EMT/Rigid Combo Elbows					
Zinc Die Cast					
<i>WITH NEOPRENE GASKET</i>					
1/2"	94505	10 BAGS	2.0	1.31	0.97
3/4"	94507	10 BAGS	3.0	1.500	1.200
1"	94510	5	2.9	1.85	1.52



APPLICATION: INDOORS OR OUTDOORS. Use as a wire pulling elbow to facilitate wire pulling through a sharp bend in a run of EMT or threaded Rigid or IMC conduit. Removable cover provides easy access to facilitate wire pulling. Not listed for wet locations. **MATERIAL:** Zinc Die Cast. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.




TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
EMT/Rigid-To-Box Combo Elbows					
Zinc Die Cast					
<i>WITH NEOPRENE GASKET</i>					
1/2"	94705	10 BAGS	1.90	1.310	1.020
3/4"	94707	5 BAGS	1.50	1.500	1.270

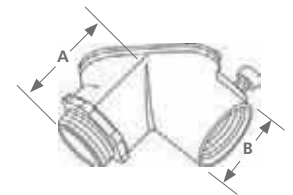

APPLICATION: INDOORS OR OUTDOORS. Use to connect a run of EMT or threaded Rigid or IMC conduit to an outlet box, or other metal enclosure. Removable cover provides easy access to facilitate wire pulling. Not listed for wet locations. **MATERIAL:** Zinc Die Cast. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.



TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
EMT-To-EMT Inside-Corner Pull Elbows					
Zinc Die Cast					
<i>WITHOUT GASKET</i>					
1/2"	14605	15	2.7	1.81	1.00
3/4"	14607	8	1.9	2.00	1.25

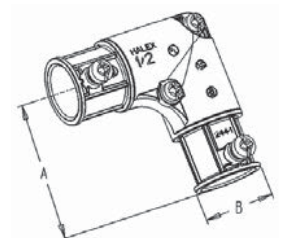

APPLICATION: INDOORS ONLY – Use to connect EMT conduit together on a 90° inside corner. **MATERIAL:** Zinc Die Cast. **TYPE:** Set-Screw. **FEATURES:** Removable cover facilitates wire pulling. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.