



# RIGID & INTERMEDIATE METALLIC CONDUIT FITTINGS


RIGID



TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)
------------	--------------	--------------	-------------------

## Conduit Nipples

Steel

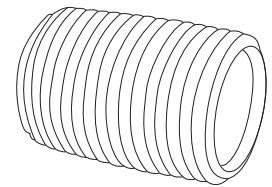

1/2"XCLOSE	<b>64305</b>	20	1.2
1/2"X1 1/2"	<b>64311</b>	25	2
1/2"X2"	<b>64325</b>	15	2
1/2"X3"	<b>64331</b>	25	4.2
1/2"X4"	<b>64341</b>	15	4.2
1/2"X5"	<b>64351B</b>	25	8.25
1/2"X6"	<b>64361</b>	10	3.9
1/2"X8"	<b>64381B</b>	1	0.5
1/2"X10"	<b>64391B</b>	1	0.7
1/2"X12"	<b>64301B</b>	1	0.8
3/4"XCLOSE	<b>64307</b>	20	1.9
3/4"X2"	<b>64327</b>	15	2.4
3/4"X3"	<b>64332</b>	20	6
3/4"X4"	<b>64342</b>	15	9
3/4"X5"	<b>64352B</b>	25	10.75
3/4"X6"	<b>64362</b>	10	5
3/4"X8"	<b>64382B</b>	1	0.72
3/4"X10"	<b>64392B</b>	1	0.9
3/4"X12"	<b>64302B</b>	1	1.1
1"XCLOSE	<b>64310</b>	15	4
1"X2"	<b>64313</b>	10	2
1"X2 1/2"	<b>64323</b>	15	4
1"X3"	<b>64333</b>	25	9
1"X4"	<b>64343B</b>	25	12.25
1"X5"	<b>64353</b>	10	6.4
1"X6"	<b>64363</b>	6	4.8
1"X8"	<b>64383B</b>	1	1.1
1"X10"	<b>64393B</b>	1	1.3
1"X12"	<b>64303B</b>	1	1.6

CONTINUATION OF CHART AND IMPORTANT APPLICATION, MATERIAL AND CERTIFICATION NOTES PROVIDED ON NEXT PAGE

1 1/4"XCLOSE	<b>64312</b>	10	2.1
1 1/4"X2"	<b>64314</b>	10	2.6
1 1/4"X3"	<b>64334</b>	5	2.4
1 1/4"X4"	<b>64344B</b>	25	16.5
1 1/4"X5"	<b>64354</b>	6	5
1 1/4"X6"	<b>64364</b>	6	6
1 1/4"X8"	<b>64384B</b>	1	1.4
1 1/4"X10"	<b>64394B</b>	1	1.8
1 1/4"X12"	<b>64308B</b>	1	2.2
1 1/2"XCLOSE	<b>64315</b>	5	1.48
1 1/2"X2"	<b>64615</b>	5	1.7
1 1/2"X3"	<b>64335</b>	10	5.6
1 1/2"X4"	<b>64345B</b>	25	20
1 1/2"X5"	<b>64355B</b>	25	25.75
1 1/2"X6"	<b>64365</b>	4	5
1 1/2"X8"	<b>64385B</b>	1	1.7
1 1/2"X10"	<b>64395B</b>	1	2.2
1 1/2"X12"	<b>64605B</b>	1	2.6
2"XCLOSE	<b>64320</b>	4	1.9
2"X3"	<b>64336</b>	6	5
2"X4"	<b>64346B</b>	25	25.75
2"X5"	<b>64356</b>	6	8
2"X6"	<b>64366</b>	5	3
2"X7"	<b>64676</b>	3	8.5
2"X8"	<b>64386</b>	4	9
2"X10"	<b>64396B</b>	1	2.9
2"X12"	<b>64306B</b>	1	3.5
2 1/2"XCLOSE	<b>64617B</b>	1	0.45
2 1/2"X4"	<b>64347B</b>	1	1.5
2 1/2"X5"	<b>64357B</b>	1	2.0
2 1/2"X6"	<b>64367B</b>	1	2.4
2 1/2"X8"	<b>64387B</b>	1	3.3
2 1/2"X10"	<b>64397B</b>	1	4.25
2 1/2"X12"	<b>64607B</b>	1	5.1
3"XCLOSE	<b>64618B</b>	1	1.2
3"X3"	<b>64338B</b>	1	1.3
3"X4"	<b>64348B</b>	1	2.0
3"X5"	<b>64358B</b>	1	2.6
3"X6"	<b>64368B</b>	1	3.0
3"X8"	<b>64388B</b>	1	4.2
3"X10"	<b>64398B</b>	1	5.3
3"X12"	<b>64608B</b>	1	6.3
3 1/2"XCLOSE	<b>64619B</b>	1	1.6
3 1/2"X4"	<b>64349B</b>	1	2.4
3 1/2"X5"	<b>64359B</b>	1	3.2
3 1/2"X6"	<b>64369B</b>	1	3.75
3 1/2"X8"	<b>64389B</b>	1	5.1
3 1/2"X10"	<b>64399B</b>	1	5.6
3 1/2"X12"	<b>64309B</b>	1	7.9
4"XCLOSE	<b>64620B</b>	1	1.8
4"X4"	<b>64340B</b>	1	2.9
4"X5"	<b>64350B</b>	1	3.8
4"X6"	<b>64360B</b>	1	4.4
4"X8"	<b>64380B</b>	1	6.0
4"X10"	<b>64390B</b>	1	7.75
4"X12"	<b>64300B</b>	1	9.25

**APPLICATION:** INDOORS OR OUTDOORS. Use to connect two steel outlet boxes or other metal enclosures; use to extend a length of threaded Rigid or IMC conduit. **MATERIAL:** Steel, Zinc Electro-Plate. **MISC:** Consult factory for availability of other sizes. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.