




ELECTRICAL METALLIC TUBING FITTINGS

EMT




TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C
Raintight Compression Connectors				Steel		
1/2"	62505B	50	5.9/29.5	1.650	0.460	1.125
3/4"	62507B	25	4.3/21.5	1.800	0.480	1.375
1"	62510B	15	3.5/17.5	1.870	0.500	1.690
1 1/4"	62512B	20	8.20	2.140	0.620	2.060
1 1/2"	62515B	10	5.00	2.270	0.650	2.250
2"	62520B	10	6.80	2.400	0.690	2.750
2 1/2"	62525B	6	10.7	2.440	0.750	3.625
3"	62530B	6	13.2	2.560	0.875	4.250
3 1/2"	62535B	6	15.4	2.750	0.938	4.688
4"	62540B	6	17.9	2.750	0.938	5.188
WITH INSULATED THROAT						
1/2"	92505B	50	5.9/29.5	1.710	0.520	1.125
3/4"	92507B	25	4.3/21.5	1.860	0.540	1.375
1"	92510B	15	3.5/17.5	1.930	0.560	1.690
1 1/4"	92512B	20	8.20	2.190	0.680	2.066
1 1/2"	92515B	10	5.00	2.330	0.710	0.760
2"	92520B	10	6.80	2.460	0.750	2.750
2 1/2"	92525B	6	10.7	2.520	0.825	3.625
3"	92530B	6	13.2	2.620	0.938	4.250
3 1/2"	92535B	6	15.4	2.810	1.000	4.688
4"	92540B	6	17.9	2.810	1.000	5.188

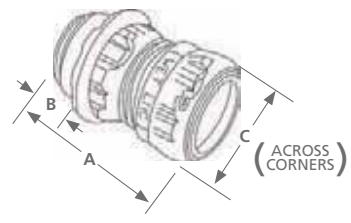

APPLICATION: INDOORS OR OUTDOORS – Use to connect EMT conduit to steel outlet box, load center, or other metal enclosure in a dry or wet location. **MATERIAL:** Steel, Zinc Electro-Plate. **FEATURES:** Concrete-Tight and Raintight. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.



TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B
Raintight Compression Couplings				Steel	
1/2"	62605B	50	7.2/36	2.000	1.125
3/4"	62607B	25	5.5/27.5	2.200	1.375
1"	62610B	15	4.5/22.5	2.450	1.690
1 1/4"	62612B	20	10.8	2.600	2.060
1 1/2"	62615B	10	6.00	2.730	2.180
2"	62620B	10	8.00	2.920	2.750
2 1/2"	62625B	6	16.0	3.875	3.625
3"	62630B	6	19.8	4.00	4.250
3 1/2"	62635B	6	23.1	4.6875	4.688
4"	62640B	6	26.8	4.9375	5.188

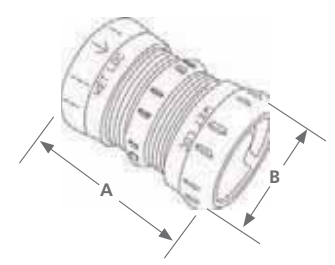

APPLICATION: INDOORS OR OUTDOORS – Use to connect two lengths of EMT conduit together in a dry or wet location. **MATERIAL:** Steel, Zinc Electro-Plate. **FEATURES:** Concrete-Tight and Raintight. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.