

TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C

Non-Metallic Strain Relief Cord Connectors


FITS CORD RANGE: .235 - .400

1/2"	76913B	25	1	1.792	0.600	1.030
------	--------	----	---	-------	-------	-------

FITS CORD RANGE: .410 - .740

3/4"	76923B	10	0.6	2.250	0.600	1.270
------	--------	----	-----	-------	-------	-------

APPLICATION: INDOORS ONLY. Use to connect cord to a steel outlet box or other metal enclosure. **MATERIAL:** PVC. **TYPE:** Gland Style. **FEATURES:** Liquid-tight seal, oil-tight seal, unique grommet with gripping fingers. A sealing ring and zinc locknut are provided to assure a liquid-tight seal when installing in non-threaded openings. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.

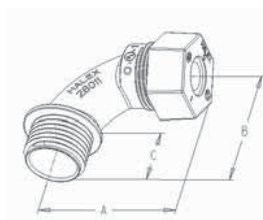

TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C

90° (Large Radius) Strain Relief Cord Connectors

Zinc Die Cast

FITS WIRE RANGE : .190 - .260

1/2"	16811B	10	1.4	1.655	1.469	0.521
------	--------	----	-----	-------	-------	-------

FITS WIRE RANGE : .260 - .375

1/2"	16812B	10	1.4	1.655	1.469	0.521
------	--------	----	-----	-------	-------	-------

FITS WIRE RANGE : .375 - .500

1/2"	16813B	10	1.4	1.655	1.469	0.521
------	--------	----	-----	-------	-------	-------

FITS WIRE RANGE : .440 - .500

3/4"	16821B	10	2.1	1.914	1.634	0.521
------	--------	----	-----	-------	-------	-------


FITS WIRE RANGE : .500 - .625

3/4"	16822B	10	2.1	1.914	1.634	0.521
------	--------	----	-----	-------	-------	-------

FITS WIRE RANGE : .625 - .725

3/4"	16823B	10	2.1	1.914	1.634	0.521
------	--------	----	-----	-------	-------	-------

APPLICATION: INDOORS ONLY. Use to connect S, SO, ST, SJ, SJO, and SJT cord to a steel outlet box or other metal enclosure. **MATERIAL:** Zinc Die Cast. **TYPE:** Gland Style. **FEATURES:** Large Radius provides minimal wire stress and easy pulling. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.

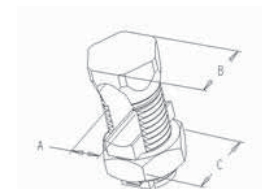

TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C

Split Bolt Connectors

Bronze

10-8	32408B	100	4	0.1475	0.4050	0.5475
8-6 SOL	32406B	100	5	0.1685	0.4055	0.6165
8-6	32404B	100	7	0.2100	0.4375	0.6780
6-2	32402B	100	11	0.3130	0.5980	0.8520
4-1/0	32310B	50	8	0.3770	0.7535	1.0085
2-2/0	32320B	25	8	0.4275	0.7915	1.0525
1-3/0	32330B	25	10	0.5375	0.9580	1.2565
1-250 MCM	32340B	25	13	0.5880	1.0410	1.3765

* **RANGE:** Equal run and tap. Each wire size is listed for both solid and stranded unless specified. **APPLICATION:** INDOORS OR OUTDOORS. Use to connect ground wires together. For direct burial stranded unless specified and concrete. **PURPOSE:** For Copper and Copperweld Wires. **MATERIAL:** Silicon Bronze. **TYPE:** Flat Style. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.

