



ACCESSORIES

+ ACC



TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C

Split Bolt Connectors with Spacer Bar Steel


FOR COPPER TO COPPER; **CAN BE USED ON ALUMINUM CONDUCTOR, BUT IS NOT UL LISTED FOR THAT APPLICATION

FOR COPPER TO COPPER, COPPER TO ALUMINUM, ALUMINUM TO ALUMINUM						
6-2	32002B	100	13	0.3155	0.6080	0.8600

FOR COPPER TO COPPER; **CAN BE USED ON ALUMINUM CONDUCTOR, BUT IS NOT UL LISTED FOR THAT APPLICATION

8-6 SOL	32006B	25	1.50	0.1670	0.3960	0.6155
8-6	32004B	25	2.00	0.2095	0.4375	0.6795
4-1/0	31910B	10	1.80	0.3785	0.7525	1.0430
2-2/0	31920B	25	8.00	0.4285	0.7955	1.0635
1-3/0	31930B	10	4.00	0.5825	1.0340	1.3725
1-250 MCM STR	31940B	25	13.30	0.05825	1.0340	1.3725

* **RANGE:** Each wire size is listed for both solid and stranded unless specified. **APPLICATION:** INDOORS OR OUTDOORS. Use to connect wires together. Use oxide-inhibiting compound when connecting aluminum or ACSR (aluminum conductor steel reinforced) or aluminum to copper wires. **MATERIAL:** Silicon Bronze with Electro-Tin plated bolt, nut, spacer, and pressure bar. **MISC:** Call factory for availability of other sizes. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.

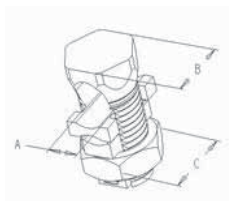


TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)		
				A	B	C

Solderless Terminal Lugs Copper

#6-#14	32606B	250	7.5	NA	0.438	1.125	0.375
#8-#2	32602B	200	10	NA	0.500	1.438	0.500
#14-10	32609B	50	1.1	NA	0.281	0.938	0.313
#1/0-#8	32510B	100	11	NA	0.625	1.875	0.625
#4-#3/0	32530B	10	1.6	NA	0.750	2.250	0.750
#2-#4/0	32540B	10	2.4	NA	1.000	2.375	1.000

APPLICATION: INDOORS OR OUTDOORS. Use to connect a ground wire or wires to a metal enclosure. **MATERIAL:** Electrolytic Copper. **FEATURES:** One Hole, Single Collar. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.

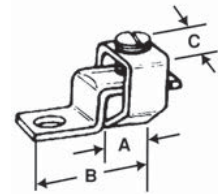

TRADE SIZE	HALEX PART #	CTN/CASE QTY	CTN/CASE WT (LBS)	DIMENSIONS (IN INCHES)	
				A	B

Strut Pipe Clamp Steel

1/2" & 3/4"	61399B	25	2.93	1.25	4.90
-------------	---------------	----	------	------	------

APPLICATION: INDOORS OR OUTDOORS. Use this strut pipe clamp for securing 1/2" and 3/4" conduit and pipe from strut sizes 1-5/8" (41 mm) wide x minimum 13/16" (21mm) high. **MATERIAL:** Steel, Zinc Electro-Plate. **FEATURES:** One clamp fits 1/2" and 3/4" trade sizes and provides a 2-1 SKU reduction. The slanted design makes installation easier and allows pipe and conduit to be tightly spaced. **CERTIFICATIONS:** TO UL AND CSA REQUIREMENTS.

