


## 739 LF FEMALE ADAPTER TUBE TO PIPE

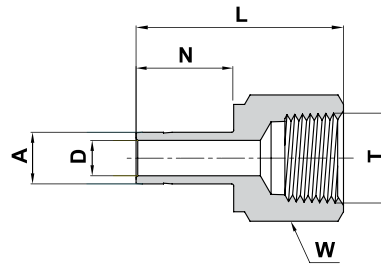

### TUBE (METRIC) FEMALE PIPE


Ordering Information	A Tube O.D.	T (NPT)	D	W Hex. Flat	N	L
	mm	inch	mm	mm	mm	mm
739LF_ 3 X 1/8	3	1/8	2.1	14	13.5	31.5
739LF_ 3 X 1/4	3	1/4	2.1	19	13.5	35.3
739LF_ 4 X 1/4	4	1/4	2.2	19	14.2	35.0
739LF_ 6 X 1/8	6	1/8	4.0	14	15.7	32.5
739LF_ 6 X 1/4	6	1/4	4.0	19	15.7	37.1
739LF_ 6 X 3/8	6	3/8	4.0	22	15.7	39.6
739LF_ 6 X 1/2	6	1/2	4.0	27	15.7	45.5
739LF_ 8 X 1/8	8	1/8	5.6	14	16.8	34.3
739LF_ 8 X 1/4	8	1/4	5.6	19	16.8	37.6
739LF_ 8 X 1/2	8	1/2	5.6	27	16.8	46.0
739LF_ 10 X 1/4	10	1/4	7.1	19	17.5	38.1
739LF_ 10 X 3/8	10	3/8	7.1	22	17.5	40.1
739LF_ 10 X 1/2	10	1/2	7.1	27	17.5	46.5
739LF_ 12 X 1/4	12	1/4	8.8	19	23.1	43.4
739LF_ 12 X 3/8	12	3/8	8.8	22	23.1	45.5
739LF_ 12 X 1/2	12	1/2	8.8	27	23.1	52.3
739LF_ 16 X 3/8	16	3/8	12.7	24	24.7	48.0
739LF_ 16 X 1/2	16	1/2	12.7	27	24.7	53.1
739LF_ 20 X 1/2	20	1/2	15.1	27	26.6	56.0
739LF_ 20 X 3/4	20	3/4	15.1	35	26.6	56.0

"D" - Dimension is minimum opening. Dimensions are for reference only, and are subject to change without notice.

Cont'd next page

## 739 LF FEMALE ADAPTER TUBE TO PIPE

(Cont'd)

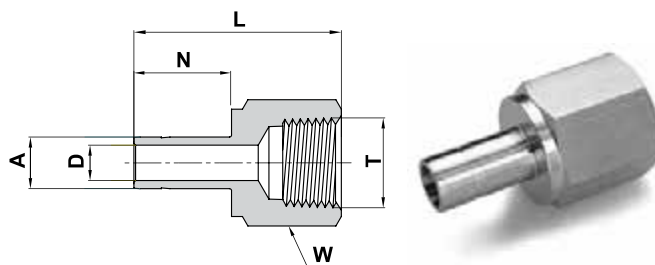

### TUBE (INCH) FEMALE PIPE

Ordering Information	A Tube O.D.		T (NPT)	D		W Hex. Flat	N		L	
	inch	mm	inch	inch	mm	inch	inch	mm	inch	mm
739LF_ 1/8 X 1/8	1/8	3.17	1/8	.08	2.0	9/16	.53	13.45	1.24	31.5
739LF_ 1/8 X 1/4	1/8	3.17	1/4	.08	2.0	3/4	.53	13.45	1.39	35.3
739LF_ 3/16 X 1/4	3/16	4.76	1/4	.12	3.0	3/4	.56	14.20	1.41	35.8
739LF_ 1/4 X 1/8	1/4	6.35	1/8	.17	4.2	9/16	.62	15.75	1.30	33.0
739LF_ 1/4 X 1/4	1/4	6.35	1/4	.17	4.2	3/4	.62	15.75	1.46	37.1
739LF_ 1/4 X 3/8	1/4	6.35	3/8	.17	4.2	7/8	.62	15.75	1.55	39.4
739LF_ 1/4 X 1/2	1/4	6.35	1/2	.17	4.2	1 1/16	.62	15.75	1.79	45.5
739LF_ 5/16 X 1/4	5/16	7.93	1/4	.22	5.6	3/4	.66	16.75	1.48	37.6
739LF_ 3/8 X 1/8	3/8	9.52	1/8	.27	6.9	9/16	.69	17.50	1.35	34.3
739LF_ 3/8 X 1/4	3/8	9.52	1/4	.27	6.9	3/4	.69	17.50	1.50	38.1
739LF_ 3/8 X 3/8	3/8	9.52	3/8	.27	6.9	7/8	.69	17.50	1.59	40.4
739LF_ 3/8 X 1/2	3/8	9.52	1/2	.27	6.9	1 1/16	.69	17.50	1.84	46.7
739LF_ 1/2 X 1/4	1/2	12.70	1/4	.37	9.4	3/4	.91	23.10	1.71	43.4
739LF_ 1/2 X 3/8	1/2	12.70	3/8	.37	9.4	7/8	.91	23.10	1.79	45.5
739LF_ 1/2 X 1/2	1/2	12.70	1/2	.37	9.4	1 1/16	.91	23.10	2.05	52.1
739LF_ 5/8 X 1/2	5/8	15.87	1/2	.50	12.7	1 1/16	.97	24.65	2.09	53.1
739LF_ 3/4 X 1/2	3/4	19.05	1/2	.59	15.0	1 1/16	.97	24.65	2.08	52.8
739LF_ 3/4 X 3/4	3/4	19.05	3/4	.59	15.0	1 5/16	.97	24.65	2.16	54.9
739LF_ 3/4 X 1	3/4	19.05	1	.59	15.0	1 5/8	.97	24.65	2.30	58.4
739LF_ 1 X 3/4	1	25.40	3/4	.80	20.3	1 5/16	1.23	31.20	2.39	60.7
739LF_ 1 X 1	1	25.40	1	.80	20.3	1 5/8	1.23	31.20	2.53	64.3
739LF_ 1 1/4 X 1 1/4	* 1 1/4	31.75	1 1/4	1.02	25.9	2 1/8	1.73	43.82	3.06	77.7
739LF_ 1 1/2 X 1 1/2	* 1 1/2	38.10	1 1/2	1.25	31.8	2 3/8	2.14	54.33	3.50	88.9

\* Supplied assembled with Nut and Ferrules. Including low friction paste, see page 91

"D" - Dimension is minimum opening. Dimensions are for reference only, and are subject to change without notice.