


740 HF
SLEEVE FOR 3-PIECE
TUBE ASSEMBLY

S.A.E. 070115

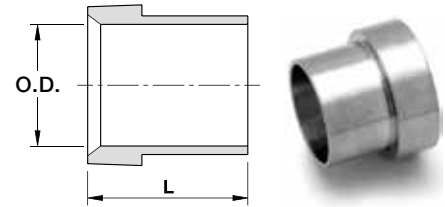


INCH SLEEVE			
Ordering Information	Tube O.D.		L
	inch	inch	mm
740HF SS 1/8"	1/8	0.34	8.6
740HF SS 3/16"	3/16	0.34	8.6
740HF SS 1/4"	1/4	0.41	10.4
740HF SS 5/16"	5/16	0.44	11.2
740HF SS 3/8"	3/8	0.50	12.7
740HF SS 1/2"	1/2	0.56	14.2
740HF SS 5/8"	5/8	0.66	16.8
740HF SS 3/4"	3/4	0.68	17.3
740HF SS 7/8"	7/8	0.76	19.3
740HF SS 1"	1	0.78	19.8
740HF SS 1 1/4"	1 1/4	0.91	23.1
740HF SS 1 1/2"	1 1/2	1.12	28.4
740HF SS 2"	2	1.19	30.2

METRIC SLEEVE		
Ordering Information	Tube O.D.	
	mm	mm
	-	-
	-	-
740HF SS 6MM	6	10.4
740HF SS 8MM	8	11.2
740HF SS 10MM	10	12.7
740HF SS 12MM	12	14.2
740HF SS 16MM	16	16.8
740HF SS 18MM	18	17.3
740HF SS 20MM	20	19.3
740HF SS 25MM	25	19.8
740HF SS 32MM	32	23.1
740HF SS 38MM	38	28.4

Metric sleeves are used with standard nuts & bodies.

741 HF
NUT FOR 3-PIECE
TUBE ASSEMBLY

S.A.E. 070110

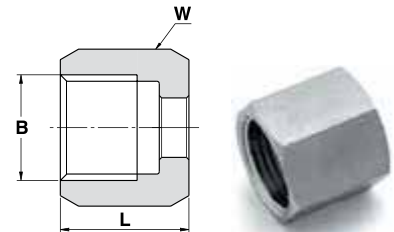

Ordering Information	Tube O.D.		B UN	W Hex. Flat		L	
	inch	mm		inch	inch	mm	
741HF SS 1/8"	1/8	-	5/16 -24	3/8	0.54	13.7	
741HF SS 3/16"	3/16	-	3/8 -24	7/16	0.60	15.2	
741HF SS 1/4" / 6MM	1/4	6	7/16 -20	9/16	0.61	15.5	
741HF SS 5/16" / 8MM	5/16	8	1/2 -20	5/8	0.67	17.0	
741HF SS 3/8" / 10MM	3/8	10	9/16 -18	11/16	0.72	18.3	
741HF SS 1/2" / 12MM	1/2	12	3/4 -16	7/8	0.84	21.3	
741HF SS 5/8" / 16MM	5/8	16	7/8 -14	1	0.97	24.6	
741HF SS 3/4" / 18MM	3/4	18	1 1/16 -12	1 1/4	1.02	25.9	
741HF SS 7/8" / 20MM	7/8	20	1 3/16 -12	1 3/8	1.08	27.4	
741HF SS 1" / 25MM	1	25	1 5/16 -12	1 1/2	1.12	28.4	
741HF SS 1 1/4" / 32MM	1 1/4	32	1 5/8 -12	2	1.22	31.0	
741HF SS 1 1/2" / 38MM	1 1/2	38	1 7/8 -12	2 1/4	1.41	35.8	
741HF SS 2"	2	-	2 1/2 -12	2 7/8	1.74	44.2	

"D" Dimension is minimum opening. Dimensions are for reference only, and are subject to change without notice.