



7639 HF
TUBE PLUG
 S.A.E. 070109

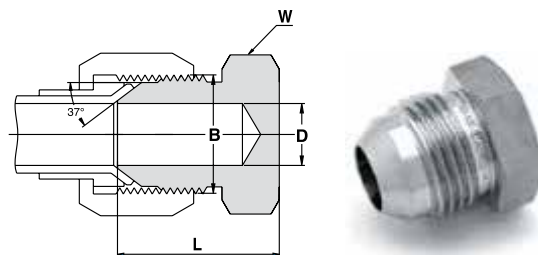

Ordering Information	Tube O.D.		B UN	D		W Hex. Flat	L	
	inch	mm		inch	mm		inch	mm
7639HF SS 1/8"	1/8	-	5/16 - 24	0.062	1.6	7/16	0.70	17.8
7639HF SS 3/16"	3/16	-	3/8 - 24	0.125	3.2	7/16	0.73	18.5
7639HF SS 1/4" / 6MM	1/4	6	7/16 - 20	0.172	4.4	1/2	0.80	20.3
7639HF SS 5/16" / 8MM	5/16	8	1/2 - 20	0.234	6.0	9/16	0.80	20.3
7639HF SS 3/8" / 10MM	3/8	10	9/16 - 18	0.297	7.5	5/8	0.84	21.3
7639HF SS 1/2" / 12MM	1/2	12	3/4 - 16	0.391	9.9	13/16	0.94	23.9
7639HF SS 5/8" / 16MM	5/8	16	7/8 - 14	0.484	12.3	15/16	1.10	27.9
7639HF SS 3/4" / 18MM	3/4	18	1 1/16 - 12	0.609	15.5	1 1/8	1.28	32.5
7639HF SS 7/8" / 20MM	7/8	20	1 3/16 - 12	0.719	18.3	1 1/4	1.31	33.3
7639HF SS 1" / 25MM	1	25	1 5/16 - 12	0.844	21.5	1 3/8	1.33	33.8
7639HF SS 1 1/4" / 32MM	1 1/4	32	1 5/8 - 12	1.078	27.5	1 11/16	1.45	36.8
7639HF SS 1 1/2" / 38MM	1 1/2	38	1 7/8 - 12	1.312	33.0	2	1.65	41.9
7639HF SS 2"	2	-	2 1/2 - 12	1.781	45.0	2 5/8	2.05	52.1

7640 HF
CAP
 S.A.E. 070112

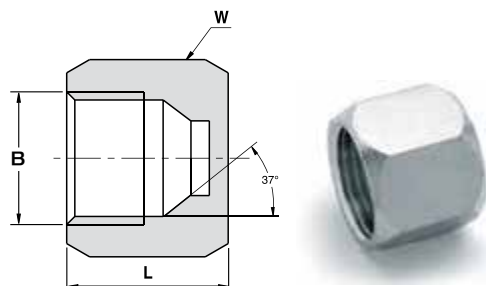

Ordering Information	TUBE O.D.		B UN	W Hex. Flat		L	
	inch	mm		inch	inch	mm	
7640HF SS 1/8"	1/8	-	5/16 - 24	3/8	0.550	12.7	
7640HF SS 3/16"	3/16	-	3/8 - 24	7/16	0.562	14.3	
7640HF SS 1/4" / 6MM	1/4	6	7/16 - 20	9/16	0.594	15.1	
7640HF SS 5/16" / 8MM	5/16	8	1/2 - 20	5/8	0.609	15.5	
7640HF SS 3/8" / 10MM	3/8	10	9/16 - 18	11/16	0.625	15.9	
7640HF SS 1/2" / 12MM	1/2	12	3/4 - 16	7/8	0.750	19.0	
7640HF SS 5/8" / 16MM	5/8	16	7/8 - 14	1	0.844	21.4	
7640HF SS 3/4" / 18MM	3/4	18	1 1/16 - 12	1 1/4	0.906	23.0	
7640HF SS 7/8" / 20MM	7/8	20	1 3/16 - 12	1 3/8	0.969	24.6	
7640HF SS 1" / 25MM	1	25	1 5/16 - 12	1 1/2	1.016	25.8	
7640HF SS 1 1/4" / 32MM	1 1/4	32	1 5/8 - 12	2	1.062	27.0	
7640HF SS 1 1/2" / 38MM	1 1/2	38	1 7/8 - 12	2 1/4	1.188	30.2	
7640HF SS 2"	2	-	1 1/2 - 12	2 7/8	1.438	36.5	

"D" Dimension is the minimum opening. Dimensions are for reference only, and are subject to change without