

Eclipse Series, Painted Stainless Steel - NEMA 4X

Single Door Enclosures with 3-Point Handle

Panel
Sold
Separately



Corrosion Resistant

Wallmount Enclosures

Application

- Designed to enclose electrical and/or electronic equipment and protect against harsh, industrial environments for wallmount applications.
- Impressive styling features like hidden hinges and attractive latching systems make the Eclipse a suitable addition to any high-tech equipment installation.
- A wide range of sizes and practical accessories make this product line a complete package.

Standards

- UL 508 Type 3R, 4, 4X and 12
- CSA Type 3R, 4, 4X and 12
- **Complies with**
 - NEMA 3R, 4, 4X, 12 and 13
 - IEC 60529, IP 66

Construction

- Formed 14 gauge 304 stainless steel.
- Continuously welded seams ground smooth.
- Door stiffeners are provided where required for increased strength and rigidity - designed to also permit additional mounting options.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Doors are secured with a 3 point Handle in 316 stainless with pad lockable feature.
- Doors may be easily removed for modifications and are interchangeable.
- Seamless poured-in place gasket.
- Collar studs provided for mounting inner panel.
- Includes hardware kit with panel mounting nuts and sealing washers for wall mounting holes.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Stainless steel hinge pins and hinges.

Finish


- Cover and enclosure are finished in recoatable smooth RAL 9003 White powder coating inside and out.

Accessories

- Air conditioners...see page **349-367**
- Blowers...see page **392**
- Breather kits...see page **400-401**
- DIN rails...see page **89**
- DIN rail mounting kit...see page **88**
- Door stop kit...see page **453**
- Door support guide...see page **451**
- Drip shield kits...see page **451**
- Filter fans...see page **371-384**
- Heaters...see page **393-396**
- Handles...see page **90**
- Inner panel...see page **87**
- Literature pocket...see page **456**
- Mounting foot kit...see page **90**
- Swing frame...see page **88**
- Swing panel...see page **87**
- Replacement hinge pins
...see page **88**
- Thermostats...see page **397**
- UL/CSA approved hardware kit
...see page **433**

Eclipse Series, Painted Stainless Steel - NEMA 4X

Single Door Enclosures with 3-Point Handle

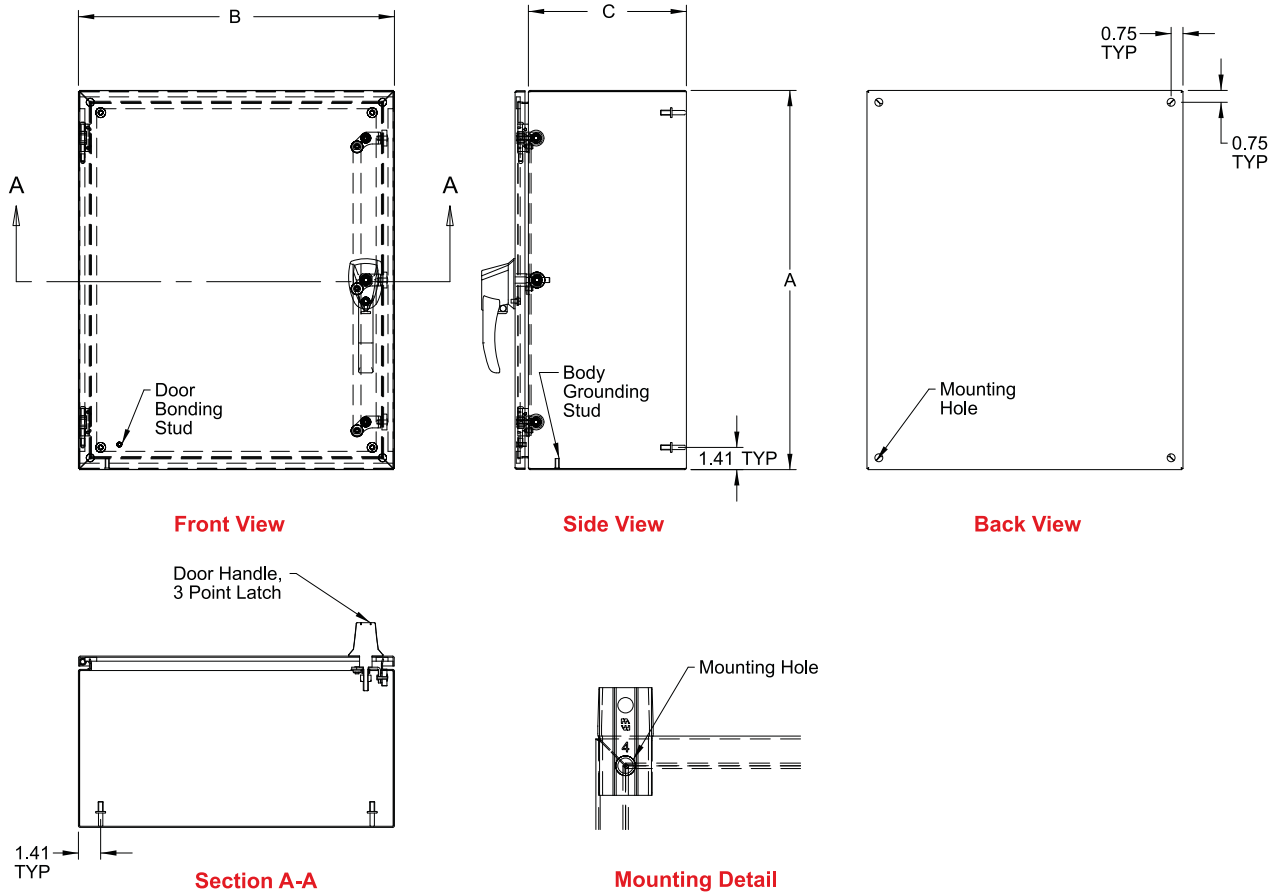

Corrosion Resistant **Wallmount Enclosures**

Part No.	Overall Dimensions			Door/Body Gauge	Opt. Panel Part No.	Panel Size		No. of Hinges	Ship Wt. Lbs.
	A	B	C			D	E		
EN4SD24248SSWH	24.00	24.00	8.00	14	EP2424	22.20	22.20	2	32
EN4SD30248SSWH	30.00	24.00	8.00	14	EP3024	28.20	22.20	3	46
EN4SD242010SSWH	24.00	20.00	10.00	14	EP2420	22.20	18.20	2	38
EN4SD242412SSWH	24.00	24.00	12.00	14	EP2424	22.20	22.20	2	47
EN4SD363012SSWH	36.00	30.00	12.00	14	EP3630	34.20	28.20	3	99
EN4SD363612SSWH	36.00	36.00	12.00	14	EP3636	34.20	34.20	3	104
EN4SD423612SSWH	42.00	36.00	12.00	14	EP4236	40.20	34.20	4	109
EN4SD483612SSWH	48.00	36.00	12.00	14	EP4836	46.20	34.20	4	124
EN4SD483616SSWH	48.00	36.00	16.00	14	EP4836	46.20	34.20	4	135
EN4SD603612SSWH	60.00	36.00	12.00	14	EP6036	58.20	34.20	4	155