



*Quality Products. Service Excellence.*

## Colocation Server Rack Cabinet *CLC Series*


UL 2416 Rated 3,000 lbs (1,361 kg) Weight Capacity



The co-location rack cabinet system from Hammond features four (4) different bay configurations and several roof options. Whether you are leasing the space or want to restrict access to section of your cabinet, the Hammond CLC Series is loaded with innovative features.

### Features

- Available in 44U mounting height.
- Available in 36", 42" and 48" depths.
- One single frame allows multiple bay configurations.
- Compatible with containment system and cable trough accessories.
- Flush mounted doors with locking swing-handle.
- Side cable pass-thru knockouts.
- Optional solid side panels.
- One (1) interchangeable top panels.

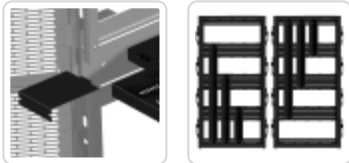

### Specifications

- Cabinet frame constructed in 14-gauge steel cabinet with 12-gauge steel re-enforced corner brackets.
- Cabinet doors and side panels constructed in 16-gauge steel.
- Square hole 19" mounting rails are constructed in 12-gauge steel, include rack unit indicators, and are Zinc-plated to provide superior surface areas for equipment grounding
- Where applicable, the divider shelves are constructed of reinforced 16-gauge steel.
  - The shelves are designed to support the most robust of equipment such as tower servers.
- UL Listed 2416 load rated for up to 3,000 lbs (1,360 kg). Static Load tested to 12,000 lbs (5,443 kg).
- Grounding studs bonded to frame, side panels and doors. Front and rear studs on cabine frame conform to PET.
- Finished in rugged textured black powder paint.
- TAA compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America.



### PCI DSS Compliancy

The CLC series is PCI-Compliant when:

- Multiple cabinets are connected together and/or the open side is closed in using the appropriate side panel (listed in accessory table below).
- The cable manager security plates CLCCMSP are installed.
- The cable manager security covers CLCCMSC are installed.

### Included Components

- Welded steel frame with factory-installed nylon leveling feet, ground studs, and mounting points for optional casters.



- Two (2) pairs (Per bay) of adjustable depth EIA compliant square hole punched mounting rails.
- One (1) removable side panel (with 1/4 turn latches). Additional side panel is sold separately.
- Two (2) (Per bay) perforated front door (65% open area vented) with locking swing-handle.
- Vented bay divider shelf with rear removable panels for vertical PDU installation.



**Note: Cabinet TOP panels are NOT included and are sold separately. (See table below)**

### Accessories

- Tool Free Mounting Plastic Blank Panel
- Adjustable Depth Shelf
- Cabinet Top Panels
- Grounding & Bonding
- Thermal Containment System
- Mounting Screw and Cage Nut Combo-Pack
- Power Distribution Units (PDUs)

### Cabinet Assemblies (Top Panel Not Included)

Part No.		Overall Dimensions			Rack Units	Mounting Dimensions		
		Height	Width	Depth	Per Bay	Height (Per Bay)	Width	Depth
CLC2B36BK	2-Bay	83.02	24.00	36.00	21U	37.88	19.00	34.13
CLC2B42BK	2-Bay	83.02	24.00	42.00	21U	37.88	19.00	40.13
CLC2B48BK	2-Bay	83.02	24.00	48.00	21U	37.88	19.00	46.13
CLC3B36BK	3-Bay	83.02	24.00	36.00	14U	24.75	19.00	34.13
CLC3B42BK	3-Bay	83.02	24.00	42.00	14U	24.75	19.00	40.13
CLC3B48BK	3-Bay	83.02	24.00	48.00	14U	24.75	19.00	46.13
CLC4B36BK	4-Bay	83.02	24.00	36.00	10U	18.19	19.00	34.13
CLC4B42BK	4-Bay	83.02	24.00	42.00	10U	18.19	19.00	40.13
CLC4B48BK	4-Bay	83.02	24.00	48.00	10U	18.19	19.00	46.13

For our Chimney Cabinet version, [Click here](#).

Overall height includes leveling feet.

### Optional Cabinet Components

Use with Frame Depth	Solid Bottom Panel Part No.	Brush Gasket Kit for Bottom Panel Part No.	Solid Top Panel Part No.	8x Brushed Entry with Center Opening Top Panel Part No.	4x Brushed Entry with Rear Opening Top Panel Part No.	Single Solid Side Panel Part No.
36.00	CLCBP36BK	CLCBG36BK	CLCST36BK	CLC8T36BK	CLC4T36BK	CLCSP36BK
42.00	CLCBP42BK	CLCBG42BK	CLCST42BK	CLC8T42BK	CLC4T42BK	CLCSP42BK
48.00	CLCBP48BK	CLCBG42BK	CLCST48BK	CLC8T48BK	CLC6T48BK	CLCSP42BK

### CLC Specific Accessories

Part No.	Description
CLCCMSP	Cable manager security plate (includes 12 plates, 54 screws, 1 hex key)
CLCCMSC	Cable manager security cover (includes 2 covers, 4 screws, 1 hex key)
CLCTRAY	Cable Tray works as a top cable tray and hides cables view.
GKIT	Cabinet Baying/Ganging/Joining Kit
C4K-Z4	Cabinet Bolt-Down Kit.

Data subject to change without notice

4/12/2021

Colocation Server Rack Cabinet (CLC Series) - Hammond Mfg.

Tags: **Co-location Cabinet, Server Rack, Server Cabinet, Cabinet Enclosure, Co-lo Cabinet, Colo Enclosures, Data Center, Collocation Cabinet**

© 2021. Hammond Manufacturing Ltd. All rights reserved.