



Quality Products. Service Excellence.

Fan Kits *FK Series*




Extend the life of your rack mount equipment by increasing airflow within your server rack or cabinet. Hammond Fan Kits are available with one (1) or two (2) fans. Our fan kits come with the essentials and include chrome fan grills for added safety. Our fans run on AC Power and are available in both high CFM or low-decibel for audio/visual and office environments.

If your fans will be mounted more than 12" apart when using the kits with two (2) fans, refer to the DNFC Fan Cord series listed in our accessories below for a longer single connection wire.

Features

- Kit includes:
 - One (1) or Two (2) Ball bearing type fan(s).
 - Two (2) chrome metal grills per fan.
 - One (1) cord assembly.
 - One (1) or Two (2) packages of mounting hardware.
- Fan component is recognized to UL 507 and CSA certified.
- Decibel (db) rating is measured at 12" to 24" from the source.
- Assembled in North America.

Gallery

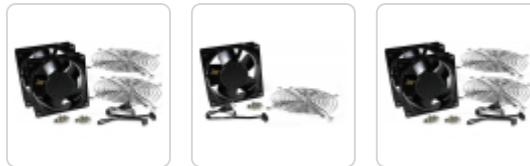

Accessories

- Filter Fan Grills
- Fan Cords

DNFK - High CFM Fans

Part No.	Fan(s) Included	Fan Width	CFM	Noise (dB)	Corded Plug	Fan Guards Included
DNFK1AC120	1	4.72	100	56	1 x 72" NEMA 1-15P	2
DNFK2AC120	2	4.72	200	60	1 x 12" daisy chain with NEMA 1-15P 72" lead	4

Each fan is rated for 22W - 0.57A at 115Vac.

AVFK - Low-Decibel Fans

Part No.	Fan(s) Included	Fan Width	Total CFM	Noise (dB)	Corded Plug	Fan Guards Included
AVFK1AC120	1	4.72	58	30	1 x 72" NEMA 1-15P	2
AVFK2AC120	2	4.72	116	30	1 x 12" Daisy Chain with NEMA 1-15P 72" lead	4

Data subject to change without notice

