



Quality Products. Service Excellence.

Vertical Finger Cable Manager with Door *FRCM Series*

For use with Open Frame Racks



The vertical Fingered Rack Cable Manager (FRCM) from Hammond Mfg can be used for managing sensitive fiber, large bundles of Cat6a and most coax cables combined into a structurally strong vertical cable manager. The easy to install, double-hinged door keeps the rack system visually organized and can be removed for ease of cable installation.

Features:

- High density cable managers may be installed back to back and ganged side by side.
- Manager is open at front allowing easy removal of cables after initial installation.
- Sturdy T-shape steel fingers are spaced at 2RU and provide support for large cable bundles and heavy gauge cables.
- Separated space easily allows for cables to be added or removed without fishing the cable.
- Includes clip-on plastic finger guards (ships loose) for cable bend radius.
- Slam-latch door opens to the right or left and is easily removed. *(Rolling change from February 2020)*
- Mount either single unit or two units for front and rear cable management.
- Includes cable mounting lances for hook and loop cable organization.
- Openings in the back of the manager allow cables to pass easily front to rear. Install optional cable rings (CMRC Series) for rear cable management.

Specifications:

- Manager body is constructed of 16-gauge steel while manager door is constructed of 18-gauge steel. Optional spool shall be extruded aluminum.
- Compatible with Hammond **DNRRHDW**, **DC4R**, **DRZ4**, **RB-2P** and **RB-2PA** Series of open frame racks.
- Finished in textured black power coat finish.
- TAA compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America.




Looking for a **double-sided manager**? Check out the **VFM Series**.

Gallery



Accessories

- Vertical Cable Ring
 - Cable Channel Divider
 - Hook and Loop Roll
- Cable Spool
 - Vertical Cable Manager Extensions

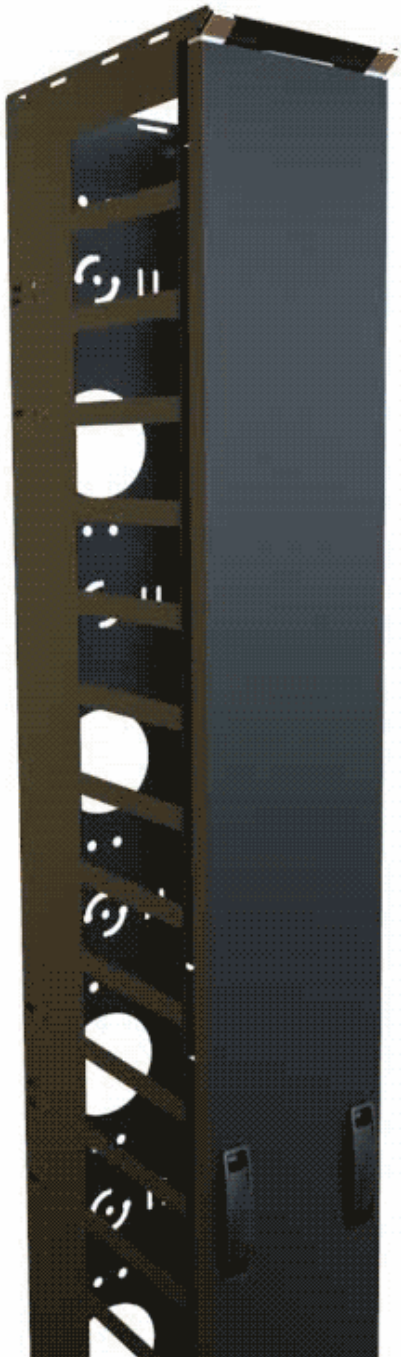

Part No.	Overall Dimensions (Inches)			Mounting Dimensions		Door Included
	Height	Width	Depth	Units	Rack Units	
FRCM44U88	82.00	8.00	9.64	77.00	44	Yes
FRCM44U812	82.00	8.00	13.64	77.00	44	Yes
FRCM44U1012	82.00	10.00	13.64	77.00	44	Yes

Part No.	Overall Dimensions (Inches)			Mounting Dimensions		Door Included
	Height	Width	Depth	Units	Rack Units	
FRCM44U128	82.00	12.00	9.64	77.00	44	Yes
FRCM44U1212	82.00	12.00	13.64	77.00	44	Yes

Estimated Cable Fill Capacities

Part No.	Description	Recommended Cable Fill (50% Fill Ratio)		Maximum Cable Fill (100% Fill Ratio)	
		Cat 6	Cat 6a	Cat 6	Cat 6a
FRCM44U88	Channel Opening	293	204	587	407
	Finger Opening	65	45	130	91
	Rear Pass Through	103	71	206	143
FRCM44U812	Channel Opening	416	289	831	577
	Finger Opening	92	64	183	127
	Rear Pass Through	103	71	206	143
FRCM44U1012	Channel Opening	554	385	1108	770
	Finger Opening	92	64	183	127
	Rear Pass Through	103	71	206	143
FRCM44U128	Channel Opening	587	407	1173	815
	Finger Opening	65	45	130	91
	Rear Pass Through	103	71	206	143
FRCM44U1212	Channel Opening	831	577	1662	1154
	Finger Opening	92	64	183	127
	Rear Pass Through	103	71	206	143

Tags: **2-Hinged, Dual Hinged**

Data subject to change without notice

© 2021. Hammond Manufacturing Ltd. All rights reserved.