




*Quality Products. Service Excellence.*

## Adjustable Rack Mount DIN Rail Kit *RMAD Series*

### Features

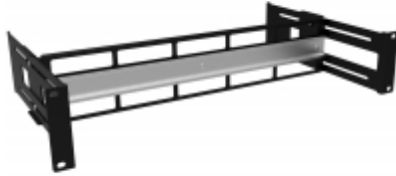

- Mounts to standard EIA 19" rack rails.
- Includes a 0.3" thick, top-hat standard DIN rail.
- Knockdown design ships unassembled for easy handling and shipping protection.
- TAA compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America.

### RMAD (Light Duty) Features



- Constructed of 14 and 16 gauge steel.
- Provides up to 8.38" of adjustable depth for DIN rail-mounted equipment.
- Cutouts on both the rear and sides provide cable pass through.
- Suggested load rating of up to 26 lbs.
- Finished in rugged textured black powder paint.

### RMHD (Heavy Duty) Features



- Constructed of 14-gauge steel.
- Provides up to 8.00" of depth options for DIN rail-mounted equipment.
- Suggested load rating of up to 100 lbs.
- Finished in smooth black powder paint.

### Accessories

- Mounting Hardware
- Hook and Loop Roll





Part No.	Mounting Dimensions			DIN Rail Overall Dimensions		Weight Capacity
	Height	Rack Units	Depth	Width	Depth	
RMAD19003BK	3.50	2U	11.25	17.18	0.30	26 lbs
RMHD19003BK	3.50	2U	9.25	16.88	0.30	100 lbs

Tags: **Industrial Automation Bracket**

*Data subject to change without notice*

© 2021. Hammond Manufacturing Ltd. All rights reserved.