


Fir Tree Mount Cable Ties

1-Piece Cable Ties with Fir Tree Mount with Disc

One-piece mounting ties offer a complete solution by both bundling and mounting wires, cables and tubes. The fir tree mount provides low insertion force with a high extraction force. Outside serrations on the cable tie leave a smooth interior surface that's gentler on sensitive wire insulation. The unique head design allows the cable tie to firmly hold bundles as small as .06" diameter. The disc offers added protection against debris.

Features and Benefits

- All-in-one bundling and fastening solution reduces costs and assembly time.
- Disc feature provides anti-rattle protection in high-vibration applications.

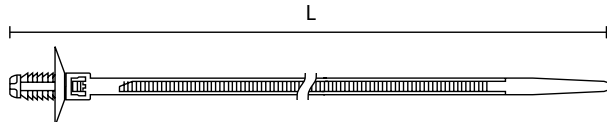

PART NO.	TYPE	Min. Mounting Hole Dia. in. (mm)	Max. Mounting Hole Dia. in. (mm)	Length (L) in. (mm)	Min. Tensile Strength lbs. (N)	Max. Bundle Diameter in. (mm)	Panel Thickness in. (mm)	Material	Color	Pkg. Qty.
157-00052	T50ROSFT6LGU	0.3 (6.5)	0.3 (7.2)	8.6 (220.0)	50.0 (225.0)	2.0 (50.0)	0.02 – 0.33 (0.6 – 8.5)	PA66HS	Black	500
157-00306	T50ROSFT6.5LG-E4	0.2 (6.1)	0.3 (6.9)	8.6 (218.1)	50.0 (225.0)	2.0 (50.0)	0.02 – 0.32 (0.6 – 8.3)	PA66HIRHS	Black	500
155-05800	T50SOSFT6E	0.3 (6.5)	0.3 (7.0)	6.0 (160.0)	50.0 (150.0)	1.4 (32.0)	0.03 – 0.12 (0.75 – 3.0)	PA66HIRHS	Black	1500
157-00050	T50SOSFT6LGU	0.3 (6.5)	0.3 (7.2)	6.5 (169.0)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.33 (0.6 – 8.5)	PA66HS	Black	500
157-00376	T50SOSFT6.5-E4	0.2 (6.1)	0.3 (6.9)	6.3 (161.5)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.17 (0.6 – 4.2)	PA66HS	Black	1000
157-00355	T50SOSFT6.5LG-E4	0.2 (6.1)	0.3 (6.9)	6.6 (167.9)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.32 (0.6 – 8.3)	PA66HIRHS	Natural	4000
157-00296		0.2 (6.1)	0.3 (6.9)	6.6 (167.9)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.32 (0.6 – 8.3)	PA66HIRHSUV	Black	4000
157-00373		0.2 (6.1)	0.3 (6.9)	6.6 (167.9)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.32 (0.6 – 8.3)	PA66HIRHSUV	Black	500
157-00303		0.2 (6.1)	0.3 (6.9)	6.6 (168.0)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.32 (0.6 – 8.3)	PA66HS	Gray	5000
157-00287	T50SOSFT6.5LG-E4X	0.3 (6.3)	0.3 (7.0)	6.5 (165.0)	50.0 (225.0)	1.4 (35.0)	0.03 – 0.28 (0.7 – 7.0)	PA66HS	Black	500
157-00359		0.3 (6.3)	0.3 (7.0)	6.5 (165.0)	50.0 (227.0)	1.4 (35.0)	0.03 – 0.28 (0.7 – 7.0)	PA66HS	Black	500
157-00302		0.3 (6.3)	0.3 (7.0)	6.5 (165.0)	50.0 (225.0)	1.4 (35.0)	0.03 – 0.28 (0.7 – 7.0)	PA66HIRHSUV	Black	4000
157-00115	T50SOSFT8E	0.3 (8.0)	0.3 (8.5)	6.4 (163.0)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.24 (0.6 – 6.0)	PA46	Gray	1000
157-00072		0.3 (8.0)	0.3 (8.5)	6.4 (163.0)	50.0 (225.0)	1.4 (35.0)	0.02 – 0.24 (0.6 – 6.0)	PA66HS	Black	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.
 Installation tools: EVO7, EVO7SP, EVO9, EVO9HT, MK7P, MK7HT, MK9P.