

Bundling and Securing

Self-Affixing Cable Ties




Stud Mount Cable Ties

Oval Shaped Variable Stud Mount Ties

Oval Shaped Stud Mount's special design allows for a .20" (5.5 mm) lateral adjustment, allowing for any misalignment of the stud or incorrect position of the tie on the cables. The mount allows it to be installed onto a weld stud without the use of any tools.

Features and Benefits

- Head allows for a .2" lateral adjustment on stud during installation.
- Quick and easy installation ideal for manufacturing environment.

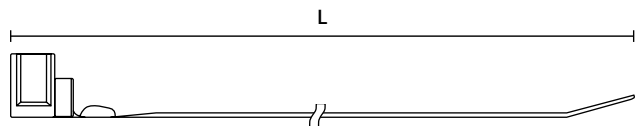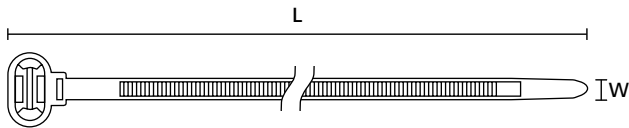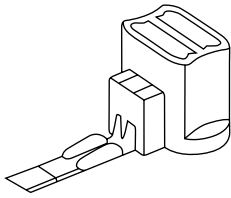

PART NO.	TYPE	Stud Dia. in.	Stud Dia. (mm)	Min. Tensile Strength lbs. (N)	Length (L) in. (mm)	Max. Bundle Diameter in. (mm)	Width (W) in. (mm)	Material	Color	Pkg. Qty.
155-46302	T50SOSSB6HE	0.24	(6.0)	50.0 (170.0)	6.0 (160.0)	1.4 (35.0)	0.2 (4.7)	PA66HS	Black	500
157-00151	T50SOSSB5-High-E-C-CC	0.20, 0.24	(5.0), M6	225.0 (225.0)	6.6 (167.0)	1.4 (35.0)	0.2 (5.0)	PA66HS	Gray	5000
157-00105		0.20	(5.0)	50.0 (225.0)	6.6 (167.0)	1.4 (35.0)	0.2 (5.0)	PA66HS	Black	3000
157-00106	T50SOSSB5-High-E-O-US	0.20	(5.0)	50.0 (225.0)	6.6 (167.0)	1.4 (35.0)	0.2 (5.0)	PA66HS	Black	3000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.
 Installation tools: EVO7, EVO7SP, EVO9, EVO9HT, MK7P, MK7HT, MK9P.