


### Stainless Steel Ratchet P-Clamp

**Size B - For bundle diameters from 1/2" to 3/4" (12.7 mm to 19.5 mm)**

The Ratchet P-Clamp family offers versatility when managing wires, cables and hoses. The robust design and durable materials make it ideal for heavy duty applications, both indoors and out. The one-piece adjustable clamp can be closed by hand to the desired diameter. The release feature provides easy and nondestructive removal of cables simply by using a flat-head screwdriver. This nondestructive release allows the clamp to be reused without removing or replacing any bolts or screws. The Ratchet P-Clamp is offered in four sizes and multiple mounting configurations.

#### Features and Benefits

- One-piece ratchet closure design allows for easy installation during pre- or final assembly.
- Four sizes and multiple configurations handle a wide range of diameters and applications, reducing part inventory.
- Clamp interior is designed to guide and center bundle to reduce pinching.
- Easy release feature allows for quick adjustments and maintenance.
- Impact modified, heat and UV stabilized PA66 provides long-term durability, indoors and out.
- Stainless steel mounting plate tolerates high torque mounting, resists galvanic corrosion with dissimilar metals, and harsh chemicals.

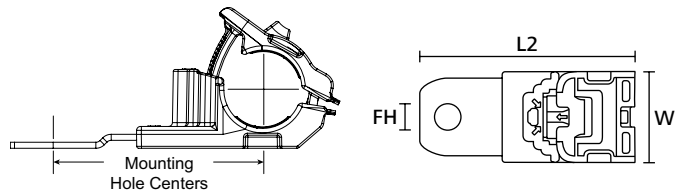

PART NO.	TYPE	Min. Tensile Strength lbs. (N)	Mounting Hole Centers in. (mm)	Mounting Hole Dia. in. (mm)	Angle/Length	Length (L2) in. (mm)	Width (W) in. (mm)	Material	Pkg. Qty.
151-01955*	RCB15SM6SS	100.0 (445.0)	2.2 (56.5)	0.3 (6.5)	15 ° Short	3.4 (86.9)	1.4 (34.9)	PA66HIRHSUV, SS304	280
151-01956*	RCB15SM8SS	100.0 (445.0)	2.2 (56.5)	0.3 (8.31)	15 ° Short	3.4 (86.9)	1.4 (34.9)	PA66HIRHSUV, SS304	280
151-01957*	RCB15SM10SS	100.0 (445.0)	2.2 (56.5)	0.4 (10.29)	15 ° Short	3.4 (86.9)	1.4 (34.9)	PA66HIRHSUV, SS304	280
151-01958*	RCB15SM12SS	100.0 (445.0)	2.2 (56.5)	0.5 (12.95)	15 ° Short	3.4 (86.9)	1.4 (34.9)	PA66HIRHSUV, SS304	280
151-01963*	RCB30LM6SS	100.0 (445.0)	2.9 (73.5)	0.3 (6.5)	30 ° Long	4.1 (103.2)	1.4 (34.9)	PA66HIRHSUV, SS304	200
151-01964*	RCB30LM8SS	100.0 (445.0)	2.9 (73.5)	0.3 (8.31)	30 ° Long	4.1 (103.2)	1.4 (34.9)	PA66HIRHSUV, SS304	200
151-01965*	RCB30LM10SS	100.0 (445.0)	2.9 (73.5)	0.4 (10.29)	30 ° Long	4.1 (103.2)	1.4 (34.9)	PA66HIRHSUV, SS304	200
151-01966*	RCB30LM12SS	100.0 (445.0)	2.9 (73.5)	0.5 (12.95)	30 ° Long	4.1 (103.2)	1.4 (34.9)	PA66HIRHSUV, SS304	200
151-01959*	RCB30SM6SS	100.0 (445.0)	1.9 (48.8)	0.3 (6.5)	30 ° Short	3.1 (78.5)	1.4 (34.9)	PA66HIRHSUV, SS304	280
151-01960*	RCB30SM8SS	100.0 (445.0)	1.9 (48.8)	0.3 (8.31)	30 ° Short	3.1 (78.5)	1.4 (34.9)	PA66HIRHSUV, SS304	280
151-01961*	RCB30SM10SS	100.0 (445.0)	1.9 (48.8)	0.4 (10.29)	30 ° Short	3.1 (78.5)	1.4 (34.9)	PA66HIRHSUV, SS304	280

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.  
 \*This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.