

Bundling and Securing

Cable Ties

 

Standard Cable Ties

T40 - T50 Series in Natural and Black

T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. The bent tail design allows quick and simple installations by hand. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.

Features and Benefits

- Engineered and manufactured for maximum performance and quality.
- Made from 100% high-quality plastic to ensure efficient recycling.
- Inside serration for a strong grip onto bundles.
- Easy application either manually or with a tensioning tool.
- Bent tail allows for simpler insertion.

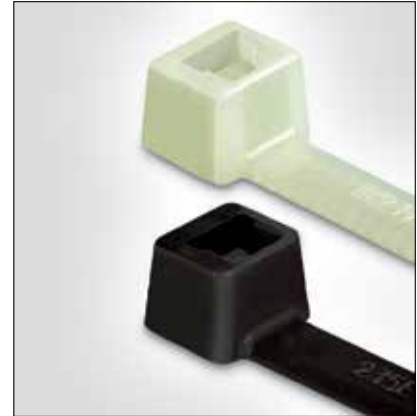

PART NO.	TYPE	Min. Tensile Strength lbs. (N)	Length (L) in. (mm)	Max. Bundle Diameter in. (mm)	Width (W) in. (mm)	Material	Color	Pkg. Qty.
T40R0C2*	T40R(U)	40.0 (180.0)	8.3 (212.0)	2.2 (55.9)	0.2 (4.0)	PA66	Black	100
T40R0M4*		40.0 (180.0)	8.3 (212.0)	2.2 (55.9)	0.2 (4.0)	PA66	Black	1000
T40R9C2*		40.0 (180.0)	8.3 (212.0)	2.2 (55.9)	0.2 (4.0)	PA66	Natural	100
T40R9M4*		40.0 (180.0)	8.3 (212.0)	2.2 (55.9)	0.2 (4.0)	PA66	Natural	1000
T40I0C2*	T40I	40.0 (180.0)	11.6 (295.0)	3.2 (80.0)	0.2 (4.0)	PA66	Black	100
T40I0M4*		40.0 (180.0)	11.6 (295.0)	3.2 (80.0)	0.2 (4.0)	PA66	Black	1000
T40I9C2*		40.0 (180.0)	11.6 (295.0)	3.2 (80.0)	0.2 (4.0)	PA66	Natural	100
T40I9M4*		40.0 (180.0)	11.6 (295.0)	3.2 (80.0)	0.2 (4.0)	PA66	Natural	1000
T40L0C2*	T40L	40.0 (180.0)	14.6 (370.0)	4.1 (104.9)	0.2 (4.0)	PA66	Black	100
T40L0M4*		40.0 (180.0)	14.6 (370.0)	4.1 (104.9)	0.2 (4.0)	PA66	Black	1000
T40L9C2*		40.0 (180.0)	14.6 (370.0)	4.1 (104.9)	0.2 (4.0)	PA66	Natural	100
T40L9M4*		40.0 (180.0)	14.6 (370.0)	4.1 (104.9)	0.2 (4.0)	PA66	Natural	1000
T50S0C2*	T50S	50.0 (225.0)	6.3 (160.0)	1.4 (35.0)	0.2 (4.6)	PA66	Black	100
T50S0M4*		50.0 (225.0)	6.3 (160.0)	1.4 (35.0)	0.2 (4.6)	PA66	Black	1000
T50S9C2*		50.0 (225.0)	6.3 (160.0)	1.4 (35.0)	0.2 (4.6)	PA66	Natural	100
T50S9M4*		50.0 (225.0)	6.3 (160.0)	1.4 (35.0)	0.2 (4.6)	PA66	Natural	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Installation tools: EVO7, EVO7SP, EVO9, EVO9HT, MK7P, MK7HT, MK9P. Military black available. Contact HellermannTyton for more information. *This product meets UL standards. Please see appendix for specific file numbers. *This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.