

# Routing, Protection and Insulation

## Wiring Duct

### Slotted Wall Duct

#### Slotted Wall Wiring Duct - Adhesive Back


HellermannTyton Slotted Wall Duct features breakaway fingers that provide additional access for wire leads. Each section of the duct is provided with two score lines. The upper score line is used to break away fingers when a wider opening is required. The lower score line allows the sidewall to be smoothly cut for joints and Ts. Pressure-sensitive, rubber-based adhesive backing aids in temporary positioning.

#### Features and Benefits

- Strong fingers prevent unintended breaking.
- Fingers are easily deflected outward, allowing easier positioning of the wires.
- Restricted opening prevents unintended removal of wires and permits any individual wire to be traced without disconnection.
- Non-permanent adhesive allows repositioning prior to final installation.
- Optional covers snap on and off easily, and their nonslip lining ensures they stay in place even under vibration.



<b>MATERIAL</b>	Polyvinylchloride (PVC)
<b>Flammability</b>	Self-Extinguishing
<b>Operating Temperature</b>	+122°F (+50°C)

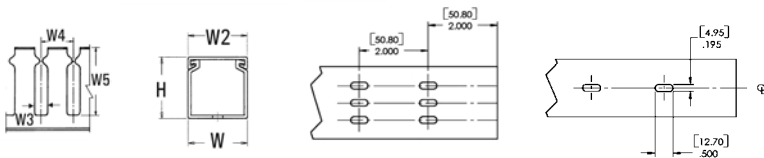

PART NO.	TYPE	Width (W) in. (mm)	Height (H) in. (mm)	Width (W2) in. (mm)	Width (W3) in. (mm)	Width (W4) in. (mm)	Width (W5) in. (mm)	Color	Pkg. Qty.
181-11016*	SLA1X1	1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	0.8 (19.1)	Black	120 ft
181-11017*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	0.8 (19.1)	Gray	30 ft
181-11019*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	0.8 (19.1)	Gray	120 ft
181-11021*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	0.8 (19.1)	White	120 ft
181-00564*	SLA1X1.5	1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	1.2 (30.2)	Black	120 ft
181-11509*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	1.2 (30.2)	Gray	120 ft
181-11510*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	1.2 (30.2)	White	30 ft
181-11511*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.4 (10.2)	1.0 (25.4)	1.2 (30.2)	White	120 ft

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes. For wire fill capacities and wiring duct material properties, see appendix. Sold in 6-ft. lengths. Adhesive back duct orders are non-cancellable and non-returnable. \*This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.