

Routing, Protection and Insulation

Wiring Duct

High Density Slotted Wall Duct

High Density Slotted Wall Wiring Duct


HellermannTyton Pro-Duct High-Density, Slotted-Wall Wiring Duct features narrow fingers equaling a 2 to 1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

Features and Benefits

- Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.
- Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.
- Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.
- Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.



MATERIAL	Polyvinylchloride (PVC)
Flammability	Self-Extinguishing
Operating Temperature	+122°F (+50°C)

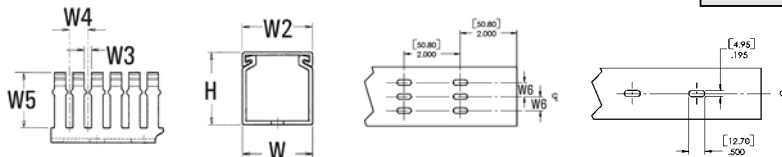

PART NO.	TYPE	Width (W) in. (mm)	Height (H) in. (mm)	Width (W2) in. (mm)	Width (W3) in. (mm)	Width (W4) in. (mm)	Width (W5) in. (mm)	Color	Pkg. Qty.
184-05525*	SLHD1X1	1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Black	30 ft
181-00597*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Black	120 ft
184-11000*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Gray	30 ft
184-11004*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Gray	120 ft
184-11005*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	White	30 ft
184-11006*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	White	120 ft
184-05534*	SLHD1X1.5	1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	1.2 (30.2)	Black	30 ft
181-00598*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	1.2 (30.2)	Black	120 ft
184-11007*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	1.2 (30.2)	Gray	30 ft
184-11010*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	1.2 (30.2)	Gray	120 ft
184-11011*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	1.2 (30.2)	White	30 ft
184-11012*		1.0 (25.4)	1.6 (39.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	1.2 (30.2)	White	120 ft

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

For wire fill capacities and wiring duct material properties, see appendix. Sold in 6-ft. lengths. *This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.