

High Density Slotted Wall Duct

High Density Slotted Wall Wiring Duct - Adhesive Back


HellermannTyton High Density Slotted Wall Duct features narrow breakaway fingers, designed at a 2-to-1 ratio compared to standard slotted duct, providing additional access for wire leads. Narrower fingers better accommodate compact designs and components. Pressure-sensitive, rubber-based adhesive backing aids in temporary positioning.

Features and Benefits

- Narrow fingers reduce fanning of wires to terminal blocks, providing a neater appearance.
- Each finger features a double restriction to hold wires in the bottom portion of the duct, simplifying installation.
- Mounting holes are uniform in size to those in slotted and solid wall duct but are provided every two inches to accommodate compact designs and provide ease of installation.
- Nonpermanent adhesive allows repositioning prior to final installation.



MATERIAL	Polyvinylchloride (PVC)
Flammability	Self-Extinguishing
Operating Temperature	+122°F (+50°C)

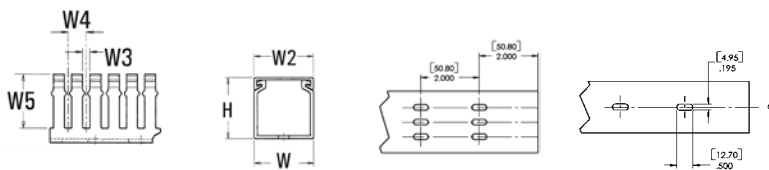

PART NO.	TYPE	Width (W) in. (mm)	Height (H) in. (mm)	Width (W2) in. (mm)	Width (W3) in. (mm)	Width (W4) in. (mm)	Width (W5) in. (mm)	Color	Pkg. Qty.
181-00637*	SLHDA1X1	1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Black	120 ft
184-11001*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Gray	30 ft
181-00621*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	Gray	120 ft
184-11002*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	White	30 ft
181-00622*		1.0 (25.4)	1.1 (26.9)	1.0 (25.4)	0.2 (4.1)	0.4 (10.2)	0.8 (19.1)	White	120 ft

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes. For wire fill capacities and wiring duct material properties, see appendix. Sold in 6-ft. lengths. Adhesive back duct orders are non-cancellable and non-returnable. *This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.