

 

Heavy Duty Releasable Cable Ties

RT250 Heavy Duty Releasable Cable Ties

HellermannTyton heavy-duty releasable cable ties offer a release feature in the head allowing for easy access to wire bundles when changes are necessary. The head design guarantees high tensile strength even after repeated use, as well as a low insertion force. For high volume applications, tensioning tools are available to ensure consistent and safe installation.

Features and Benefits

- Special extended-pawl design offers a release feature for quick and easy access to wire bundles.
- Head design provides high tensile strength with very low insertion force even after repeated use.
- Buckle feature on head allows excess strap to be tucked away after installation.

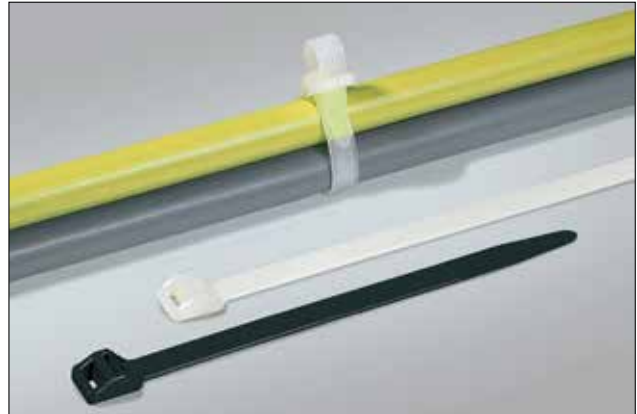

| PART NO. | TYPE | Min. Tensile Strength lbs. (N) | Length (L) in. (mm) | Max. Bundle Diameter in. (mm) | Width (W) in. (mm) | Material | Color | Pkg. Qty. |
|--------------|---------|--------------------------------|---------------------|-------------------------------|--------------------|----------|---------|-----------|
| RT250S0X2* | RT250S | 250.0 (1,115.0) | 9.1 (230.0) | 2.0 (50.0) | 0.5 (12.5) | PA66 | Black | 25 |
| RT250S9X2* | | 250.0 (1,115.0) | 9.1 (230.0) | 2.0 (50.0) | 0.5 (12.5) | PA66 | Natural | 25 |
| RT250S0UVX2 | | 250.0 (1,115.0) | 9.1 (230.0) | 2.0 (50.0) | 0.5 (12.5) | PA66UV | Black | 25 |
| RT250R0X2* | RT250R | 250.0 (1,115.0) | 20.3 (515.0) | 4.9 (125.0) | 0.5 (12.5) | PA66 | Black | 25 |
| RT250R9X2* | | 250.0 (1,115.0) | 20.3 (515.0) | 4.9 (125.0) | 0.5 (12.5) | PA66 | Natural | 25 |
| RT250R0UVX2 | | 250.0 (1,115.0) | 20.3 (515.0) | 4.9 (125.0) | 0.5 (12.5) | PA66UV | Black | 25 |
| RT250M0X2* | RT250M | 250.0 (1,115.0) | 22.3 (565.3) | 5.9 (150.0) | 0.5 (12.5) | PA66 | Black | 25 |
| RT250M9X2* | | 250.0 (1,115.0) | 22.3 (565.3) | 5.9 (150.0) | 0.5 (12.5) | PA66 | Natural | 25 |
| RT250M0UVX2* | | 250.0 (1,115.0) | 22.3 (565.3) | 5.9 (150.0) | 0.5 (12.5) | PA66UV | Black | 25 |
| RT250I0X2* | RT250I | 250.0 (1,115.0) | 28.7 (730.0) | 8.0 (203.0) | 0.5 (12.5) | PA66 | Black | 25 |
| RT250I9X2* | | 250.0 (1,115.0) | 28.7 (730.0) | 8.0 (203.0) | 0.5 (12.5) | PA66 | Natural | 25 |
| RT250I0UVX2 | | 250.0 (1,115.0) | 28.7 (730.0) | 8.0 (203.0) | 0.5 (12.5) | PA66UV | Black | 25 |
| RT250L0X2* | RT250L | 250.0 (1,115.0) | 34.6 (880.0) | 10.0 (254.0) | 0.5 (12.5) | PA66 | Black | 25 |
| RT250L9X2* | | 250.0 (1,115.0) | 34.6 (880.0) | 10.0 (254.0) | 0.5 (12.5) | PA66 | Natural | 25 |
| RT250L0UVX2 | | 250.0 (1,115.0) | 34.6 (880.0) | 10.0 (254.0) | 0.5 (12.5) | PA66UV | Black | 25 |
| RT250XL0X2* | RT250XL | 250.0 (1,115.0) | 40.6 (1,030.0) | 12.0 (305.0) | 0.5 (12.5) | PA66 | Black | 25 |
| RT250XL9X2* | | 250.0 (1,115.0) | 40.6 (1,030.0) | 12.0 (305.0) | 0.5 (12.5) | PA66 | Natural | 25 |
| RT250XL0UVX2 | | 250.0 (1,115.0) | 40.6 (1,030.0) | 12.0 (305.0) | 0.5 (12.5) | PA66UV | Black | 25 |

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.
Installation tools: EVO9, EVO9HT, MK9P. *This product meets UL standards. Please see appendix for specific file numbers.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.