

# Bundling and Securing

## Self-Affixing Cable Ties


### Arrowhead Mount Cable Ties

#### Domed Push Mount Ties

The Domed Push Mount Tie provides a tight, rattle-free installation and acts as a seal to keep out dust and debris. One-piece mounting ties offer a complete solution by both bundling cable and at the same time providing a mounting solution.

#### Features and Benefits

- An all-in-one bundling and fixing solution reduces costs.
- Disc provides secure insertion and minimizes access of dust, dirt and water.

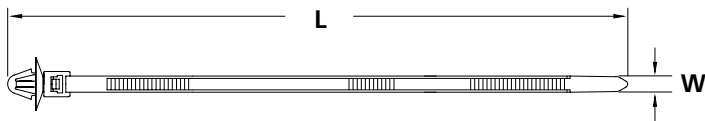

PART NO.	TYPE	Min. Tensile Strength lbs. (N)	Mounting Hole Dia. in. (mm)	Panel Thickness in. (mm)	Length (L) in. (mm)	Max. Bundle Diameter in. (mm)	Width (W) in. (mm)	Material	Color	Pkg. Qty.
126-02300	T50SST5	50.0 (225.0)	0.24 - 0.26 (6.1 - 6.5)	0.03 - 0.06 (0.7 - 1.5)	7.0 (170.0)	1.2 (31.0)	0.2 (4.6)	PA66	Natural	1000
126-00017		50.0 (225.0)	0.24 - 0.26 (6.1 - 6.5)	0.03 - 0.06 (0.7 - 1.5)	7.0 (170.0)	1.2 (31.0)	0.2 (4.6)	PA66HS	Black	1000
150-15395		50.0 (225.0)	0.24 - 0.26 (6.1 - 6.5)	0.03 - 0.06 (0.7 - 1.5)	7.0 (170.0)	1.2 (31.0)	0.2 (4.6)	PA66HIRHS	Black	1000
126-00015	T50SDOP	50.0 (225.0)	0.24 - 0.27 (6.2 - 12.2)	0.04 - 0.08 (1.0 - 1.9)	6.3 (160.0)	1.2 (30.0)	0.2 (5.0)	PA66HS	Black	500
126-00114	T50ROSAH6U	50.0 (225.0)	0.24 - 0.27 (6.1 - 6.9)	0.07 - 0.12 (1.8 - 3.0)	8.5 (215.9)	2.0 (50.0)	0.2 (5.0)	PA66HIRHS	Natural	500
126-00115		50.0 (225.0)	0.24 - 0.27 (6.1 - 6.9)	0.07 - 0.12 (1.8 - 3.0)	8.5 (215.9)	2.0 (50.0)	0.2 (5.0)	PA66HIRHS	Black	500
126-03102	T50SOSSFT6.5E	50.0 (225.0)	0.25 - 0.26 (6.3 - 6.7)	0.07 - 0.10 (1.9 - 2.5)	6.0 (158.8)	1.2 (30.0)	0.2 (4.6)	PA66HS	Black	500
T50SD60HSH4	T50SD6	50.0 (200.0)	0.25 - 0.30 (6.3 - 7.5)	0.02 - 0.07 (0.6 - 1.8)	6.0 (160.0)	1.2 (31.0)	0.2 (5.0)	PA66HS	Black	500
111-85850	T50MD7	50.0 (225.0)	0.27 - 0.28 (6.8 - 7.2)	0.03 - 0.08 (1.2 - 2.0)	9.0 (225.0)	2.3 (59.0)	0.2 (5.0)	PA66HS	Black	100
126-00183	PT2ASFT6.5 PT0.7-1.5-E	51.7 (230.0)	0.24 - 0.26 (6.3 - 6.7)	0.03 - 0.06 (0.7 - 1.5)	4.4 (112.7)	0.8 (20.0)	0.1 (3.4)	PEEK	Beige	7000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.  
Installation tools: EVO7, EVO7SP, EVO9, EVO9HT, MK7P, MK7HT, MK9P.