


## Specification Sheet

Part Number: RT50S9M4

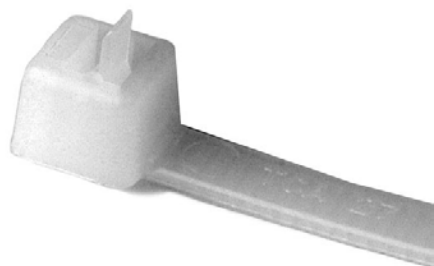

Releasable Cable Tie, Release Tab, 6.3" Long, 50 lb Tensile Strength, PA66, Natural, 1000/pkg

Article Number	115-06304
Type	RT50S
Color	Natural (NA)
Features & Benefits	<ul style="list-style-type: none"><li>• Special extended-pawl design offers a release feature for quick and easy access to wire bundles.</li><li>• Head design provides high tensile strength with very low insertion force even after repeated use.</li><li>• Bent tail ensures a quick and simple installation.</li></ul>
Quantity Per	bag

### Product Description

HellermannTyton Releasable Cable Ties feature an extended pawl for easy access to wire bundles when changes are necessary. The head design guarantees high tensile strength even after repeated use, as well as a low insertion force. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.

<b>Short Description</b>	Releasable Cable Tie, Release Tab, 6.3" Long, 50 lb Tensile Strength, PA66, Natural, 1000/pkg
<b>Global Part Name</b>	RT50S-PA66-NA
<b>Minimum Tensile Strength (Imperial)</b>	50.0
<b>Minimum Tensile Strength (Metric)</b>	225.0
<b>Length L (Imperial)</b>	6.3
<b>Length L (Metric)</b>	160.0
<b>Identification Plate Position</b>	none
<b>Releasable Closure</b>	Yes
<b>Tie Closure</b>	plastic pawl
<b>Variant</b>	Inside Serrated
<b>Width W (Imperial)</b>	0.18
<b>Width W (Metric)</b>	4.6
<b>Bundle Diameter Min (Imperial)</b>	0.06
<b>Bundle Diameter Min (Metric)</b>	1.5
<b>Bundle Diameter Max (Imperial)</b>	1.38
<b>Bundle Diameter Max (Metric)</b>	35.0

**Height H (Imperial)**

.06

**Height H (Metric)**

1.40

**Material**

Polyamide 6.6 (PA66)

**Material Shortcut**

PA66

**Flammability**

UL 94 V2

**Operating Temperature (Metric)**

-40°F to +185°F (-40°C to +85°C)

**ROHS Complaint**

Yes

**Certification/Specification WEB**

UL-ZODZ2.E64139

**UL Recognized (US)**

Yes

**UL Recognized (US and Canada)**

Yes

**Package Quantity(Imperial)**

1000

**Package Quantity (Metric)**

1000

**Customs Number**

3926909988

**Weight (Metric)**

1.2

---

© 2019 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)