


Specification Sheet

Part Number: RT50S9C2

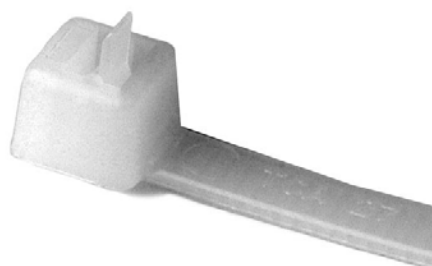

Article Number

115-06319

Type

RT50S

Color

Natural (NA)

Features & Benefits

- Special extended-pawl design offers a release feature for quick and easy access to wire bundles.
- Head design provides high tensile strength with very low insertion force even after repeated use.
- Bent tail ensures a quick and simple installation.

Quantity Per

bag

Product Description

HellermannTyton Releasable Cable Ties feature an extended pawl for easy access to wire bundles when changes are necessary. The head design guarantees high tensile strength even after repeated use, as well as a low insertion force. For high-volume applications, tensioning tools are available to ensure consistent and safe installation.

Short Description	Releasable Cable Tie, Release Tab, 6.3" Long, 50 lb Tensile Strength, PA66, Natural, 100/pkg
Global Part Name	RT50S-PA66-NA
Minimum Tensile Strength (Imperial)	50.0
Minimum Tensile Strength (Metric)	225.0
Length L (Imperial)	6.3
Length L (Metric)	160.0
Identification Plate Position	none
Releasable Closure	Yes
Tie Closure	plastic pawl
Variant	Inside Serrated
Width W (Imperial)	0.18
Width W (Metric)	4.6
Bundle Diameter Min (Imperial)	0.06
Bundle Diameter Min (Metric)	1.5
Bundle Diameter Max (Imperial)	1.38
Bundle Diameter Max (Metric)	35.0

Thickness T (Imperial)	0.05
Thickness T (Metric)	1.2
Height H (Imperial)	.06
Height H (Metric)	1.40
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	UL 94 V2
Operating Temperature (Metric)	-40°F to +185°F (-40°C to +85°C)
Reach Complaint(Article 33)	Yes
ROHS Complaint	Yes
Certification/Specification WEB	UL-ZODZ2.E64139
UL Recognized (US)	Yes
UL Recognized (US and Canada)	Yes
Package Quantity(Imperial)	100
Package Quantity (Metric)	100

Customs Number

3926909988

Content Unit(BMEcat)

pcs.

Weight (Metric)

1.2