


Specification Sheet

Part Number: MB410H4

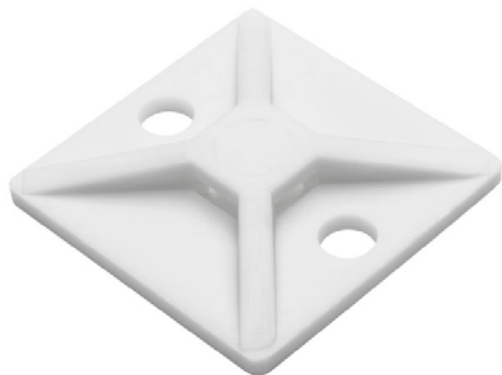

Screw Mount Cable Tie Base, 1.12" x 1.12", .18" Max Tie Width, .18" Hole Dia, PA66, White, 500/pkg

Article Number	151-00319
Type	MB4
Color	White (WH)
Features & Benefits	<ul style="list-style-type: none">•Compact size fits most mounting applications.•Simple to install with a screw or rivet.•Single hole attachment with two-way entry for cable tie.
Quantity Per	bag
Product Description	These cable tie mounts are compact in size. They are designed for simple yet robust installation. They pair with a cable tie for mounting applications including telecom equipment, switchgear and control cabinets.
Short Description	Screw Mount Cable Tie Base, 1.12" x 1.12", .18" Max Tie Width, .18" Hole Dia, PA66, White, 500/pkg

Global Part Name

MB4-PA66-WH

Length L (Imperial)

1.12

Length L (Metric)

28.5

Fixation Method

Screw Mounting and Rivet

Width W (Imperial)

1.12

Width W (Metric)

28.5

Cable Ties

T18 - 50

Height H (Imperial)

.19

Height H (Metric)

4.80

Cable Tie Width Max (Imperial)

0.18

Cable Tie Width Max (Metric)

4.6

Mounting Hole Diameter D (Imperial)

0.18

Mounting Hole Diameter D (Metric)

4.6 mm

Mounting Hole Diameter D Max (Metric)

4.6

Mounting Hole Centers (Imperial)

0.8

Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	UL 94 V2
Operating Temperature (Metric)	-40°F to +185°F (-40°C to +85°C)
ROHS Complaint	Yes
Certification/Specification WEB	UL
UL Recognized (US)	Yes
UL Recognized (US and Canada)	Yes
Package Quantity(Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988