


## Specification Sheet

Part Number: MB510C2

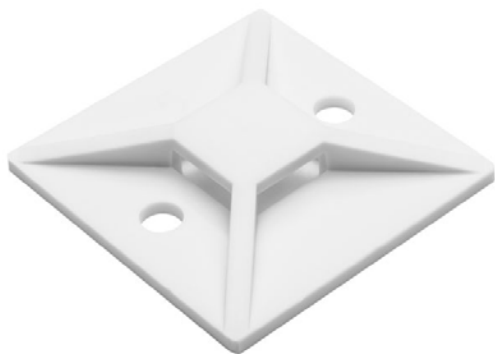

<b>Article Number</b>	151-00324
<b>Type</b>	MB5
<b>Color</b>	White (WH)
<b>Features &amp; Benefits</b>	<ul style="list-style-type: none"><li>•Compact size fits most mounting applications.</li><li>•Simple to install with a screw or rivet.</li><li>•Single hole attachment with two-way entry for cable tie.</li></ul>
<b>Quantity Per</b>	bag
<b>Product Description</b>	These cable tie mounts are compact in size. They are designed for simple yet robust installation. They pair with a cable tie for mounting applications including telecom equipment, switchgear and control cabinets.
<b>Short Description</b>	Screw Mount Cable Tie Base, 1.49" x 1.49", .35" Max Tie Width, .19" Hole Dia, PA66, White, 100/pkg
<b>Global Part Name</b>	MB5-PA66-WH

<b>Length L (Imperial)</b>	1.49
<b>Length L (Metric)</b>	37.7
<b>Fixation Method</b>	Screw Mounting and Rivet
<b>Width W (Imperial)</b>	1.49
<b>Width W (Metric)</b>	37.7
<b>Cable Ties</b>	T18 - T150
<b>Height H (Imperial)</b>	.25
<b>Height H (Metric)</b>	6.20
<b>Cable Tie Width Max (Imperial)</b>	0.35
<b>Cable Tie Width Max (Metric)</b>	8.9
<b>Mounting Hole Diameter D (Imperial)</b>	0.19
<b>Mounting Hole Diameter D (Metric)</b>	4.8 mm
<b>Mounting Hole Diameter D Max (Metric)</b>	4.8
<b>Mounting Hole Centers (Imperial)</b>	1.0
<b>Material</b>	Polyamide 6.6 (PA66)

**Material Shortcut** PA66

**Flammability** UL 94 V2

**Operating Temperature (Metric)** -40°F to +185°F (-40°C to +85°C)

**Reach Complaint(Article 33)** Yes

**ROHS Complaint** Yes

**Certification/Specification WEB** UL | ANSI/UL 62275 UL | ANSI/UL 746B UL | ANSI/UL 1565

**UL Recognized (US)** Yes

**UL Recognized (US and Canada)** Yes

**Package Quantity(Imperial)** 100

**Package Quantity (Metric)** 100

**Customs Number** 3926909988

**Content Unit(BMEcat)** pcs.