


Specification Sheet

Part Number: 151-00903

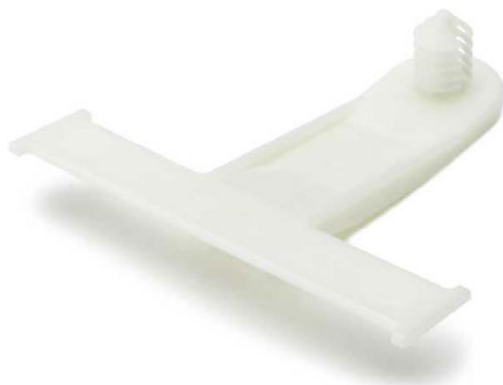

Standoff Bundling Clip, 2.3" Long, Panel Thickness .02"–.23", PA66HIRHS, Natural, 3000/box

Article Number	151-00903
Type	SOC10FT6LG
Color	Natural (NA)
Features & Benefits	<ul style="list-style-type: none">•Clip can be installed by hand – no need for hardware or tools.•Design provides low insertion and high extraction force, for simple, secure performance.•Clip keeps bundle away from areas that could cause damage due to rubbing.
Quantity Per	box

Product Description

Bundling clips are designed to provide simple and easy methods of securing cable bundles, hoses, or pipes. They are fastened onto the tape bar using bundle or cable ties. The different fixing orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standard bundling clips are available as well as standoff and stud mount versions.

Short Description	Standoff Bundling Clip, 2.3" Long, Panel Thickness .02"-.23", PA66HIRHS, Natural, 3000/box
Global Part Name	SOC10FT6LG-PA66HIRHS-NA
Length L (Imperial)	2.3
Length L (Metric)	58.0
Offset Length(Imperial)	1.71
Offset Length(Metric)	43.35
Fixation Method	Fir Tree
Width W (Imperial)	0.6
Width W (Metric)	16.0
Height H (Imperial)	0.60
Height H (Metric)	14.50
Panel Thickness Min(Imperial)	0.02
Panel Thickness Max(Imperial)	0.23
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	5.75
Mounting Hole Diameter D (Imperial)	0.24 " x 0.27

Mounting Hole Diameter D (Metric)

6.35 mm (hexagonal) 6.1 - 6.9 mm

Mounting Hole Diameter D Min (Imperial)

0.24

Mounting Hole Diameter D Max (Imperial)

0.27

Mounting Hole Diameter D Max (Metric)

6.9

Material

Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)

Material Shortcut

PA66HIRHS

Flammability

UL 94 HB

Operating Temperature (Metric)

-40°F to +230°F (-40°C to +110°C)

Reach Complaint(Article 33)

Yes

ROHS Complaint

Yes

Package Quantity(Imperial)

3000

Package Quantity (Metric)

3000

Customs Number

3926909988

Content Unit(BMEcat)

pcs.

© 2019 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)